



On Line Catalog



BURNDY Catalog Number
UPC Number
Description
Status

YS34L
781810508558
500 MCM CU. BUTT SPLICE
Active

Web Use
BURNDY Product Line

Strip Length
Barrell Style
Barrel Type

Dimensional
1-7/16
Chamfered
Standard

General
Compression CU Reducer/Splice,
Barrel A:500kcmil(Str) Barrel
B:500kcmil(Str), 600V-35kV,
Standard Barrel, Electro-Tin Plated

Physical
Tin - Electro Plated
Y
20,299
Copper


Approvals / Certifications

Y
Y
Compliant
N
N
UL468A-468B

Product Description

Type of Plating
Plated (Yes or No)
Index Number
Product Material

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS
Industry Standards
Documentation

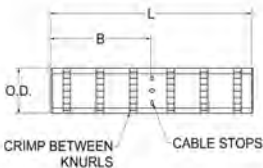

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175