

Intensifier3® Series Indoor Dome Cameras

See Color In Almost Complete Darkness Without IR LEDs


CVC6246iHR 2.8 - 12mm auto iris varifocal lens, black housing

CVC6246iHRW 2.8 - 12mm auto iris varifocal lens, white housing

Features

- 1/3" Sony Super HAD II™ CCD
- 650 TV lines of color resolution
- Amplify existing light with no distance limitations
- No problems caused by objects that reflect or absorb IR light sources
- Minimum illumination 0.00002 lux (Intensifier3® @ 512x)
- Now with Presets: Outdoor, Indoor, Elevator, Lobby, Hallway & Dark
- Full OSD operation
- Wall or ceiling mount
- S/N Ratio more than 52dB (weight on)
- EZ mount system simplifies installation
- 5 year warranty

**INT
3**

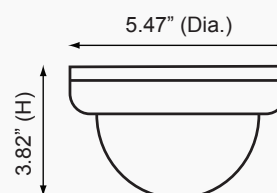

Specifications

Image Sensor	1/3" Sony Super HAD II™ CCD
Resolution	650 TV lines
Minimum Illumination	CDS Off: 0.15 lux CDS On: 0.00002 lux
Effective Pixels	768 (H) x 494 (V)
Total Pixels	811 (H) x 508 (V)
TV System	NTSC
Scanning Frequency	15.734kHz (H) & 59.94Hz (V)
Scanning System	2:1 interlace
Synchronization	Internal
S/N Ratio	More than 52dB
Video Output	CVBS: 1.0Vp-p / 75 ohms
Electronic Shutter Speed	1/60 sec. - 1/120,000 sec.
OSD	Available
WDR	On / Off (level adjustable)
Backlight Compensation	BLC / HLC / Off
Day/Night	Color / BW / Auto
AGC	High / Low / Off

White Balance	ATW / Outdoor / Indoor / Manual / AWC (1,700°K - 11,000°K)
Intensifier3®	Auto / Off (selectable x2 - x512)
Motion Detection	On / Off (8 programmable zones)
Privacy Masking	On / Off (12 programmable zones)
Speco DNR	On / Off (level adjustable)
Digital Zoom	On / Off (1x - 16x)
DIS	On / Off
Sharpness	On / Off (level adjustable)
Flip / Mirror	On / Off
Power Supply	12VDC / 24VAC dual voltage operation (power supply not included)
Power Consumption	12VDC, 250mA / 24VAC, 100mA
Operating Temperature	14° F – 122° F
Storage Temperature	-4° F – 140° F
Dimensions	3.82" (H) x 5.47" (Dia.)
Weight	1.54 lbs.

Speco Technologies is constantly developing and improving products. We reserve the right to modify product design and specifications without notice and without incurring any obligation.
Spec Rev. 2/25/13



Optional Accessories



DFM
Tile Ceiling
Flush Mount



CVCWMTIND
Indoor
Wall Mount



PSW4
24VAC
Power Supply



PSW5
12VDC
Power Supply