

960H 700 TVL Indoor/Outdoor IR Dome Camera with Chameleon Cover™


- HT670H** 4mm fixed lens, dark grey housing
HT671H 2.8-12mm auto iris varifocal lens, dark grey housing
HT672H 5-50mm auto iris varifocal lens, dark grey housing

Features

- 1/3" 960H color CCD
- 700 TV lines of resolution
- 28 IR LEDs
- Chameleon Cover™: snaps on and can be painted to match any décor!*
- Highest resolution: vivid sharp picture in complete darkness
- No noise, ghosting effect with DNR
- 3DNR (digital noise reduction)
- DWDR (digital wide dynamic range)
- Smart digital zoom
- Full OSD operation
- Digital image stabilizer
- De-fog
- 3 axis lens mount
- IP67 compliant
- 12VDC / 24VAC dual voltage operation
- 5 year warranty



Shown with included paintable, snap-on Chameleon Cover™

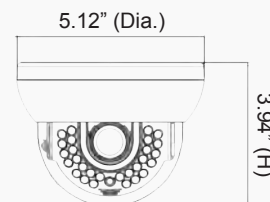

Specifications

Image Sensor1/3" 960H color CCD
 Resolution700 TV lines
 Minimum Illumination0.01 lux @ F1.2 / IR LED On
 Effective Pixels976 (H) x 494 (V)
 Total Pixels1020 (H) x 508 (V)
 TV SystemNTSC
 Scanning System.....2:1 interlace
 Number of IR LEDs.....28
 IR Range98 ft. (depending on scene reflection)
 IR LED Wavelength850nm
 S/N Ratio.....52dB
 Video Output1.0Vp-p / 75 ohms
 DWDROutdoor / Indoor / Off
 Backlight Compensation.....BLC / HLC / Off
 Day/NightAuto / Day / Night / Ext
 AGCHigh / Middle / Low
 Sense-Up.....Auto / Off (x2 – x256)
 White Balance.....ATW / AWB / AWC – Set / Manual (1,800°K – 11,000°K)

Privacy Masking8 zones
 MirrorH-Rev / V-Rev / Rotate / PIP
 Digital Zoomx32
 Smart Digital Zoom.....On / Off
 De-FogManual / Auto / Off
 Defect CompensationAuto (512 points)
 3DNR1 – 200 level selectable
 DISOn / Off
 Power Supply12VDC / 24VAC dual voltage operation
 (power supply not included)
 Power Consumption.....12VDC, 500mA / 24VAC, 250mA
 Storage Temperature/
 Humidity.....-4° F – 140° F / 20% – 95% RH
 Operating Temperature/
 Humidity.....-4° F – 140° F / 20% – 95% RH
 Dimensions.....3.94" (H) x 5.12" (Dia.)
 Weight1.98 lb.

Optional Accessories



INTPM
Pendant
Mount



INTWM
Wall Mount



DFM
Tile Ceiling
Flush Mount



INTCM
Corner/Pole
Adaptor
(use with INTWM)



CVCJBD
Dome Camera
Junction Box



PSW4
24VAC
Power Supply



PSW5
12VDC
Power Supply



* Chameleon Cover™ - for best results when used outdoors, waterproof paint is recommended. Speco Technologies is constantly developing and improving products. We reserve the right to modify product design and specifications without notice and without incurring any obligation. Spec Rev. 8/25/14