

P.A. Amplifiers


PBM60A	60W RMS P.A. Amplifier
PBM120A	120W RMS P.A. Amplifier
PBM60AT	60W RMS P.A. Amplifier with AM/FM Tuner
PBM120AT	120W RMS P.A. Amplifier with AM/FM Tuner
PBM60AU	60W RMS P.A. Amplifier with Tuner, CD, and USB
PBM120AU	120W RMS P.A. Amplifier with Tuner, CD, and USB

Features

- Includes IR remote and rack-mounting kit
- 5 zoned 70 or 25V speaker outputs
- Non-zoned 4/8/16 Ohms output
- Master digital volume control with display
- Individual volume control for each input
- Front bass and treble controls
- Phantom power for all Mic inputs, and Mic1 selectable priority paging
- Digital front panel lock
- RCA or XLR line output
- Telephone paging input and Music-on-hold output
- RS232 input for integration with popular control systems

Specifications

	PBM120A/T/U
RMS Power	120W
Max. Power.....	240W
AC Power Consumption	200W
Power Supply	AC 115V, 60Hz
Zones.....	5
Speaker Outputs.....	4/8/16 Ohms (non-zoned), 70/25V (zoned)
Other Outputs.....	Aux (RCA or XLR)
Inputs.....	1 x AM Antenna (Press terminal), 1 x FM Antenna (BNC), 3 x Aux (Stereo RCA), 3 x Mic (XLR), 1 x RS-232, 1 x TEL (Terminal)
Frequency Response	50Hz ~ 20kHz
Tone Control	Bass $\pm$ 10dB, Treble $\pm$ 10dB
THD	Less than 1% @ 1KHz
Signal/Noise Ratio	>89dB
Controls	Volume for each source, Master Volume, Vox Volume, MoH Volume, Tone, Source Selector, Zone Selector, Module
Telephone.....	TEL in and MoH Out
Indicators.....	Volume level, power, source, & System Lock
Dimensions.....	16.9" (W) x 3.4" (H) x 11.75" (D)
Weight	26.5 lbs.
Includes	IR Remote Control, Rack Mounting Hardware
Listings	CE, FCC, RoHS

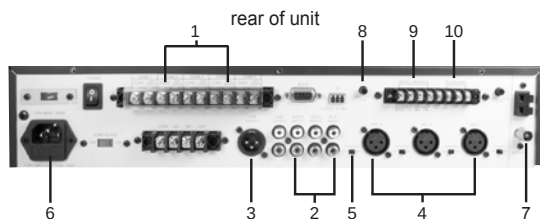

1. Zone 1-5 output terminals
2. Aux. input jacks
3. Aux. output jacks
4. XLR Mic connectors
5. Phantom power buttons
6. AC plug-in for electrical cord
7. Inputs for AM/FM Radio antennas
8. Music-on-hold volume adjustment
9. Music-on-hold input
10. Telephone paging input



**PBM60A
PBM120A**



**PBM60AT
PBM120AT**



**PBM60AU
PBM120AU**

PBM60A/T/U

60W
120W
100W
AC 115V, 60Hz
5
4/8/16 Ohms (non-zoned), 70/25V (zoned)
Aux (RCA or XLR)
1 x AM Antenna (Press terminal), 1 x FM Antenna (BNC), 3 x Aux (Stereo RCA), 3 x Mic (XLR), 1 x RS-232, 1 x TEL (Terminal)
50Hz ~ 20kHz
Bass $\pm$ 10dB, Treble $\pm$ 10dB
Less than 1% @ 1KHz
>88dB
Volume for each source, Master Volume, Vox Volume, MoH Volume, Tone, Source Selector, Zone Selector, Module
TEL in and MoH Out
Volume level, power, source, & System Lock
16.9" (W) x 3.4" (H) x 11.75" (D)
20 lbs.
IR Remote Control, Rack Mounting Hardware
CE, FCC, RoHS



Rack mounting
kit included



IR remote
included

Optional Accessories



IRRPTKIT
IR Repeater Kit



MMB3XLR
3 Channel
XLR Microphone Mixer



MMB8XLR
8 Channel
Microphone/Line
Level Mixer