


## 4-Port Component Video + Stereo Audio over Cat5/Cat6 Extender Splitter, Box-Style Transmitter

MODEL NUMBER: **B136-004**

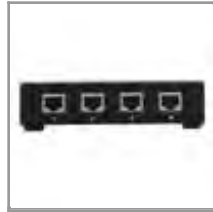

### Description

Tripp Lite's B136-004 takes a single Component Video and Stereo Audio signal and splits it to five (1 local, 4 remote). When used in conjunction with a B136-100 or B136-100-WP remote unit, you can transmit a Component Video ( YPbPr ) and Stereo Audio signal from any DVD player, PS3, or Cable/Satellite device to up to four displays over a single CAT5, CAT5E, or CAT6 cable. A 1080i (60Hz) Component Video and Stereo Audio signal can be extended up to 300 ft. when using 24Awg, Solid Wire UTP cable (Tripp Lite N202-Series); or, up to 400 ft. when using Zero-Skew UTP cable (Tripp Lite P524-01K). A 480p (60Hz) Component Video and Stereo Audio signal can be extended up to 500 ft. when using 24Awg, Solid Wire UTP cable (Tripp Lite N202-Series); or, up to 700 ft. when using Zero-Skew UTP cable (Tripp Lite P524-01K). The number of displays can be increased to up to 13 (1 local, 12 remote) by daisy chaining 3 B136-004 units together. Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases.

### Features

- Splits a single Component Video and Stereo Audio signal into five (1 local, 4 remote)
- Features an extra set of Component Video and Stereo Audio connectors for an optional local display
- Works in conjunction with a B136-100 remote unit or a B136-100-WP remote wallplate
- A 1080i (60Hz) Component Video and Stereo Audio signal can be extended up to 300 ft. when using 24Awg, Solid Wire UTP cable (Tripp Lite N202-Series); or, up to 400 ft. when using Zero-Skew UTP cable (Tripp Lite P524-01K)
- A 480p (60Hz) Component Video and Stereo Audio signal can be extended up to 500 ft. when using 24Awg, Solid Wire UTP cable (Tripp Lite N202-Series); or, up to 700 ft. when using Zero-Skew UTP cable (Tripp Lite P524-01K)
- Connect up to 13 displays (1 local, 12 remote) by cascading 3 B136-004 units together
- Includes a 1 ft. Component Video + Stereo Audio daisychain cable
- Up to 3 B136-004 units can be mounted in 1U of rack space when using a B132-004-RB Extender/Splitter 19 in. rackmount bracket
- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases

## Specifications

### Highlights

- Splits a single Component Video and Stereo Audio signal into five (1 local, 4 remote)
- Extends a 1080i (60Hz) Component Video and Stereo Audio signal up to 300 ft. when using 24Awg, Solid Wire UTP cable (Tripp Lite N202-Series); or, up to 400 ft. when using Zero-Skew UTP cable (Tripp Lite P524-01K)
- Connect up to 13 displays (1 local, 12 remote) by daisy chaining 3 B136-004 units together
- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases

### Package Includes

- B136-004 4-Port Component Video + Stereo Audio Extender/Splitter
- AC Adapter ( Input: 100-240V, 50/60Hz, 0.5A Output: 5V, 2A )
- 1 ft. Component Video + Stereo Audio Source / Daisychain cable
- Owner's Manual



General Info	
RoHS	Y
OVERVIEW	
Chromebook Compatible	No
Display Style	Splitter
Model Type	Component
Cable Types	CAT5/CAT5E
PHYSICAL	
Optional Mounting Accessory Notes	Up to 3 <a href="#">B136-004</a> units can be mounted in 1U of rack space when using a <a href="#">B132-004-RB</a> Extender/Splitter 19 in. rackmount bracket
Unit Dimensions (hwd / in.)	1.1 x 5 x 4
Unit Dimensions (hwd / cm)	2.79 x 12.7 x 10.16
Unit Weight (lbs.)	1.1
Unit Weight (kg)	0.50
Included Mounting Accessories	Yes
Color	Black
CONNECTIONS	
Side A - Connector 1	SOURCE: (x5) RCA Female
Side A - Connector 2	LOCAL: (x5) RCA Female
Side B - Connector 1	(x4) RJ45 Female
WARRANTY	
Product Warranty Period (Worldwide)	1-year limited warranty

© 2015 Tripp Lite. All rights reserved. All trademarks are the sole property of their respective owners. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Photos may differ slightly from final products.