



Cross Connect Punchdown System

- Exceeds all ANSI/TIA-568-C.2 Category 6 and 5e standard requirements for voice and data applications
- Third party tested
- Multiple mounting configurations allow brackets to be mounted to back board or wall maximizing the use of valuable space
- Integrated mounting notches are compatible with standard cross connect mounting brackets providing maximum design flexibility for new and existing Category 6 and Category 5e installations
- Mounting bases accept 4 and 5-pair connecting blocks up to 50 or 300-pairs

- 4 or 5-pair terminal markings on connecting blocks speed installation by assisting in punchdown terminal identification
- Punchdown tool terminates 22 – 26 AWG UTP cable
- Optional deep trough cable distribution ring maintains proper bend radius control providing improved cable management in 300 pair mounting systems for both horizontal and vertical cable routing
- Optional label kit compatible with 50 and 300-pair Panduit Cross Connect Bases; enables port identification enabling compliance according to ANSI/TIA/EIA-606-A labeling standards



PXMT50



PXMT300




PXPCB4



PXPCB5



PXDR

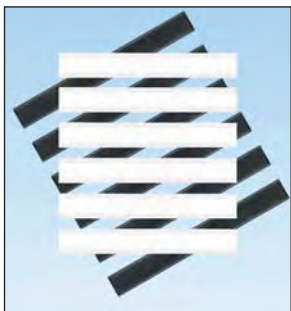

PXLK-VI

Part Number	Part Description	Std. Pkg. Qty.	Std. Ctn. Qty.
Mounting Bases			
PXMT50	50-pair mounting base.	1	0
PXMT300	300-pair mounting base.	1	0
Mounting Bases			
PXPCB4	4-pair cross connect block.	1	20
PXPCB5	5-pair cross connect block.	1	20
Mounting Bases			
PXDR	Cross connect cable distribution ring.	1	10
PXLK-VI	Cross connect label kit includes six labels and six label holders. Compatible with 50 and 300-pair cross connect bases.	6	60

Termination tool found on page B.87 of SA-NCCB51.