



Quam

LOUDSPEAKER ASSEMBLIES

SOLUTION 2

CEILING MOUNT

Includes TWO (2) Each : C10X/BU/WS/VC, ERD8U, SSB-3

GENERAL DESCRIPTION

The **SOLUTION 2** is a complete speaker/transformer/baffle solution for ceiling installations. Each installer package includes two (2) C10X/BU/WS/VC - The 8C10PAX - 8" O.D. dual cone loudspeaker with a 10 oz. magnet and a TBLU - 5W-25/70V transformer with a screwdriver or knob adjusted (knob is included) volume control mounted on a BR8WS - round, steel, stud mount baffle. Also included are two (2) SSB-3 - rust-resistant steel, load bearing supports and two (2) ERD8U - 275 CID, round, steel back boxes.

*** SHIPPED AS A COMPLETE PAIR IN ONE CARTON**

INTENDED USE - Indoor Environment


 
Program Material	Signal tones, voice, and music
Installation	Downward-Firing in a 24" Wide, Drop-Tile Ceiling

AUDIO SPECIFICATIONS



Average Sensitivity	95 dB SPL, 1W/ 1M
Loudspeaker Power Rating	20W RMS, EIA 426A Standard
Calculated Output	102dB SPL, 5W/ 1M
Magnet Type & Weight	BeFe Ceramic, 10 oz. Nominal
Frequency Response	60Hz - 17 kHz EIA 426A Standard
Nominal Coverage Angle	90° Included Angle, -6 dB / 2 kHz, Half space
Audio Connection	7" Color Coded Leads

SYSTEM COMPONENTS


Loudspeaker	8C10PAX
Transformer	5W-25/70V : 5 tap, Color Coded Leads (5W, 2.5W, 1.25W, 0.63W, 0.31W)
Baffle	BR8WS
Back Box	ERD8U
Mounting Device	SSB-3

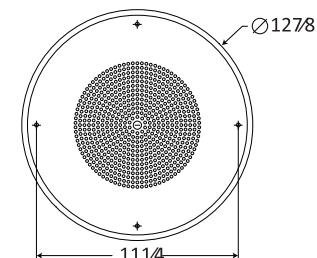

C10X/BU/WS/VC

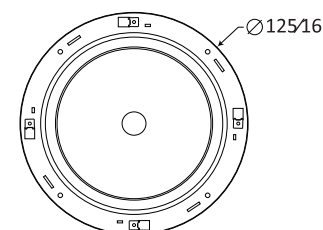 

ERD8U

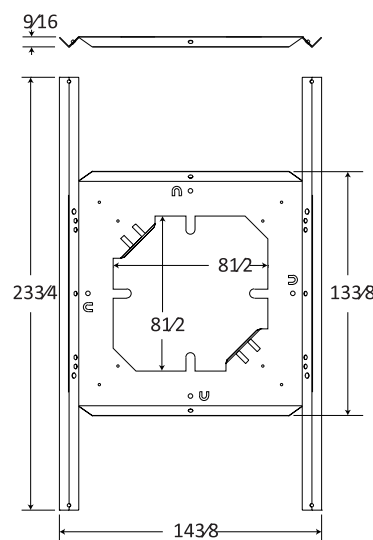

SSB-3

Recommended construction sequences, installation instructions, and A&E Specifications are available in various formats in the QUAM Architects' and Engineers' Resources section on the web at:
www.QuamSpeakers.com

© 2013 Quam-Nichols Company reserves the right to make changes and/or improvements to its products at any time and without notice.



QUAM-NICHOLS COMPANY, INC.
234 East Marquette Rd.
Chicago, IL. 60637
Tel: 1-800-NEED-NOW (800-633-3669)
Fax: 1-888-NEED-NOW (888-633-3669)
e-mail: NeedNow@QNC.com
www.QuamSpeakers.com