

MODEL:

SR2POST25

25U SmartRack® Open Frame Rack



25 Rack Units



800 lb
Stationary
Load Capacity



Standard 19-inch
Rack Width



Toolless
Mounting Slots




Integrated
Baying Tabs



Square Hole
Mounting

- A** Mounting Rails (2)
- B** Toolless Button Holes
(for vertical PDUs or cable managers)

Also Includes: Owner's manual, installation hardware, rackmount equipment mounting hardware (28 screws, 28 washers) and cable management hooks.

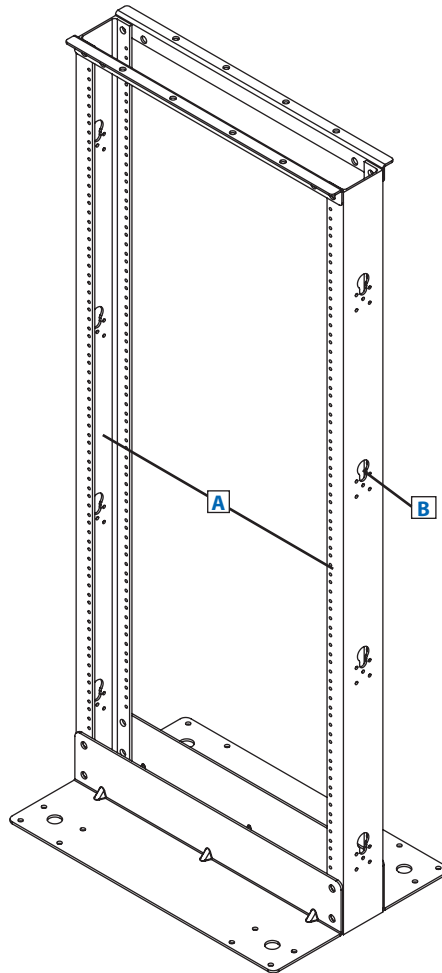

- Ships disassembled for easy transport and assembly in tight spaces
- Modular design optimized for quick configuration and reconfiguration
- Multiple units can be bolted together side by side
- Ideal for space-constrained or cost-conscious 19-inch rackmount applications

Specifications

Model	SR2POST25
Rack Spaces	25U
Stationary Load Capacity	800 lb (362.9 kg)
Unit Dimensions (H x W x D)	49 x 20.3 x 4.75 in (1244.6 x 515.62 x 120.7 mm)
Shipping Dimensions (H x W x D)	7 x 3 x 49 in (177.8 x 76.2 x 1244.6 mm)
Unit Weight	23 lb (10.43 kg)
Shipping Weight	24 lb (10.89 kg)
Regulatory Compliance	Meets EIA-310-D, NOM (Mexico), IEC 60297-3-100, DIN 41494 and RoHS standards




Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.



SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS



1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

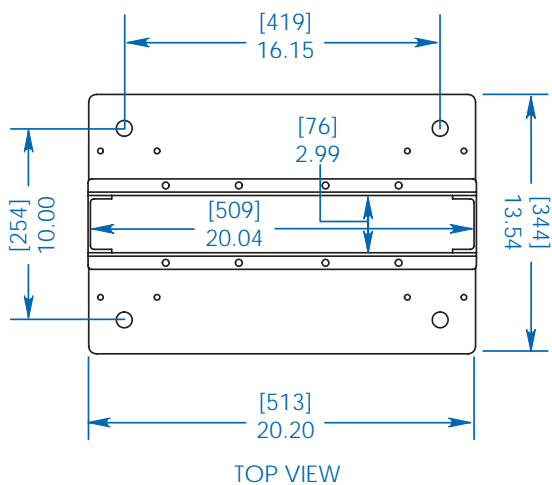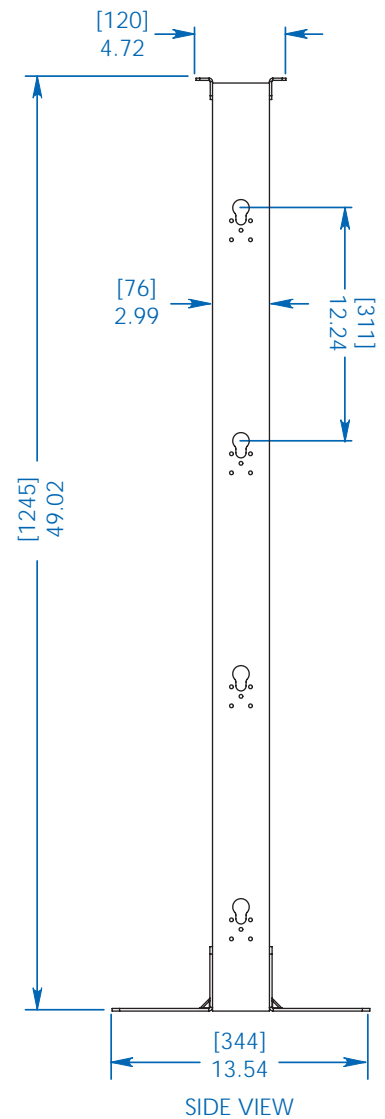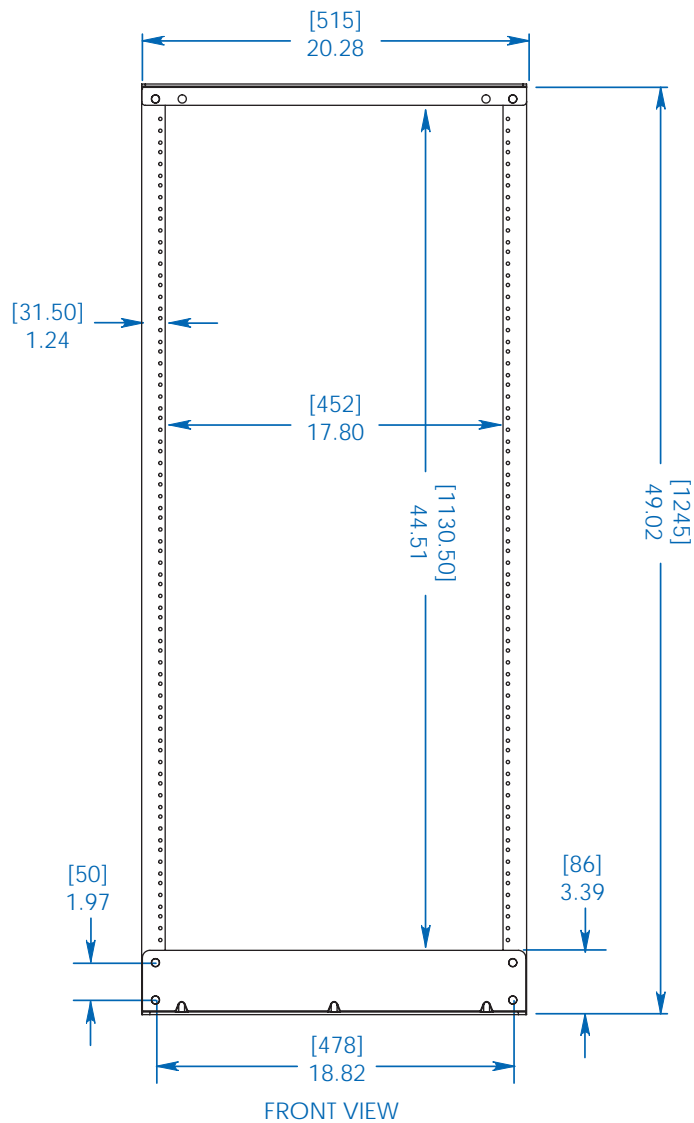

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:
SR2POST25

TRIPP·LITE

1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripp-lite.com