

MODEL:

SR42UBDPWD

SmartRack™ Deep & Wide Rack Enclosure



42 Rack Units



3000 lb
Stationary
Load Rating



2250 lb
Rolling
Load Rating



Heavy-Duty
Casters



Locking Doors
& Side Panels



Standard
19-inch
Rack Width



Toolless
Mounting Slots



Adjustable
Rails with
Easy-View
Depth Index



Airflow
Exceeds
Server OEM
Requirements




Integrated
Baying Tabs



Square Hole
Mounting

- A** Adjustable Mounting Rails (4)
- B** Adjustable PDU Mounting Rails with Toolless Mounting Slots (2 rails hold up to 4 vertical PDUs.)
- C** Roof Panel (Removable)
- D** Front Door (Lockable/Removable/Reversible)
- E** Split Rear Doors (2) (Lockable/Removable)
- F** Side Panels (4) (Lockable/Removable)
- G** Heavy-Duty Casters (4)
- H** Heavy-Duty Levelers (4)
- I** Keys (For doors and side panels.)

Also Includes: Owner's manual, 2 shipping/stabilizing brackets and rackmount equipment mounting hardware (50 cage nuts, 50 mounting screws, 50 nylon cup washers).

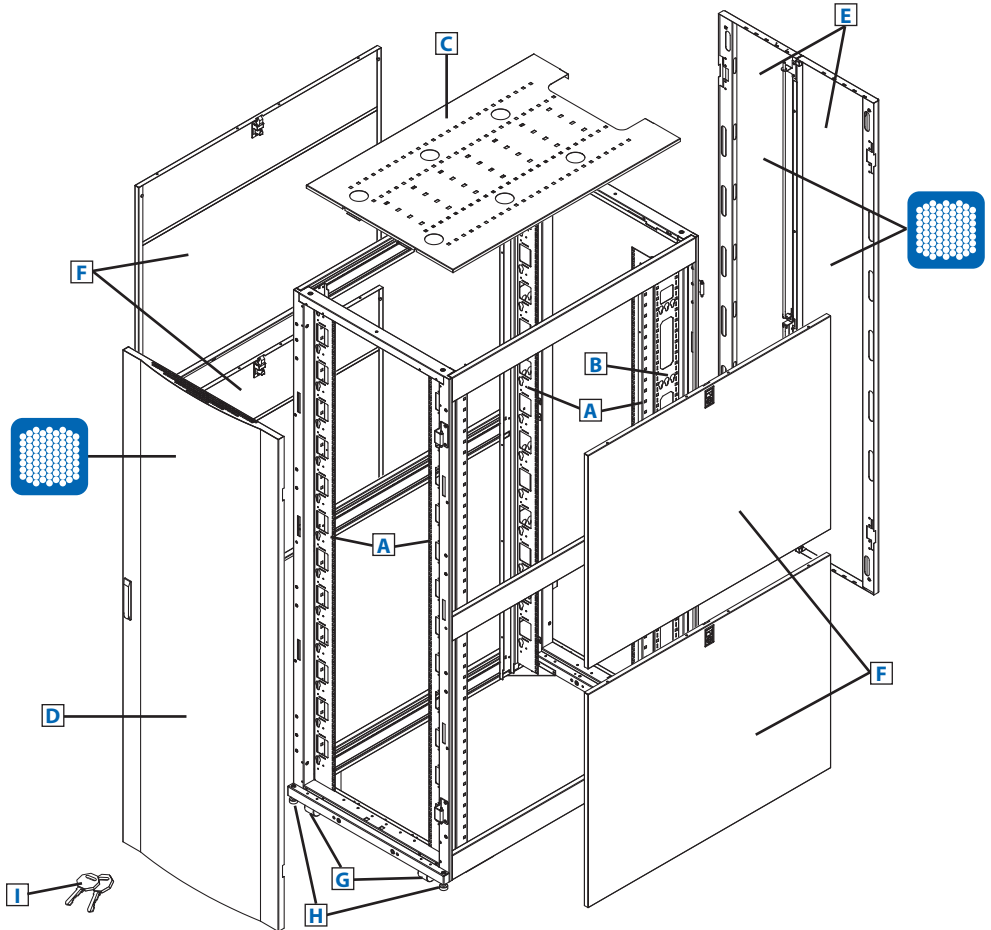

Specifications

Model	SR42UBDPWD
Rack Spaces	42U
Stationary Load Capacity	3000 lb (1361 kg)
Rolling Load Capacity	2250 lb (1021 kg)
Unit Dimensions (H x W x D)	78.5 x 29.53 x 47.25 in. (1994 x 750 x 1200 mm)
Shipping Dimensions (H x W x D)	85 x 32 x 54 in. (2159 x 813 x 1372 mm)
Unit Weight	342 lb (155 kg)
Shipping Weight	404 lb (183 kg)
Certifications	EIA-310-E, IEC 60297-3-100, DIN 41494, UL 60950, RoHS, NOM, PCI-DSS

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.


Also Available: Shock pallet model with special packaging to facilitate equipment pre-installation and reshipment to final site. Heavy-duty shock pallet holds up to 1250 lb (568 kg), including the weight of the enclosure and pre-installed equipment. Add "SP1" to model number above to order shock pallet model.

- Enclosures ship ready for rapid deployment, but can be knocked down for easy reassembly in confined spaces
- Modular design optimized for quick configuration and reconfiguration
- Ideal for rackmount server, network and telecom applications


SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS

TRIPP-LITE


1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

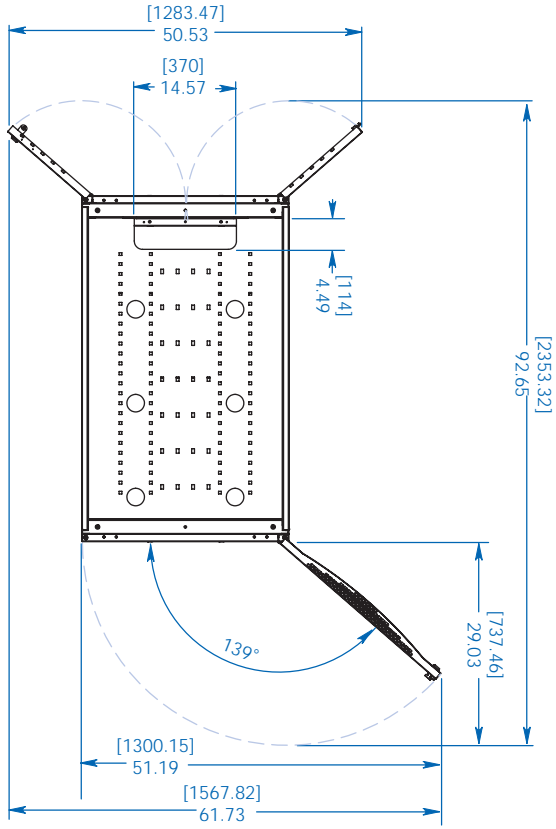

TOP VIEW

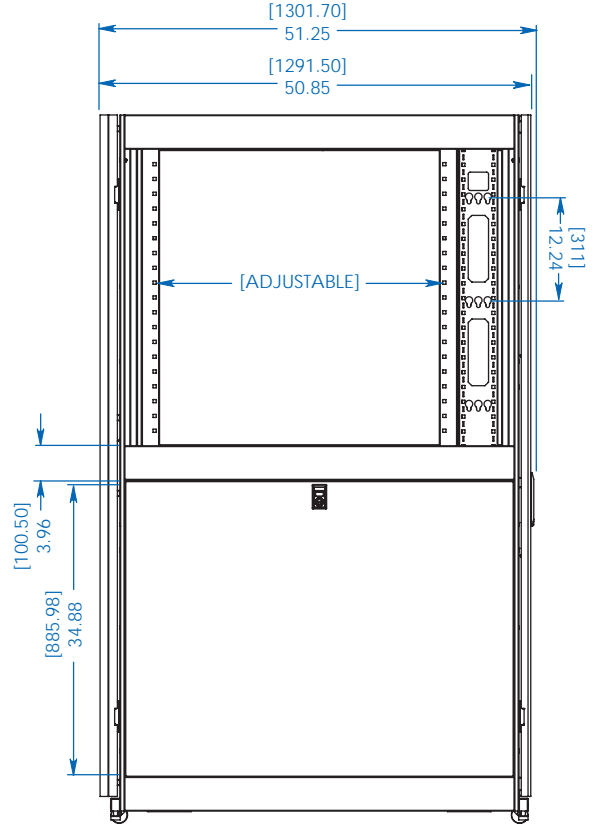


SIDE VIEW

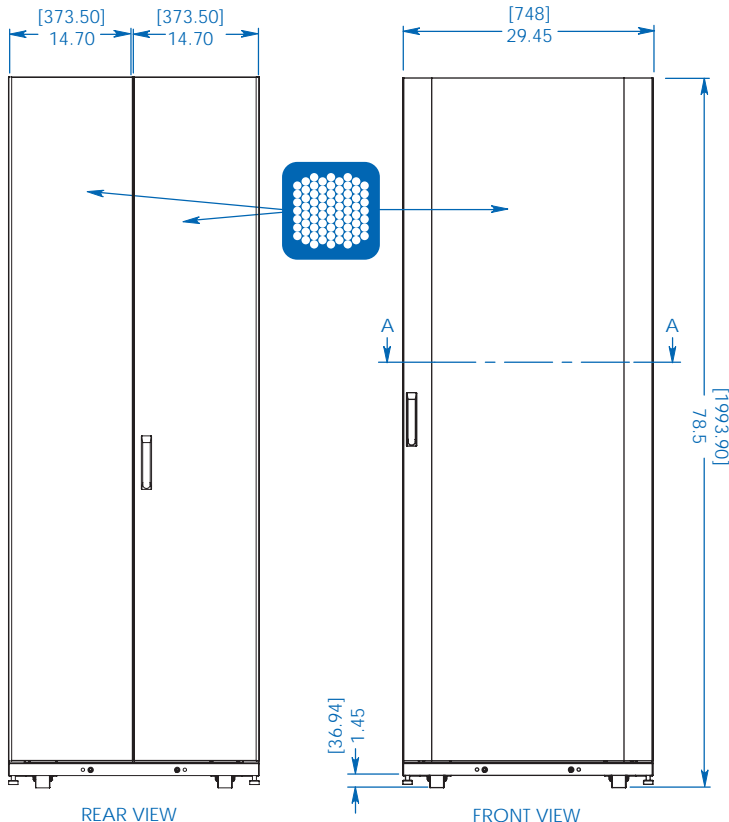

REAR VIEW

FRONT VIEW

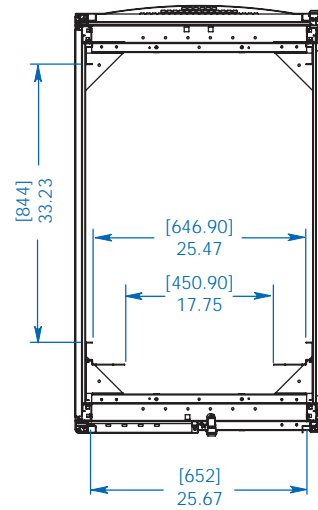


CROSS SECTION A

MODEL:
SR42UBDPWD




Dimensions: [mm] INCHES


Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

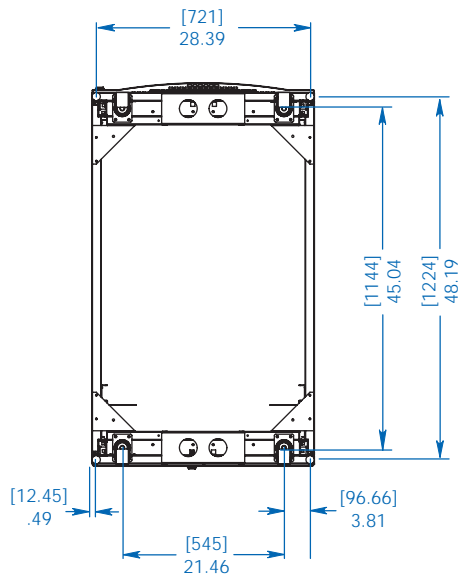

BOTTOM VIEW

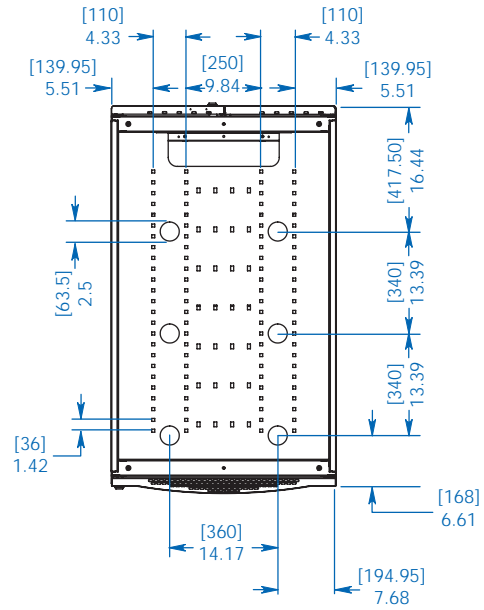

TOP VIEW

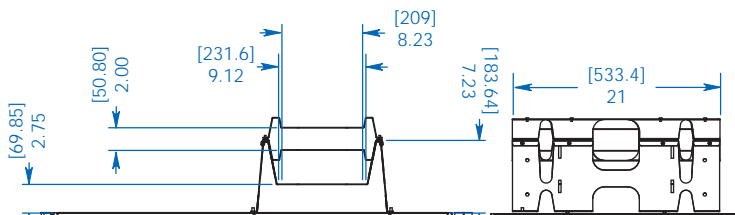


LOCKING LATCH


LOCKING HANDLE

LOCKING, REVERSIBLE HANDLE


OPTIONAL SRCABLETRAY AND SRCABLETRAYEXP CABLE MANAGEMENT ACCESSORIES SHOWN (MOUNTING POSITION ADJUSTS TO ACCOMMODATE A WIDE RANGE OF APPLICATIONS)

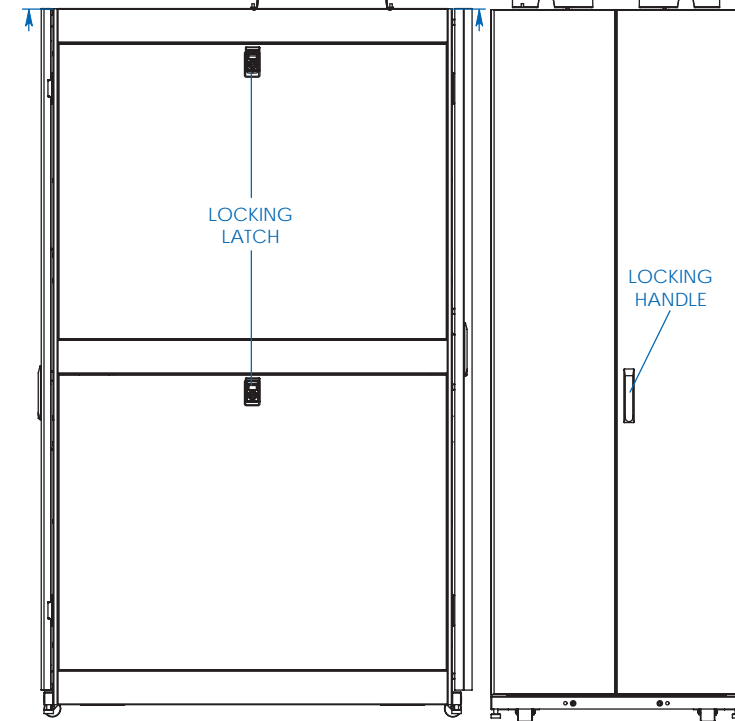

SIDE VIEW

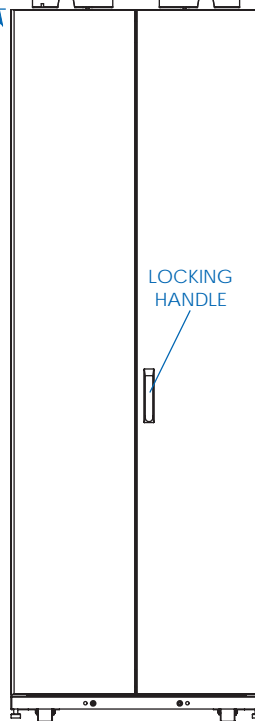

REAR VIEW

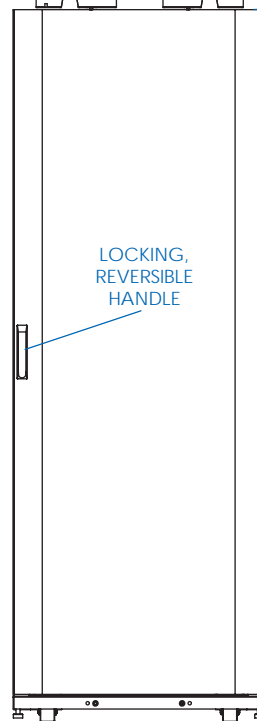

FRONT VIEW

MODEL:
SR42UBDPWD



1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.