

MODEL:

# SR42UBEIS

## SmartRack™ Industrial Rack Enclosure



42 Rack Units



3000 lb Load Rating



Toolless Mounting Slots



Heavy-Duty Industrial Casters



Standard 19-inch Rack Width



Dust, Drip & Splash Protection



Strongest Earthquake Zone Rating



Louvered Doors for Drip-Resistant Ventilation



12 Fans for Superior Airflow

 



Replaceable Dust Filters

- A** Adjustable Equipment Mounting Rails with Depth Index (4, Square Mounting Holes)
- B** Adjustable PDU Mounting Rails with Toolless Mounting Slots (2)
- C** Drip/Dust-Resistant Roof Panel (Removable)
- D** Front Door with Dust-Resistant Gasket (Louvered/Lockable/Removable)
- E** Off-the-Shelf Dust Filters (Replaceable)
- F** Rear Door with Dust-Resistant Gasket (Louvered/Lockable/Removable)
- G** High-Performance Ventilation Fans (12)
- H** Side Panels (Lockable/Removable)
- I** Drip/Dust-Resistant Cable Access Ports (6)
- J** Heavy-Duty Industrial Casters (4)
- K** Heavy-Duty Levelers (4)
- L** Seismic Floor Brackets (2)
- M** Integrated Baying Tabs (2)
- N** Keys (For doors and side panels.)

Also Includes: Documentation, fan power cords (3) and rackmount equipment mounting hardware (50 cage nuts, 50 mounting screws, 50 nylon cup washers).

Also Available: Shock pallet model (SR42UBEISSP1) supports equipment pre-installation and reshipment to final site. Reinforced shock pallet holds up to 1250 lb (567 kg), including the weight of the enclosure and pre-installed equipment.

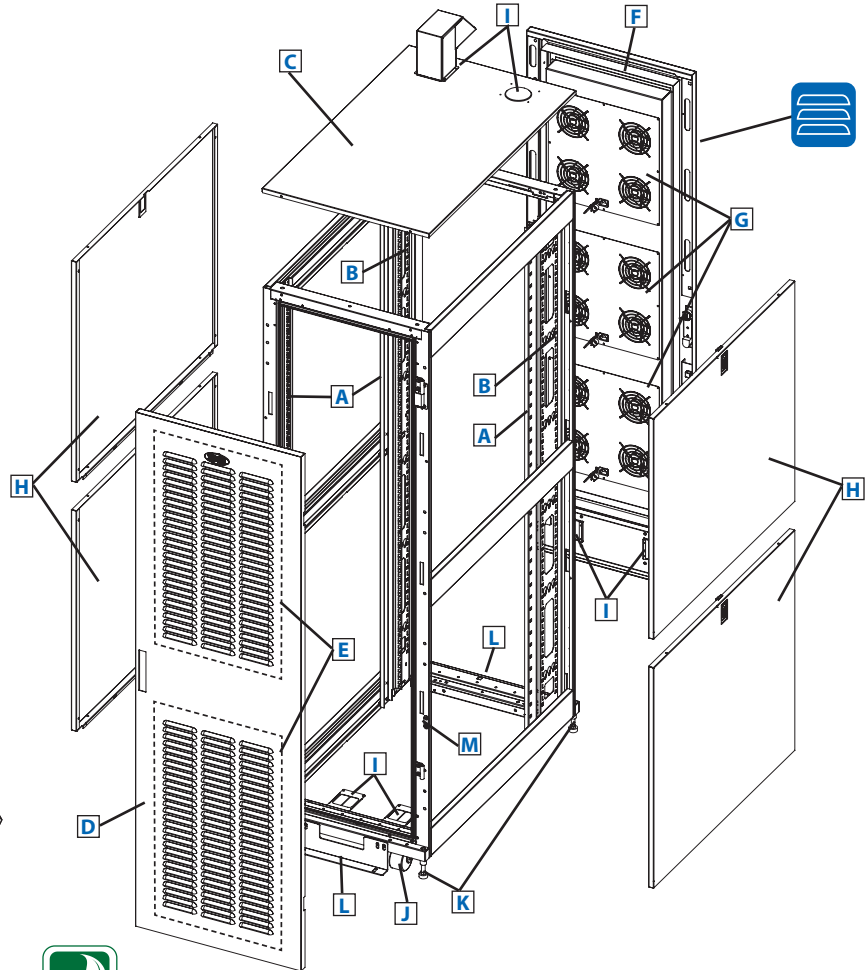

### Specifications

Model	SR42UBEIS
Rack Spaces	42U
Stationary Load Rating	3000 lb (1361 kg)
Rolling Load Rating	3000 lb (1361 kg)
Unit Dimensions (H x W x D)	79.8 x 23.63 x 43 in (2027 x 600 x 1092 mm)
Shipping Dimensions (H x W x D)	86.5 x 26 x 45 in (2197 x 660 x 1143 mm)
Unit Weight	310 lb (140.6 kg)
Shipping Weight	352 lb (159.7 kg)
Certifications	NEMA 12 (IP54), Seismic Zone 4 (NEBS Telcordia/Bellcore GR-63-CORE), TIA/EIA-310-D, EIA/ECA-310-E, IEC 60297-3-100, DIN 41494, UL 60950, NOM, RoHS

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.


- **NEMA 12 (IP54) Protection Rating:** Sealed, locking rack enclosure cabinet protects against dust, falling dirt, drips and splashes.
- **Zone 4 Seismic Rating:** Heavy-duty, torsion-resistant construction meets seismic requirements for the strongest earthquake zones.

**SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS**




1111 W. 35th Street  
Chicago, IL 60609 USA  
773.869.1234  
www.tripplite.com




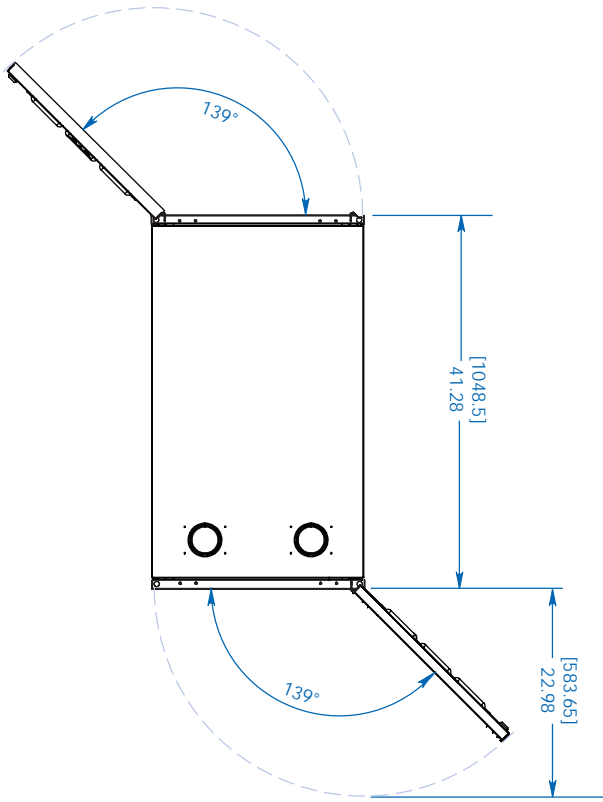

TOP VIEW

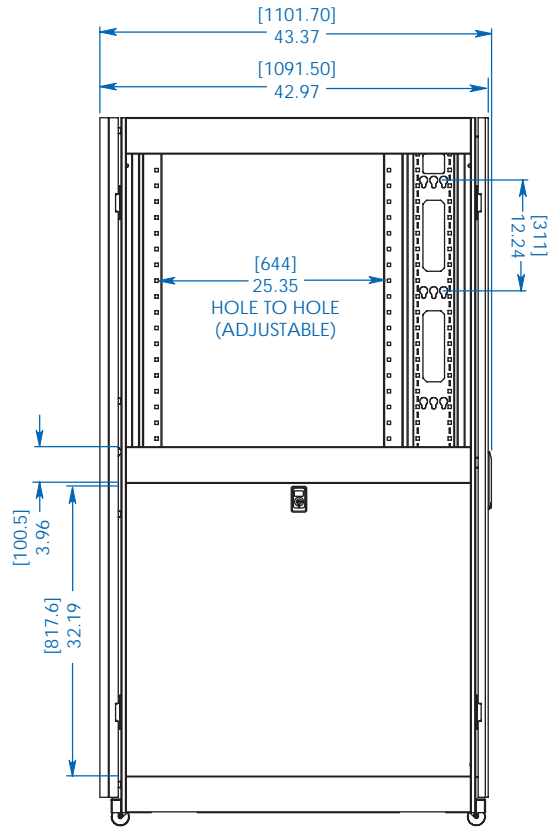


SIDE VIEW

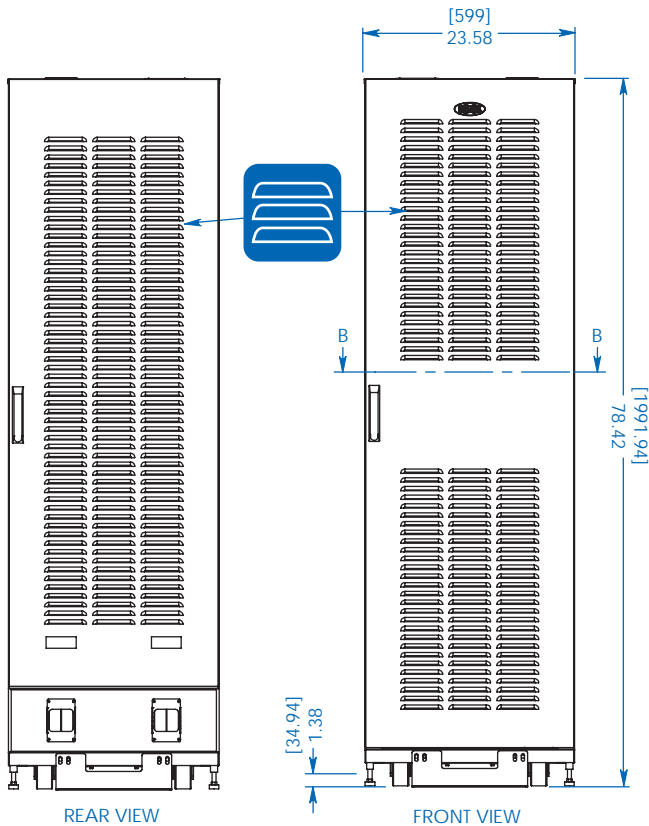

REAR VIEW

FRONT VIEW

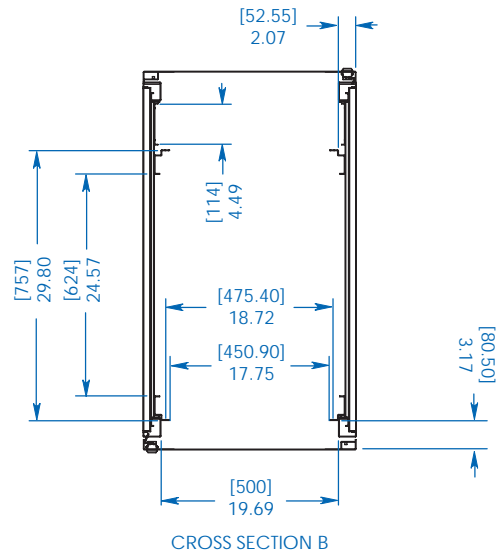


CROSS SECTION B

Dimensions: [mm] INCHES


Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:  
SR42UBEIS




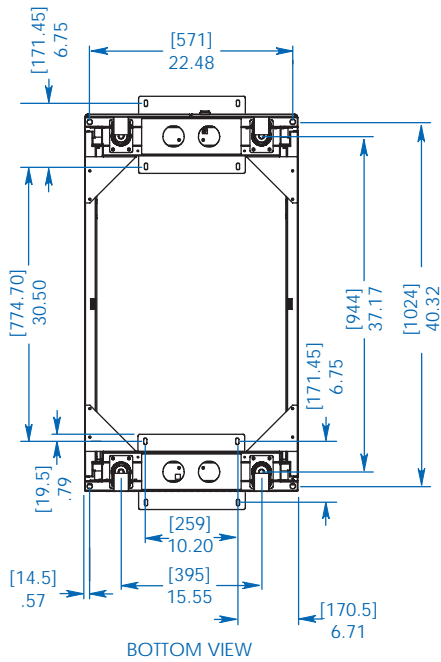


BOTTOM VIEW

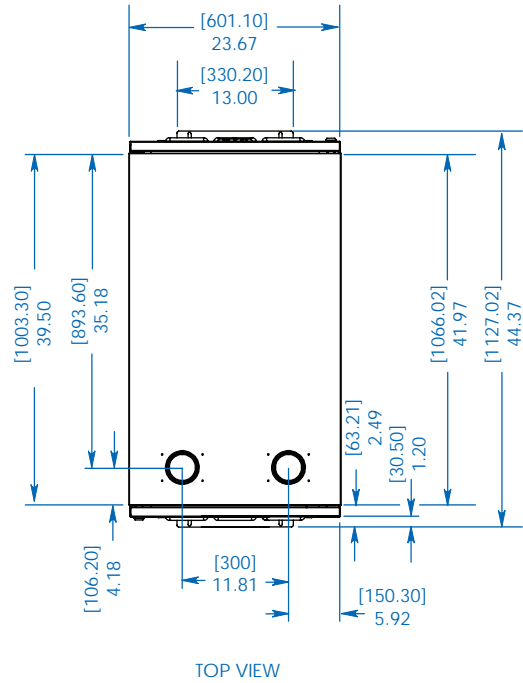


TOP VIEW

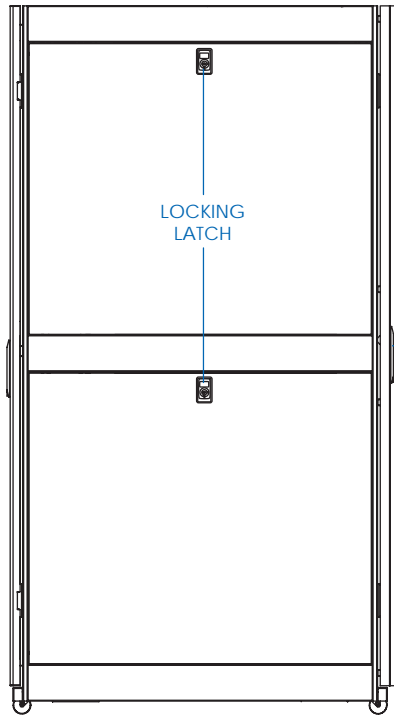

SIDE VIEW

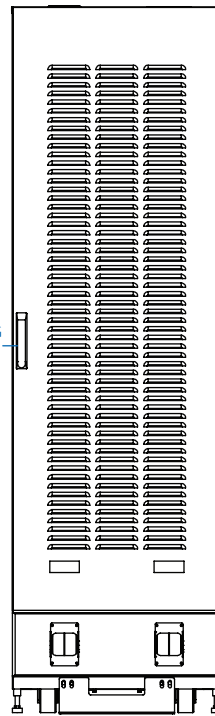

REAR VIEW

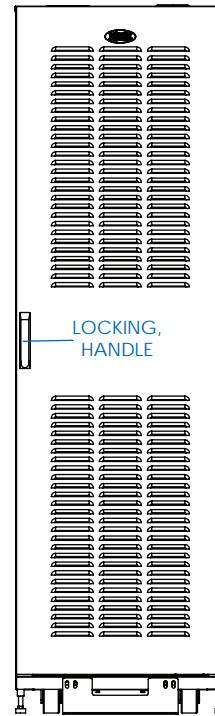

FRONT VIEW

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:  
**SR42UBEIS**



1111 W. 35th Street  
Chicago, IL 60609 USA  
773.869.1234

[www.tripplite.com](http://www.tripplite.com)