

MODEL:

SR4POST1224

SmartRack® Open Frame Rack with Threaded (12-24) Mounting Holes



45 Rack Units



1000 lb
Stationary
Load Capacity



Standard 19-inch
Rack Width



 
Toolless
Mounting Slots



Adjustable
Rails with Easy-View
Depth Index




Integrated
Baying Tabs



Threaded (12-24)
Mounting Holes

- A** Adjustable Mounting Rails (4)
- B** Toolless Button Holes
(for vertical PDUs or cable managers)
- C** Threaded (12-24) Mounting Holes

Also Includes: Owner's manual, installation hardware, rackmount equipment mounting hardware (50 screws, 50 washers) and cable management hooks.

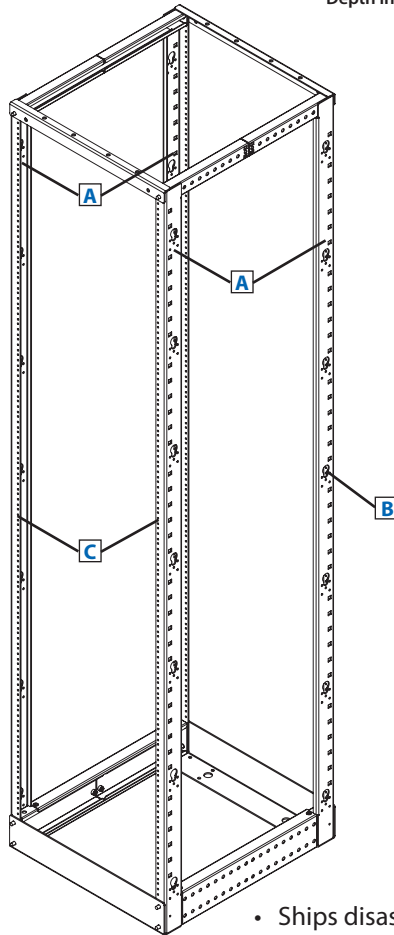

- Ships disassembled for easy transport and assembly in tight spaces
- Modular design optimized for quick configuration and reconfiguration
- Threaded (12-24) mounting holes enable fast equipment mounting
- Multiple units can be bolted together side by side
- Ideal for cost-conscious 19-inch rackmount applications

Specifications

Model	SR4POST1224
Rack Spaces	45U
Stationary Load Capacity	1000 lb (453.6 kg)
Unit Dimensions (H x W x D)	84.29 x 20.28 x 22-39.4 in (2141.01 x 515 x 558.8-1000.7 mm) (adjustable depth)
Shipping Dimensions (H x W x D)	6 x 4 x 85 in (152.4 x 101.6 x 2159 mm)
Unit Weight	69 lb (31.29 kg)
Shipping Weight	70 lb (31.5 kg)
Regulatory Compliance	Meets EIA-310-D, NOM (Mexico), IEC 60297-3-100, DIN 41494 and RoHS standards


Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.




SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS




1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

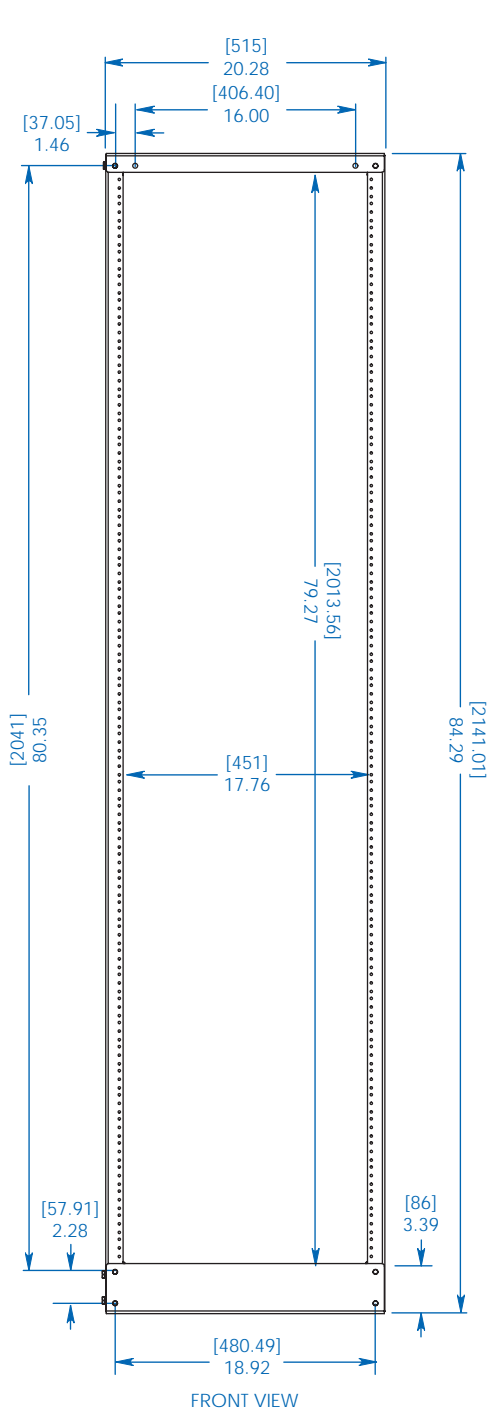

FRONT VIEW

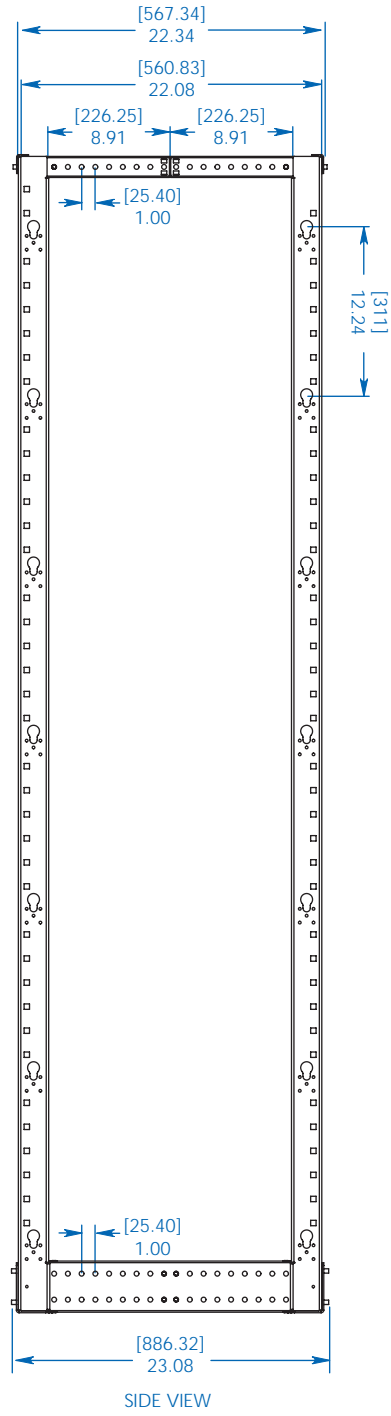

SIDE VIEW

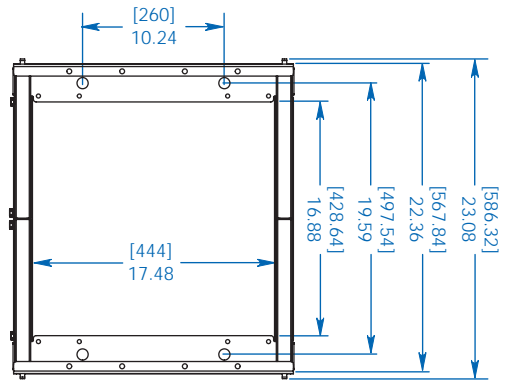

TOP VIEW

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:
SR4POST1224

1111 W. 35th Street
 Chicago, IL 60609 USA
 773.869.1234
 www.tripplite.com