

MODEL:

SR4POST13

13U SmartRack® Open Frame Rack



13 Rack Units



1000 lb
Stationary
Load Capacity



Standard 19-inch
Rack Width



 
Toolless
Mounting Slots



Adjustable
Rails with Easy-View
Depth Index




Integrated
Baying Tabs



Square Hole
Mounting

- A** Adjustable Mounting Rails (4)
- B** Toolless Button Holes
(for vertical PDUs or cable managers)

Also Includes: Owner's manual, installation hardware, rackmount equipment mounting hardware (16 cage nuts, 16 screws, 16 washers) and cable management hooks.

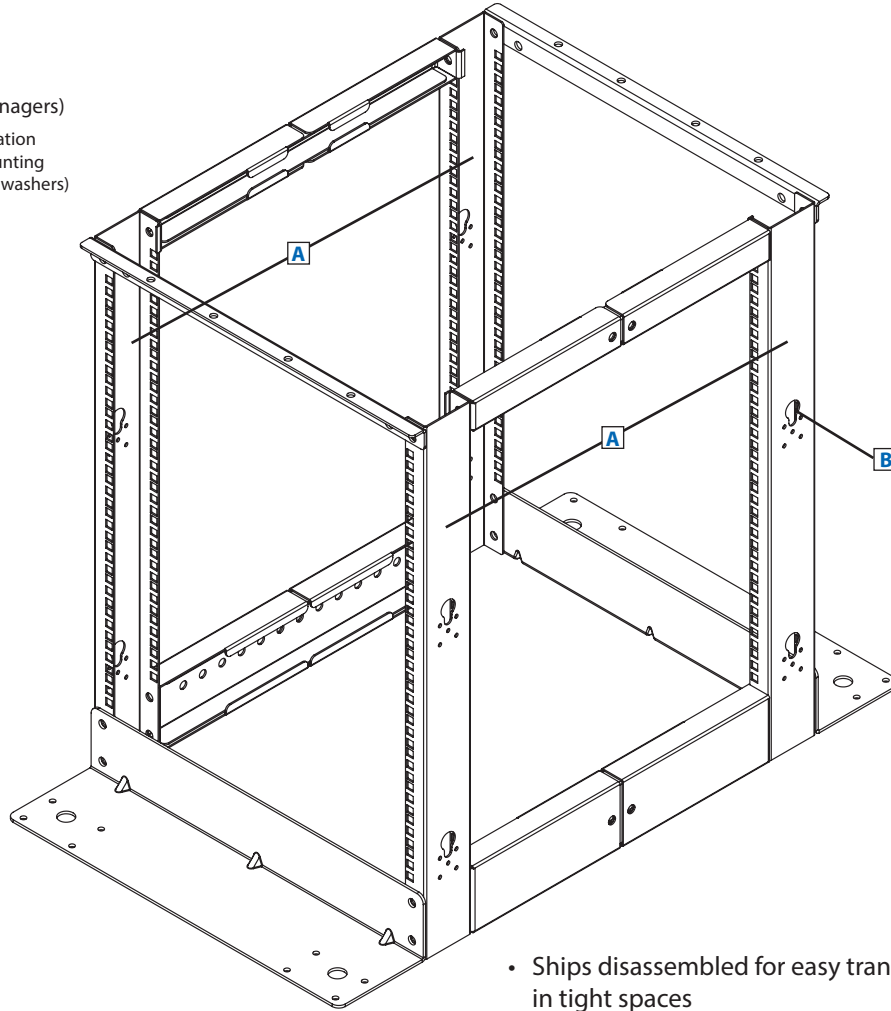

- Ships disassembled for easy transport and assembly in tight spaces
- Modular design optimized for quick configuration and reconfiguration
- Multiple units can be bolted together side by side
- Ideal for cost-conscious 19-inch rackmount applications in up to 13U rack space



Specifications


Model	SR4POST13
Rack Spaces	13U
Stationary Load Capacity	1000 lb (453.6 kg)
Unit Dimensions (H x W x D)	28.02 x 20.31 x 34.29 in (711.71 x 516 x 871 mm) (adjustable depth)
Shipping Dimensions (H x W x D)	4.13 x 5.71 x 43.3 in (105 x 145 x 1099.8 mm)
Unit Weight	39 lb (17.55 kg)
Shipping Weight	40 lb (18 kg)
Regulatory Compliance	Meets EIA-310-D, NOM (Mexico), IEC 60297-3-100, DIN 41494, RoHS standards

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.


SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS




1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

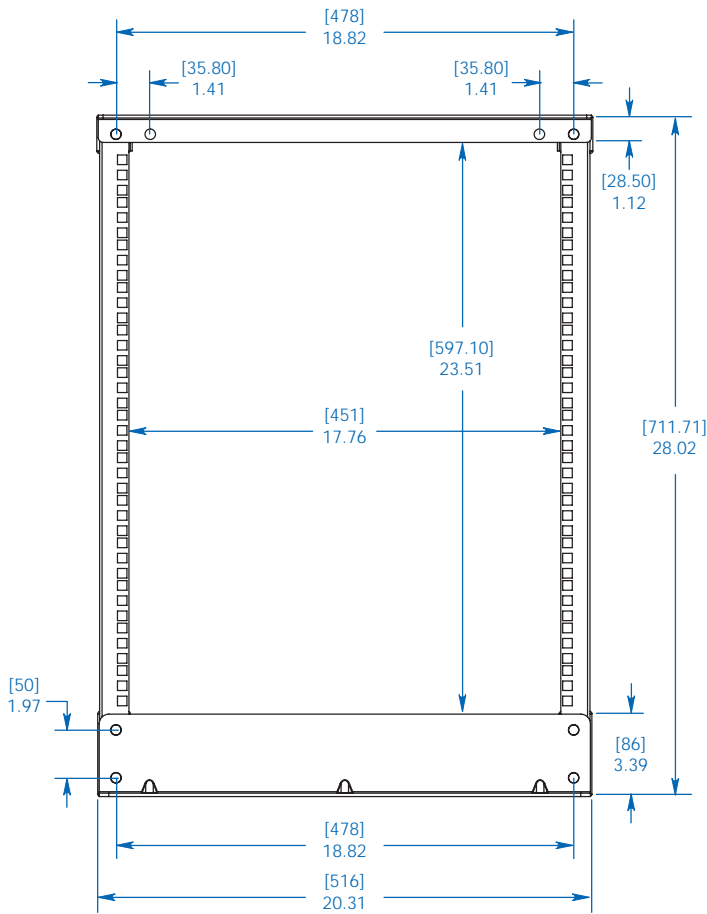

FRONT VIEW

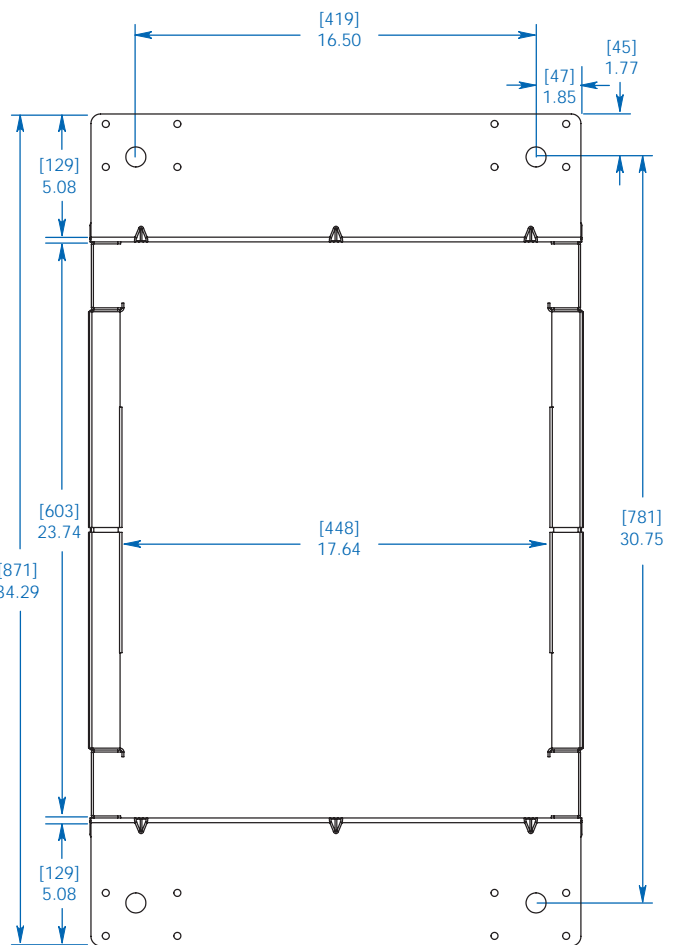

TOP VIEW

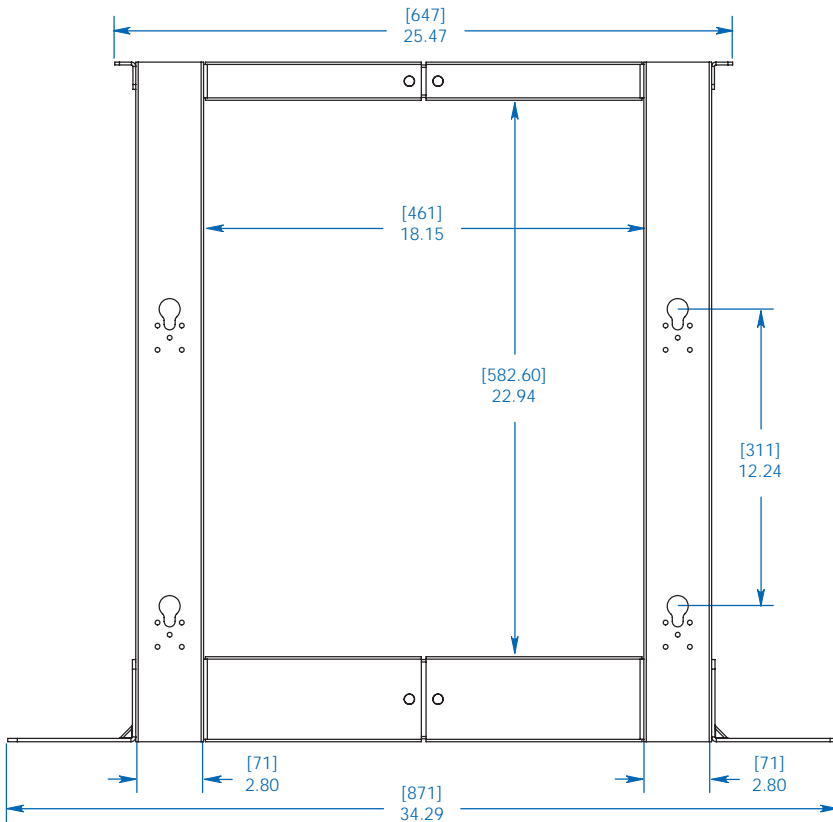

SIDE VIEW

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:
SR4POST13
TRIPP·LITE

1111 W. 35th Street
 Chicago, IL 60609 USA
 773.869.1234
 www.triplite.com