

MODEL:

# SR4POST25

## 25U SmartRack® Open Frame Rack



25 Rack Units



1000 lb  
Stationary  
Load Capacity



Standard 19-inch  
Rack Width



 
Toolless  
Mounting Slots



Adjustable  
Rails with Easy-View  
Depth Index




Integrated  
Baying Tabs



Square Hole  
Mounting

- A** Adjustable Mounting Rails (4)
- B** Toolless Button Holes  
(for vertical PDUs or cable managers)

Also Includes: Owner's manual, installation hardware, rackmount equipment mounting hardware (32 cage nuts, 32 screws, 32 washers) and cable management hooks.

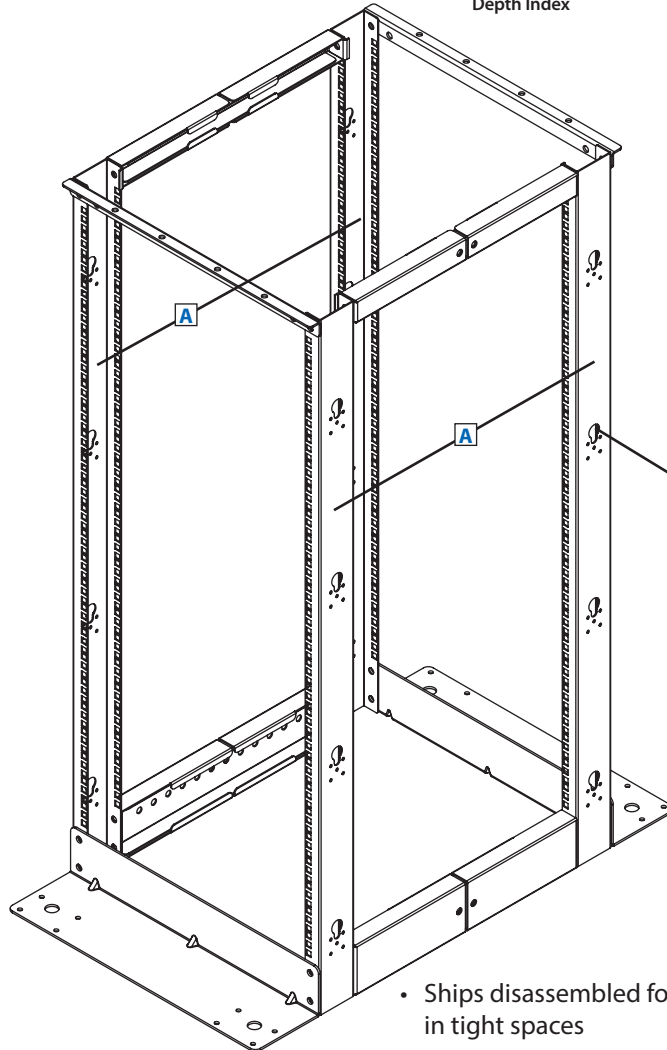

- Ships disassembled for easy transport and assembly in tight spaces
- Modular design optimized for quick configuration and reconfiguration
- Multiple units can be bolted together side by side
- Ideal for cost-conscious 19-inch rackmount applications in up to 25U rack space

### Specifications

Model	SR4POST25
Rack Spaces	25U
Stationary Load Capacity	1000 lb (453.6 kg)
Unit Dimensions (H x W x D)	49.3 x 20.2 x 22-39.3 in (1252.2 x 513.x 558.8-998.2 mm) (adjustable depth)
Shipping Dimensions (H x W x D)	4.1 x 5.7 x 56.5 in (104.9 x 145 x 1435.1 mm)
Unit Weight	45 lb (20.25 kg)
Shipping Weight	46 lb (20.7 kg)
Regulatory Compliance	Meets EIA-310-D, NOM (Mexico), IEC 60297-3-100, DIN 41494 and RoHS standards


Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.




SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS




1111 W. 35th Street  
Chicago, IL 60609 USA  
773.869.1234  
www.tripplite.com

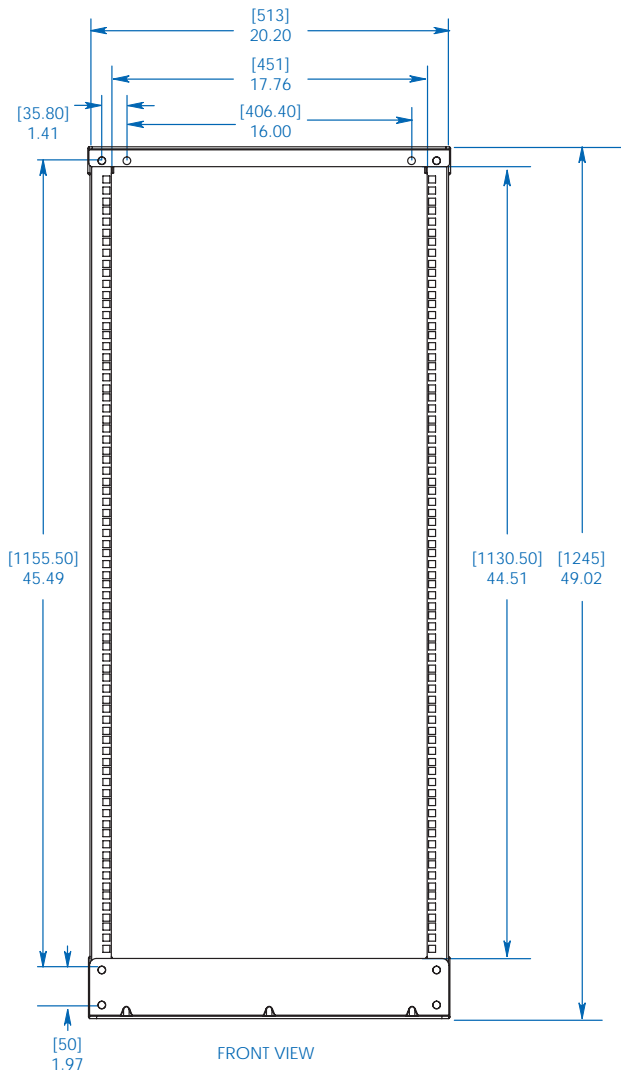

FRONT VIEW

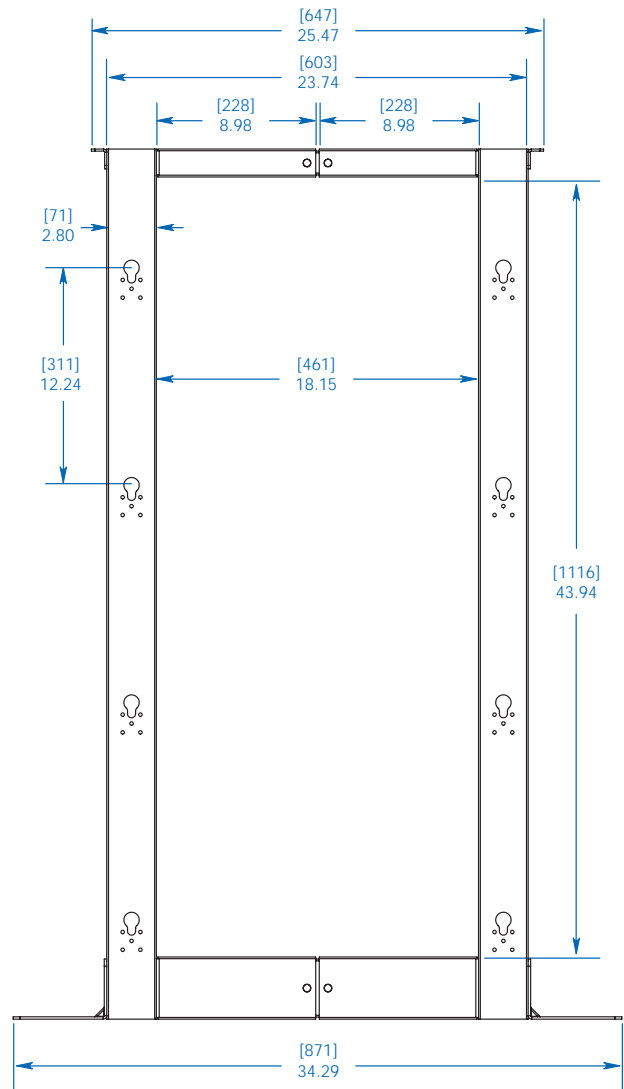

SIDE VIEW

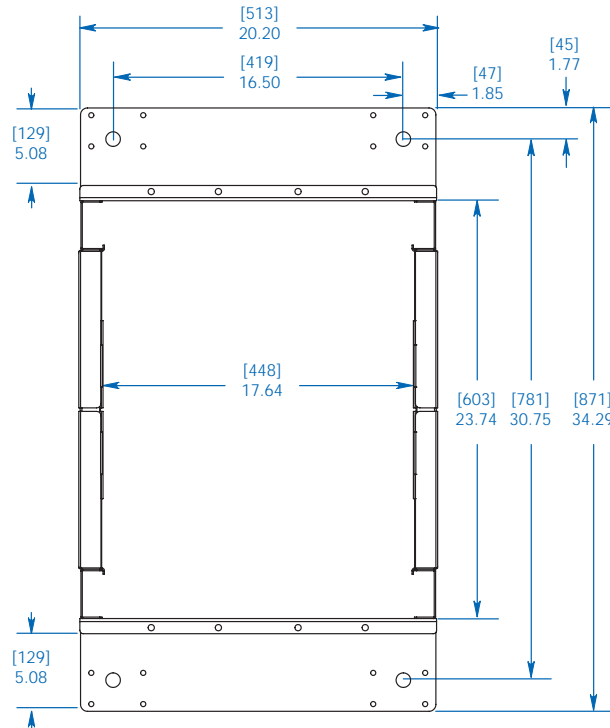

TOP VIEW

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:  
**SR4POST25**  
**TRIPP·LITE**

1111 W. 35th Street  
Chicago, IL 60609 USA  
773.869.1234  
[www.tripp-lite.com](http://www.tripp-lite.com)