



MODEL:

SRSHELF2PX2

2U Cantilever Fixed Shelves for 2-Post Racks

- A** 2U Height
- B** 18-inch Depth Per Shelf (Combined 36-inch Depth)
- C** Slotted Air Vents
- D** Cold-Rolled Steel Construction

x2

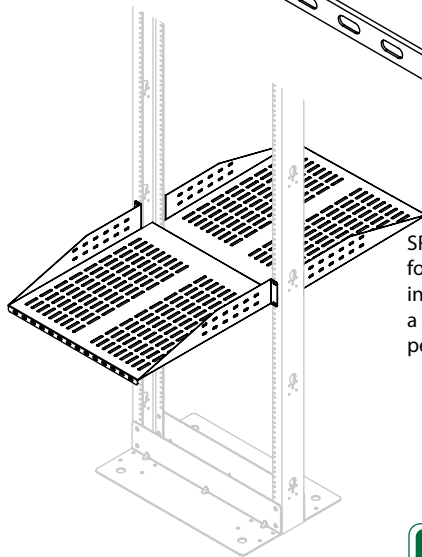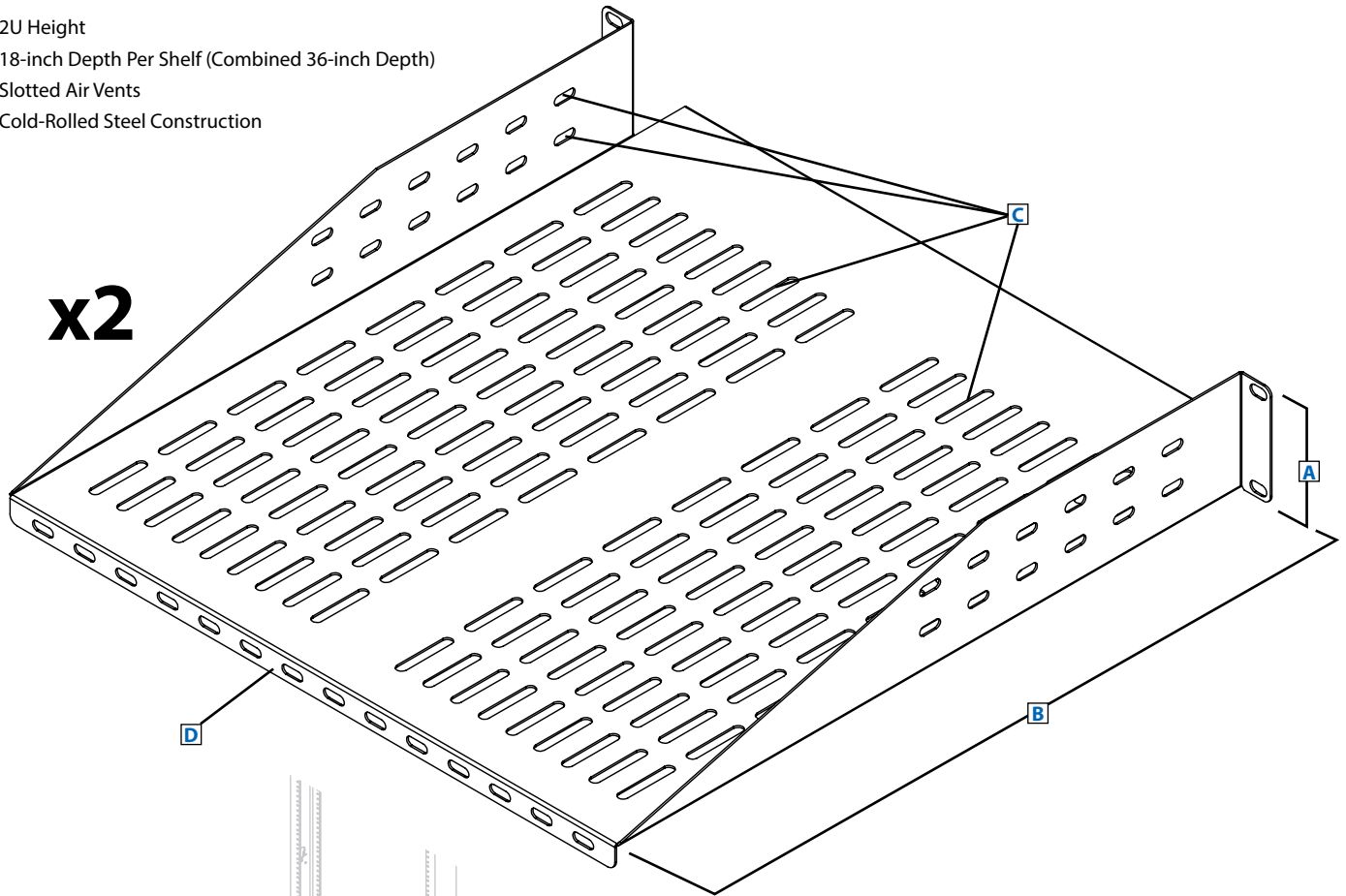

SRSHELF2PX2 is a double-sided, 2U fixed shelf for use in 2-post racks. Each individual shelf is 18 inches in depth (for a combined 36-inch depth as a single shelf) and supports weights of up to 60 lb. per shelf. Includes mounting hardware.

Specifications

Model	SRSHELF2PX2
Load Rating	60 lb. (27 kg)
Unit Dimensions per Shelf (H x W x D)	3.5 x 19 x 19.25 in. (890 x 482 x 489 mm)
Shipping Dimensions (H x W x D)	4.75 x 20 x 21 in. (120 x 508 x 533 mm)
Total Unit Weight	12 lb. (2.72 kg)
Shipping Weight	13.25 lb. (6.01 kg)
Standards	Tested to RoHS




Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.



SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS



1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

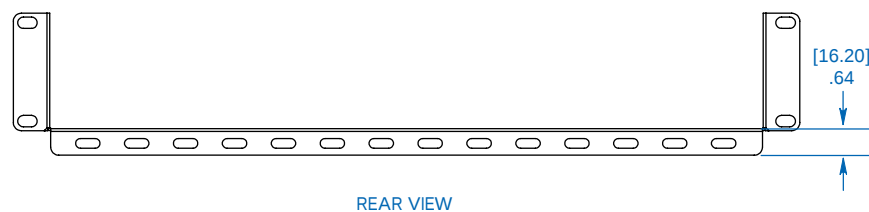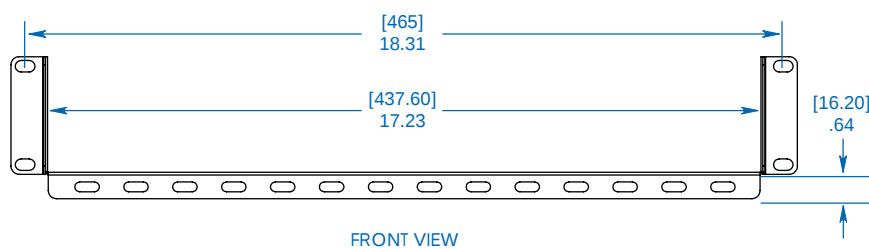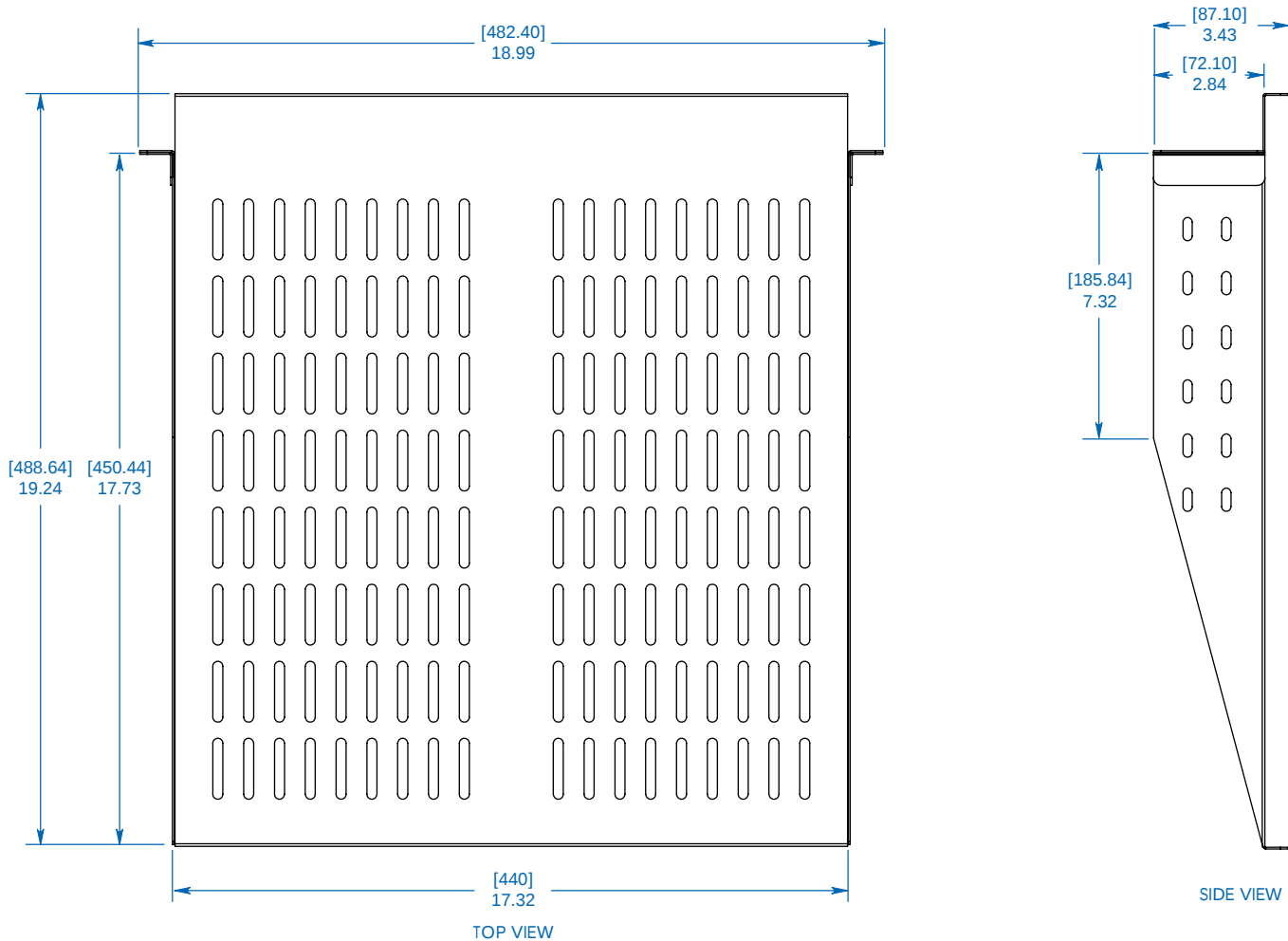

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:
SRSHELF2PX2

TRIPP·LITE

1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com