

MODEL:

SRW12UHD

SmartRack® Heavy-Duty, Side-Mounting Wall-Mount Rack Enclosure Cabinet



12 Rack Units



500 lb
Load Rating



Sturdy Steel
Construction



Locking
Doors
& Side Panels



Fits Full-Depth
Network
Equipment



Standard
19" Rack
Width



24" Low-Profile
Side Mounting



Convenient
Cable Access



Adjustable
Mounting Rails




Ventilated for
Ample Airflow



Square Hole
Mounting

- A** Front Panel
(Lockable/Removable)
- B** Adjustable Mounting Rails (4)
- C** Side Doors (2)
(Lockable/Removable)
- D** Wall Mount Keyhole Slots (6)
- E** Cable Access Port Covers (4)
(Removable)
- F** Ventilation Fan Ports (8)
(Support optional SRFANWM fan kit.)
- G** Keys (2)

Also Includes: Owner's manual, cabinet ground screw, pre-installed side door ground wire and rackmount equipment mounting hardware (20 cage nuts, 20 mounting screws, 20 nylon cup washers, 20 #12-24 equipment screws).

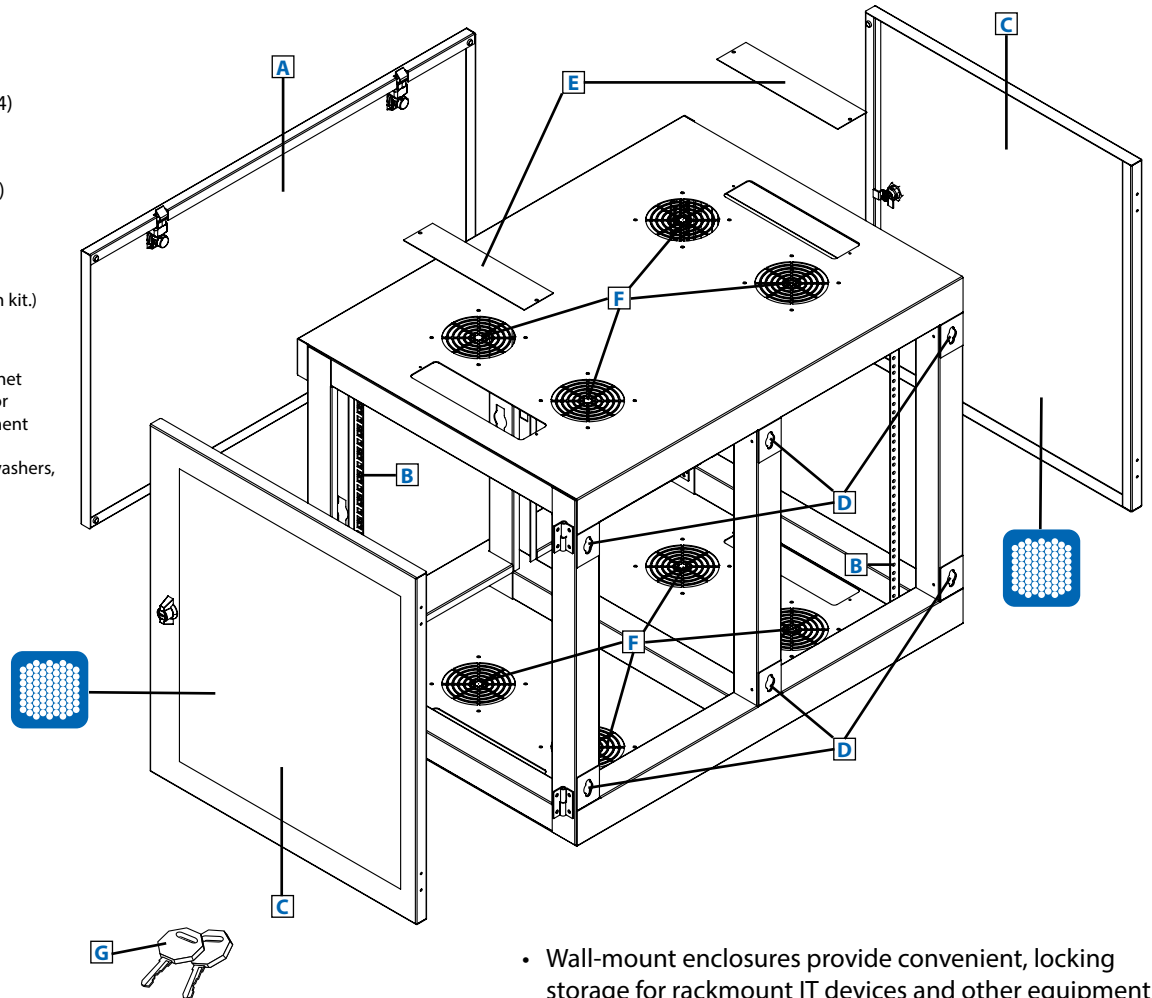

- Wall-mount enclosures provide convenient, locking storage for rackmount IT devices and other equipment that should be off the floor, out of the way and secure
- Accommodates 29"-31" full-depth server equipment in limited-space applications
- Sideways wall mount design creates a low profile (24") and provides sufficient leverage for heavy equipment

SEE NEXT PAGE FOR DETAILED UNIT MEASUREMENTS


Specifications

Models	SRW12UHD
Rack Spaces	12U
Equipment Mounting Depth	Up to 32.5 in. (826 mm)
Load Rating*	500 lb (181 kg)
Unit Dimensions (H x W x D)	26.5 x 36.2 x 24.8 in. (672 x 920 x 629 mm)
Shipping Dimensions (H x W x D)	28 x 26 x 38 in. (711 x 660 x 965 mm)
Unit Weight	101.4 lb (46 kg)
Shipping Weight	119 lb (54 kg)
Standards	Meets EIA-310-E, NOM, RoHS standards


* The load rating includes the combined weight of the unit and installed equipment. The unit must be mounted to a stable surface with user-supplied anchors capable of bearing the full load. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.




1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

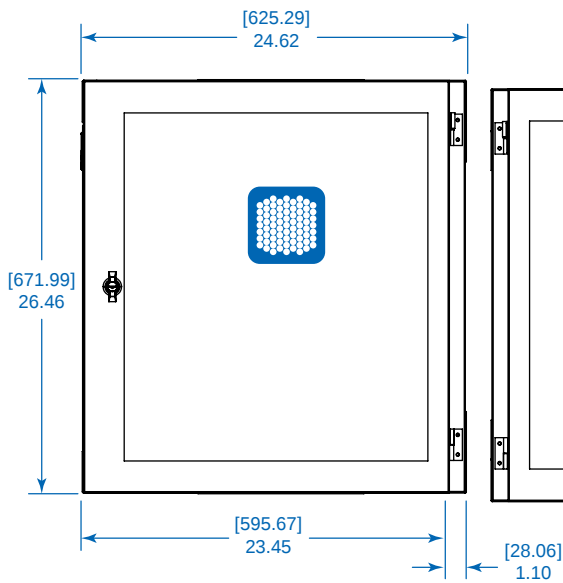


SIDE VIEWS

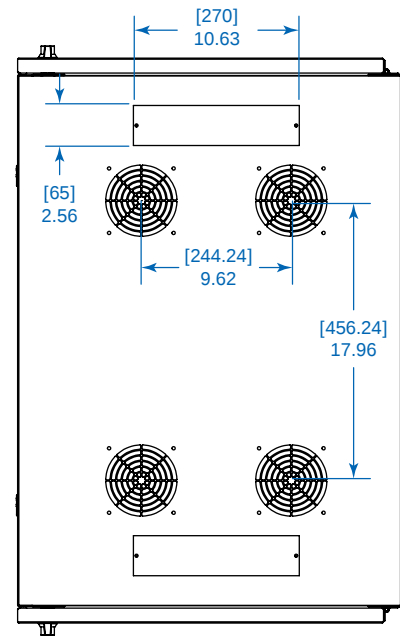

TOP/BOTTOM VIEW

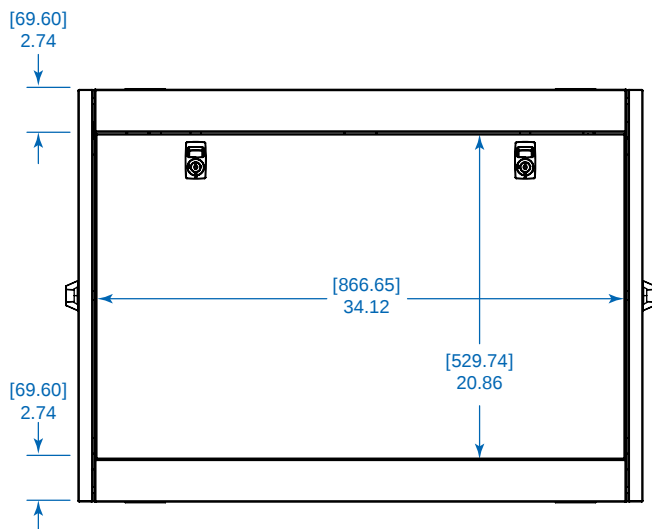

FRONT VIEW

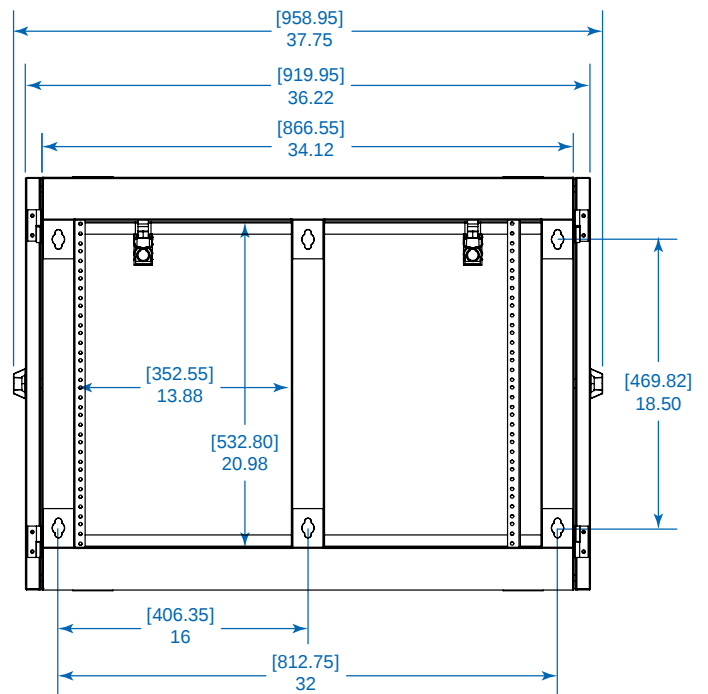


BACK VIEW

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:
SRW12UHD
TRIPP·LITE

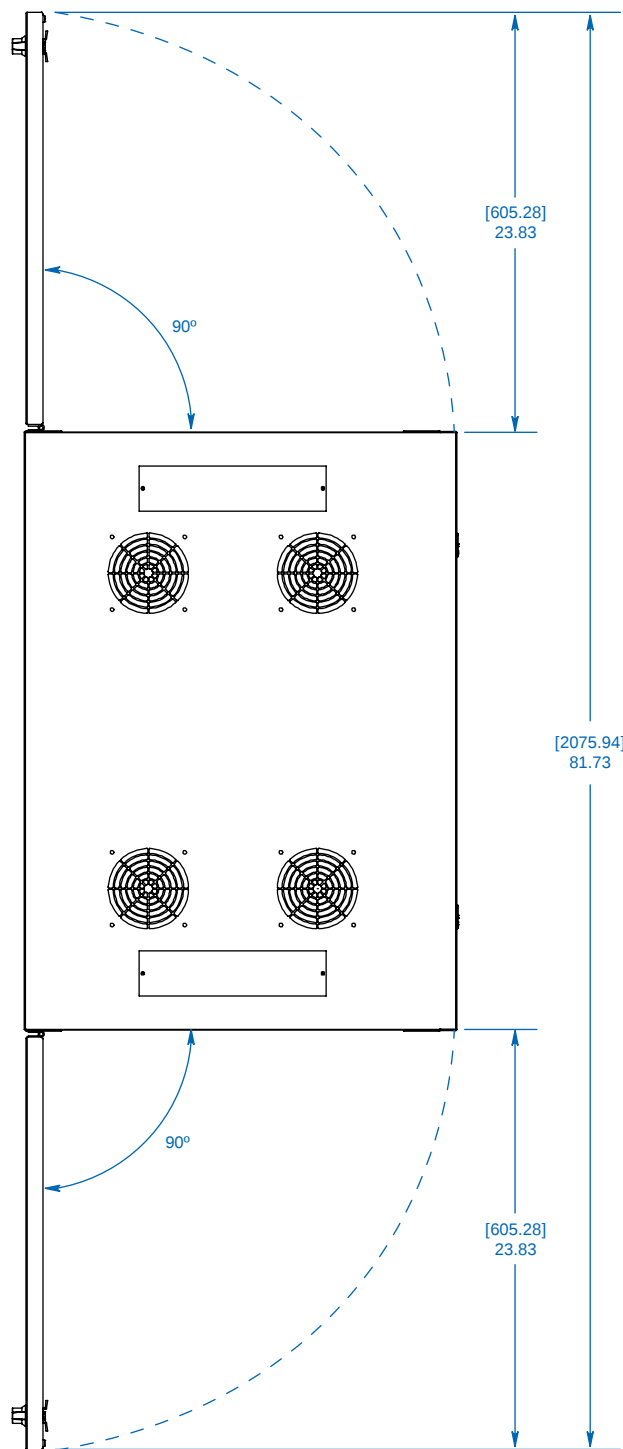

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

MODEL:
SRW12UHD
TRIPP·LITE

1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com