

MODEL:

SRW12USNEMA

SmartRack® NEMA 12-Rated Industrial Wall-Mount Rack Enclosure



12 Rack Units



200 lb
Stationary
Load Capacity



Locking Front
Door & Side Panels



Standard 19-inch
Rack Width



Removable Dust
Filter



High-Performance
Fans



Hinged
Back Panel




Airflow Exceeds
Server OEM
Requirements



Square Hole
Mounting

- A** Locking, Reversible Front Door
- B** Built-In, Removable Dust Filter
- C** High-Performance Fans
- D** Adjustable Mounting Rails
- E** Locking, Removable Side Panels
- F** Ventilating Louvers
- G** Hinged Back Panel
- H** Cable Routing Ports
- I** Keys
(For doors and side panels)


Also includes: owner's manual, rackmount equipment mounting hardware (20 cage nuts, 20 mounting screws, 20 nylon cup washers) and 1 removable/replaceable dust filter.

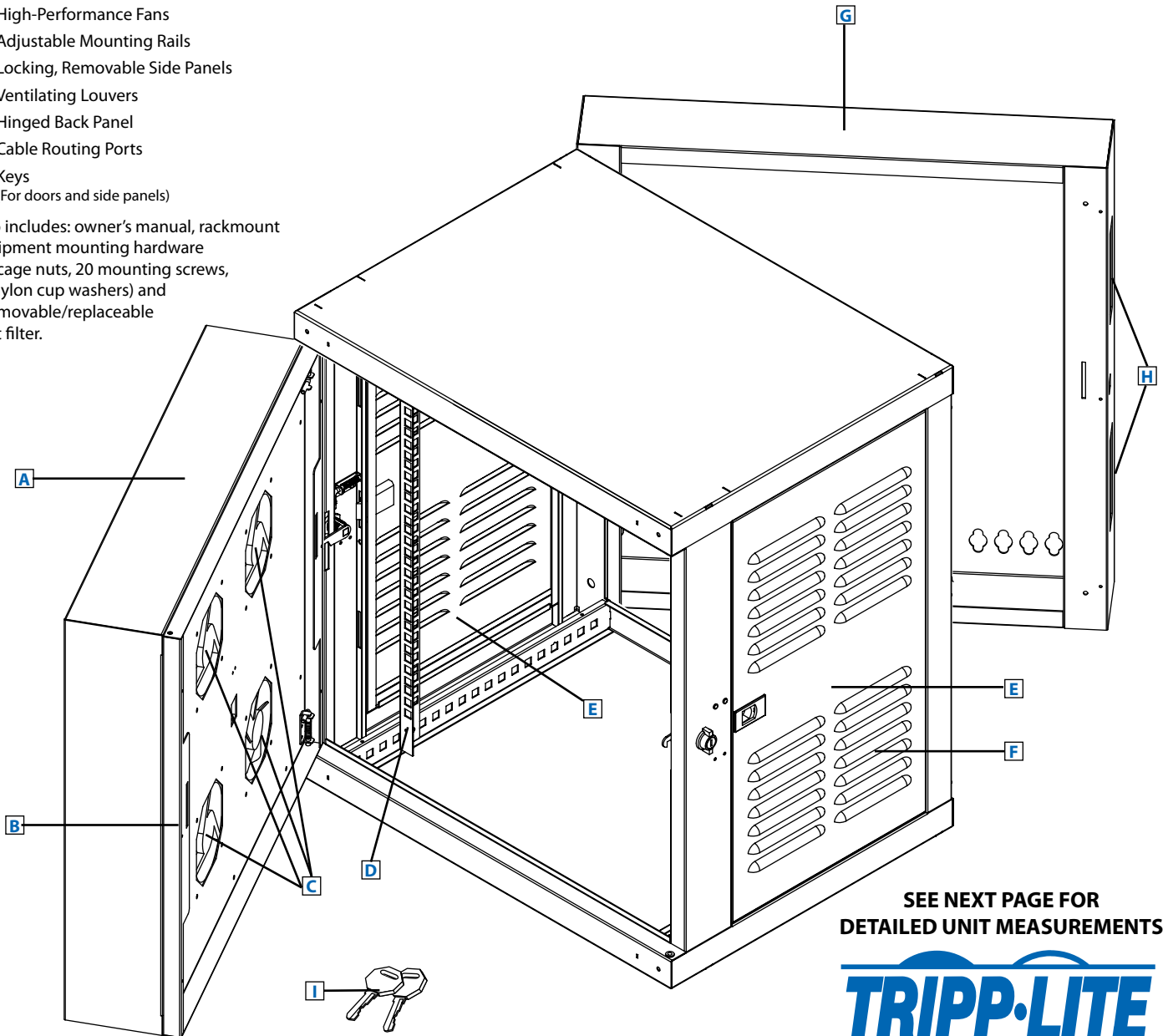


SEE NEXT PAGE FOR
DETAILED UNIT MEASUREMENTS




1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.tripplite.com

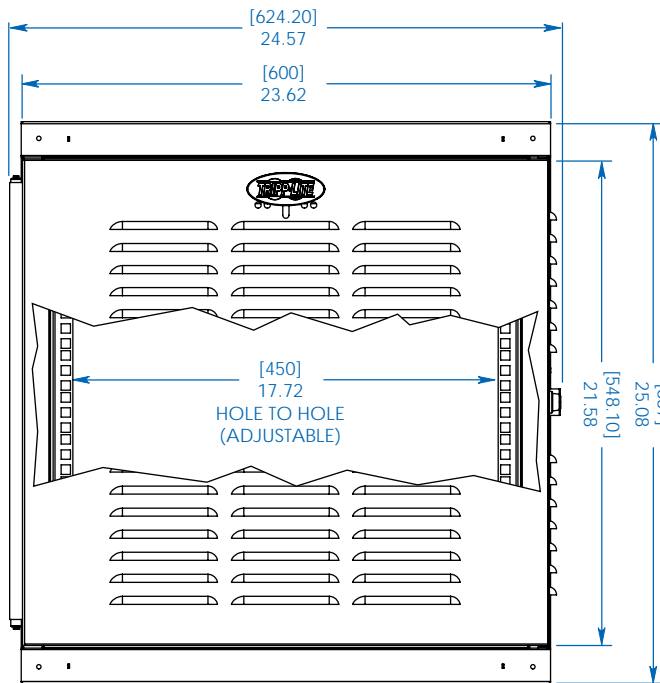


FRONT VIEW

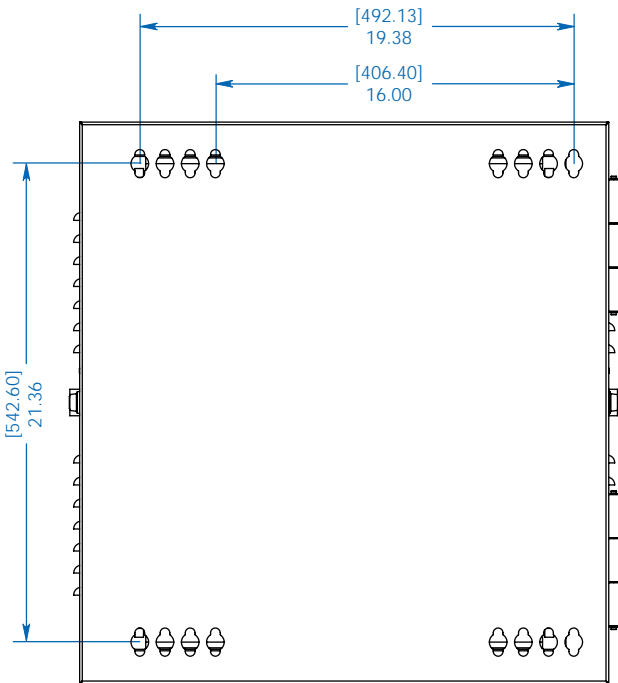

REAR VIEW

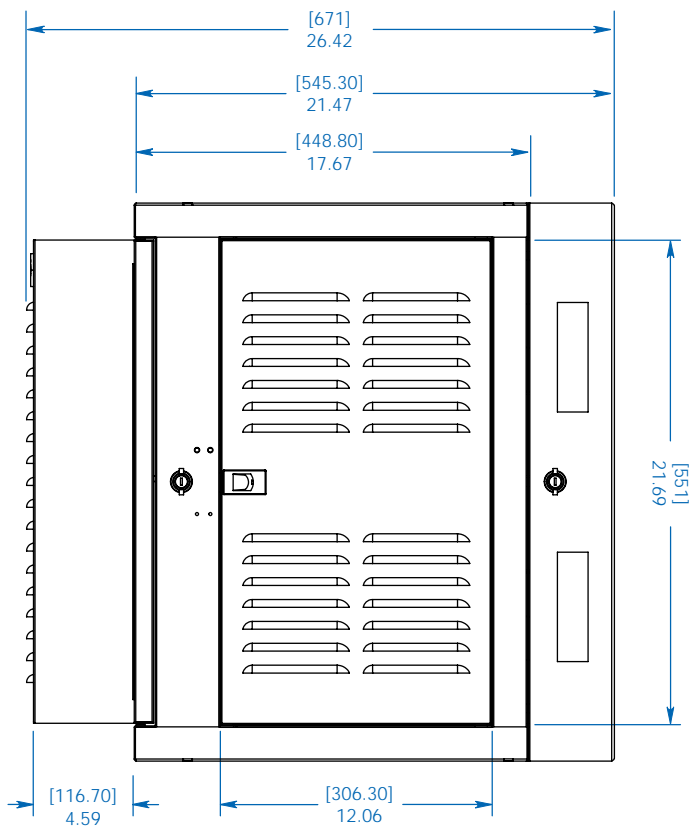

SIDE VIEW

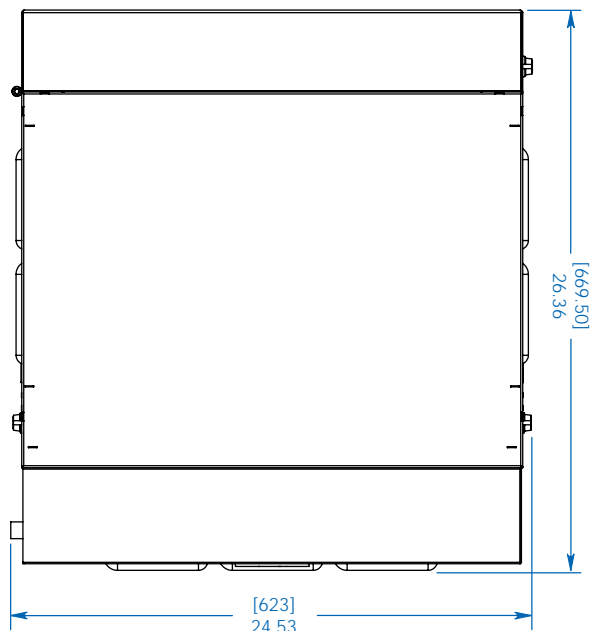

TOP VIEW

MODEL:

SRW12USNEMA



1111 W. 35th Street
Chicago, IL 60609 USA
773.869.1234
www.triplite.com

Dimensions: [mm] INCHES

Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.