


# Pole-Mounting Kits

Models 230-001, 231-001 and 232-001

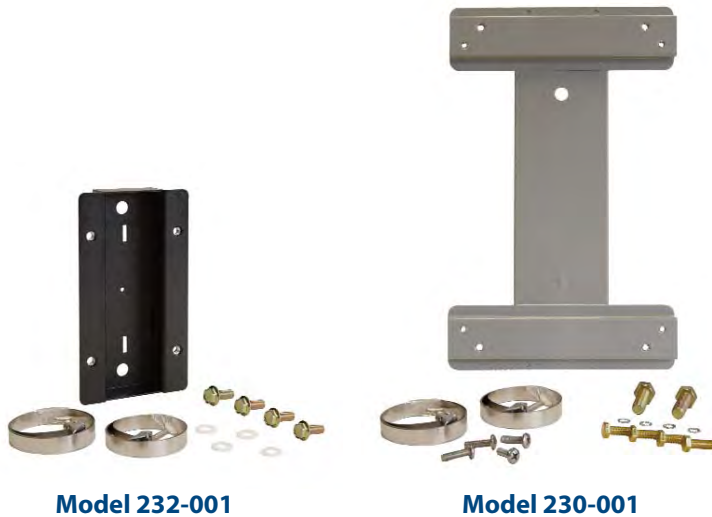

**Model 232-001**

**Model 230-001**

Model 231-001 and 232-001  
utilize captive screw  
mounting holes to  
prevent unauthorized  
removal of equipment.



**Model 231-001**

GAI-Tronics Pole Mount brackets provide a suitable mounting surface for a variety of pole shapes. The universal bands are capable of securing the bracket to poles that are between 2.5 inches and 15 inches in diameter.

For additional support or for poles less than five inches in diameter, center mounting holes are provided for lag or machine bolts. These holes can also be utilized to surface-mount a telephone using only two lag bolts (surface mounting a telephone typically requires four bolts)

All pole mount brackets are manufactured using 14-gauge cold-rolled steel with a gray polyurethane finish. The banding straps are 0.012 inch x 0.5 inch stainless steel.

## POLE MOUNT KIT GUIDE

GAI-Tronics Model	230-001	231-001	232-001
226-001   226-005 Rugged Industrial Telephone			•
227-001   227-005 Rugged Auto-dial Telephone			•
246-001   246-005 Industrial Telephone		•	
255-003 Series NEMA 4X Enclosures	•		
256-001   256-005 Industrial Telephone (Weatherproof)	•		
261-001 Intrinsically-Safe Telephone		•	
271-001 Weatherproof Intrinsically-Safe Telephone	•		
351-001 Division II Telephone (Weatherproof)	•		
354-001 Series NEMA 4X Telephones	•		
393-00x RED ALERT® Emergency Telephones		•	
394AL-00x RED ALERT® Emergency Telephones		•	
13353 / 13363 / 13373 Addressable Amplified Speakers		•	
XB001 Long-Life Battery Enclosure	•		

# Strobe Mounting Bracket Assembly

Model 4115A




The Model **4115A Surface-Mount Strobe Mounting Bracket Assembly** includes the following components:

- Aluminum wall-mounting bracket, 3/4" NPT entrance and exit
- Gasketed access cover with stainless steel screws
- 10" galvanized conduit pipe nipple
- 3/4" NPT, 90° aluminum elbow
- Pipe nipple lock nut



## Strobe Mounting Details

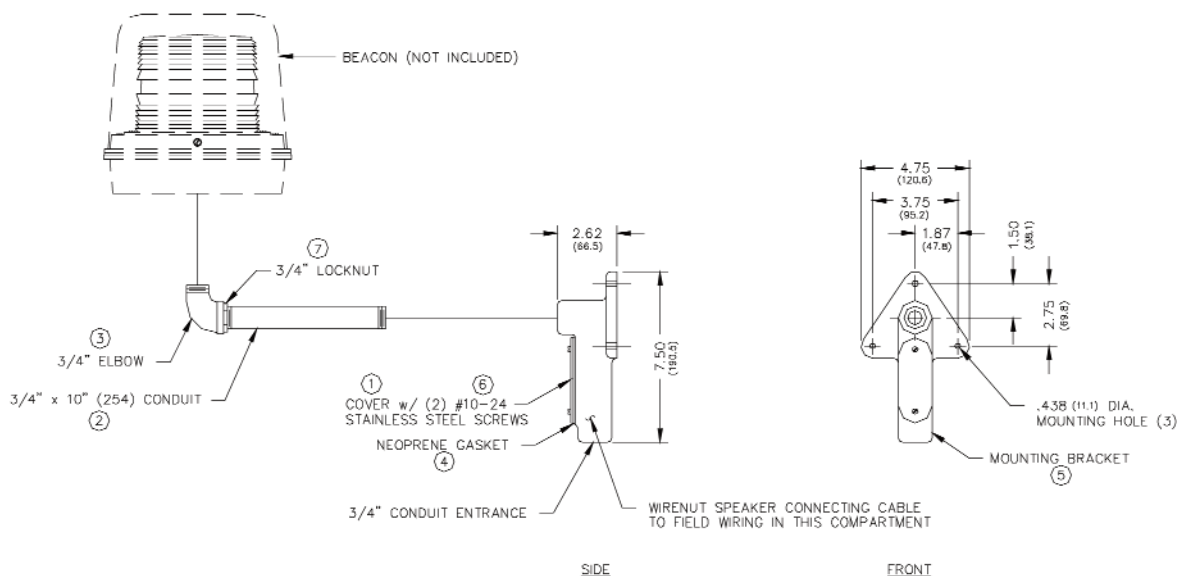

USA Toll Free: 1 (800) 492-1212 Tel: (610) 777-1374 Fax: (610) 796-5954 [www.gai-tronics.com](http://www.gai-tronics.com)  
UK Tel: +44 (0)1283 500500 Fax: +44 (0)1283 500400 [www.gai-tronics.co.uk](http://www.gai-tronics.co.uk)  
Italy Tel: +39 02 48601460 Fax: +39 02 93663110 [www.gai-tronics.it](http://www.gai-tronics.it)  
Malaysia Tel: +60-3-8945-4035 / 8945-7348 Fax: +60-3-8945-4675 [www.gai-tronics.com](http://www.gai-tronics.com)  
Australia Tel: 011-61-28-851-5000 Fax: 011-61-29-899-2490 [www.austdac.com.au](http://www.austdac.com.au)



Quality Management System Certified by DNV - ISO 9001:2008. The policy of GAI-Tronics is one of continuous improvement; therefore the company reserves the right to change specifications without notice.

Pub. 910100 Rev 10/2014