

Fiber Raceway Solid and Slotted Ducting

APPLICATION

Fiber Raceway Solid and Slotted Ducting is designed to route, protect and support cables throughout fiber systems. In addition, raceway can be utilized to support copper systems. Slotted Ducting is ideal for carrying a high volume of cables that need to exit at multiple locations.

SPECIFICATION

Solid and Slotted Ducting shall route, protect, and support cables throughout fiber systems. Ducting shall protect fiber and maintain proper bend radius. Components shall be UL-listed and manufactured of fire retardant material. Ducting shall be mountable above equipment rack, below floor, suspended, or on a wall. The system shall be highly adaptable to support multiple network configurations and be expandable for future configurations.

FEATURES

- Solid Ducting available in four sizes
 - 2" x 2"
 - 4" x 4"
 - 4" x 8"
 - 4" x 12"
- Slotted Ducting available in two sizes
 - 2" x 2"
 - 4" x 4"
- Safely stores and routes optical fiber in an indoor environment
- Ducting and covers are 6.5' long and can be hand-cut to meet exact specifications
- Covers for 2" x 2" Slotted Ducting with Hinged Covers are pre-cut into 8 10" sections before shipping. All other covers are shipped in 6.5' lengths
- Two ducting styles available: Solid wall or slotted for exiting fibers
- Snap-on Covers and Hinged Covers available for Solid Wall Duct and Slotted Duct
- Bend Radius Guides available as necessary to safely route fiber as it exits from the Slotted duct
- Available in yellow, orange, black, and grey



DESIGN CONSIDERATIONS

- Manufactured of Noryl plastic, a halogen-free, low smoke, fire retardant material
- Mounts above equipment rack, below floor, suspended, or wall-mount
- Available in single quantities or bulk packs
- May be utilized to store and route copper cable in an indoor environment. It is recommended that fiber and copper be stored in separate systems

STANDARDS COMPLIANCE

UL 94V-0 Material Rating for Flammability

Meets NEBS GR-63-CORE*

UL 2024A Optical Fiber Raceway, Riser Rated

PHYSICAL SPECIFICATIONS

Dimensions: See page two

Materials: Noryl Plastic


Color: See page two

WARRANTY INFORMATION


For a copy of Leviton product warranties, visit www.leviton.com.

ELECTRONIC FILES

For CAD files, typical specs, or technical drawings (.DXF, .DWG, .VISIO), visit www.leviton.com.

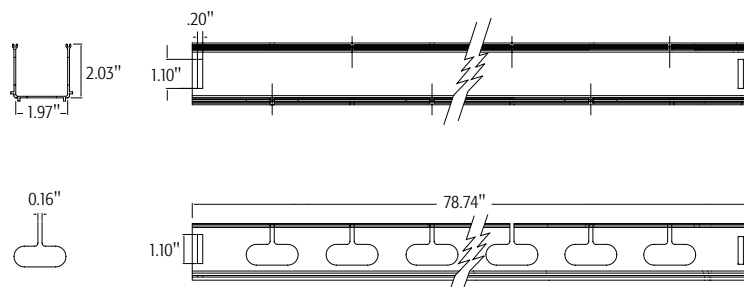

Pictured: S2DCT-DSL
NOTE: Illustrations not to scale

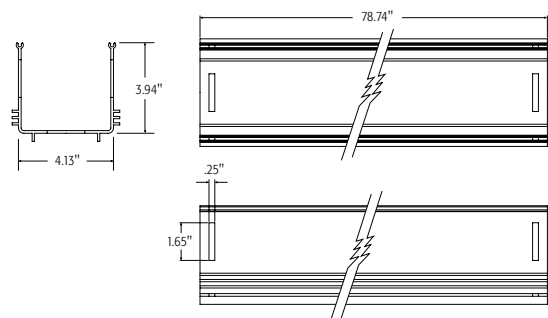

Pictured: S4DCT-SDT
NOTE: Illustrations not to scale

XXDCT-XXX

DUCT DIMENSIONS

Description	2" x 2"	4" x 4"	4" x 8"	4" x 12"
Internal Cross Sectional Area	3.9" ²	14.6" ²	32.1" ²	43.9" ²
Patch Cord Capacity	293	1004	2050	3100
Weight Capacity	22 lbs.	88 lbs.	110 lbs.	126 lbs.

NOTE: Fiber capacities listed are maximum quantities and are based off of cable that is 3.0 mm in diameter. It is recommended that duct be filled to about 50% of its depth with optical fiber to avoid crushing or placing excessive stress on the fiber cable.

DUCTING

Description	2" x 2"	4" x 4"	4" x 8"	4" x 12"
Solid Duct	S2DCT-SDT	*4DCT-SDT	*8DCT-SDT	*WDCT-SDT
Solid Duct and Cover	S2DCT-SDC	*4DCT-SDC	*8DCT-SDC	*WDCT-SDC
Slotted Duct	S2DCT-DSL	*4DCT-DSL		
Solid Duct Hinged Covert	S2DCT-DHC	*4DCT-DHC	*8DCT-DHC	
Slotted Duct Cover	S2DCT-DCS	*4DCT-DCS		
Slotted Duct Hinged Cover		*4DCT-SHC		

Dimensions listed as H x W.

† 2" x 2" Hinged cover is in 8 10" sections only.

2" x 4" and 2" x 8" ducting available by special order.

* = Color: Choose from any of the colors below. Grey is special order and requires additional lead time. 2" x 2" offered in yellow only.



Yellow (S) Orange (O) Black (E) Grey (G)

Contact inside sales at 800.722.2082 to order.

Callers from outside the U.S. and Canada please dial 1.425.486.2222

BULK PACK DUCTING

Description	2" x 2" (5 per carton)	4" x 4" (4 per carton)	4" x 8" (4 per carton)	4" x 12" (4 per carton)
Solid Duct	S2DCT-5DT	*4DCT-4DT	*8DCT-4DT	*WDCT-4DT
Solid Duct & Cover	S2DCT-5DC	*4DCT-4DC	*8DCT-4DC	*WDCT-4DC
Solid Duct & Hinged Cover†	S2DCT-5HC	*4DCT-4HC		
Slotted Duct	S2DCT-5SL	*4DCT-4SL	*8DCT-4HC	
Slotted Duct & Cover	S2DCT-5CS	*4DCT-4CS		
Slotted Duct & Hinged Cover†		*4DCT-SH4		

ACCESSORIES

Description	2" x 2"	4" x 4"	4" x 8"	4" x 12"
Radius Guide (10 Pack) (fit 2"x2" and 4"x4" slotted ducts)	SRAGD-SLT	SRAGD-SLT		
Joiner	S2JNR-SLT	S4JNR-SLT	S8JNR-SLT	
Slotless Joiner		S4JNR-SLS	S8JNR-SLS	SWJNR-SLS

END CAPS

Description	2" x 2"	4" x 4"	4" x 8"	4" x 12"
End Cap, standard		*4END-CAP	*8END-CAP	
End Cap, slotless		*4END-CSL	*8END-CSL	*WEND-CSL
End Cap, Two 0.75" diameter knockouts	S2END-20D			
End Cap, One 1.5" diameter knockout	S2END-38D			
End Cap, One 1.5" hole	S2END-38H			
End Cap Tube Outlet for 2" Tube	S2END-OUT			
End Cap, Two 1.75" diameter knockouts		*4END-46D		
End Cap, Two 1.25" diameter knockouts		*4END-32D		

Dimensions listed as H x W.

† 2" x 2" Hinged cover is in 8 10" sections only.

2" x 4" and 2" x 8" ducting available by special order.

* = Color: Choose from any of the colors below. Grey is special order and requires additional lead time. 2" x 2" offered in yellow only.



Yellow (S)



Orange (O)



Black (E)



Grey (G)

Contact inside sales at 800.722.2082 to order. Callers from outside the U.S. and Canada please dial 1.425.486.2222

MOUNTING HARDWARE

Description	Part No.
4" x 4" Wall-Mounting Kit	S4MNT-KIT
4" x 8" Wall-Mounting Kit	S8MNT-KIT
4" x 4" Wall Extension Bracket (up to 10") Mounting Kit	S4EXT-KIT
4" x 8" Wall Extension Bracket (up to 14") Mounting Kit	S8EXT-KIT
2" x 2" Duct Mounting Bracket	S2DMB-000
4" x 4" Duct Mounting Bracket	S4DMB-000
4" x 8" Duct Mounting Bracket	S8DMB-000
4" x 12" Duct Mounting Bracket	SWDMB-000
4" x 4", 4" x 8", and 4" x 12" Retro-Fit Support Bracket (for existing 1/2" threaded rod)	SWRFK-12R
4" x 4", 4" x 8", and 4" x 12" Retro-Fit Support Bracket (for existing 5/8" threaded rod)	SWRFK-58R
4" x 4" Suspension Kit (with 3.3' rod)	S4SUS-KIT
4" x 8" Suspension Kit (with 3.3' rod)	S8SUS-KIT
4" x 12" Suspension Kit (with 3.3' rod)	SWSUS-KIT
4" x 12" Suspension Kit (without rod)	SWSUS-WRD
2" x 2" Raised Mounting Kit (for above or below cabinet)	S1RMK-000
4" x 4" Raised Mounting Kit (for above or below cabinet)	S4RMK-000
4" x 8" Raised Mounting Kit (for above or below cabinet)	S8RMK-000
4" x 12" Raised Mounting Kit (for above or below cabinet)	SWRMK-000
2" x 2" Ladder Rack/Unistrut Mounting Kit	S1LRU-000
4" x 4" Ladder Rack/Unistrut Mounting Kit	S4LRU-000
4" x 8" Ladder Rack/Unistrut Mounting Kit	S8LRU-000
9" x 12" Ladder Rack/Unistrut Mounting Kit	SWLRM-000
5/8" Threaded Rod Side Mount Bracket (threaded rod not included)	SMH00-SMB

TOOLS

Description	Part No.
Mitre Box (for 1.25" and 2" Ducting)*	SMTRE-050
Mitre Box (for 4", 8" and 12" Ducting)*	SMTRE-300
2" Side Cut-Out Tool Kit (for use with 2" x 2" Side Drop-Off Kits)**	S2CUT-TOL
4" Side Cut-Out Tool Kit (for use with 2" x 4" and 4" x 4" Side Drop-Off Kits)**	S4CUT-TOL
2" End Slot Tool (for use with 2" x 2" Joiners)	SSLOT-050
4" x 8" End Slot Tool (for use with 4" x 4" and 4" x 8" Joiners)	SSLOT-200

* = Ducting and saw not included.

** = Ratchet and socket not included.

Contact inside sales at 1.800.722.2082 to order. Callers from outside the US and Canada please dial +1.425.486.2222.