



FS436
Meets ANSI/BHMA 156.16, L12141 for brass
or bronze and L32141 for aluminum.



FS438
Meets ANSI/BHMA 156.16, L12141 for brass
or bronze and L32141 for aluminum.

FS436 Dome Stop

FS438 Dome Stop

- FS436 for doors without threshold.
- FS438 for doors with threshold or undercut doors.
- Heavy-Duty Cast Dome Stops constructed of brass, bronze or aluminum.
- Packed with wood screw and plastic anchor.

Replaceable gray, non-marring rubber bumper.

Dimensions

FS436

Overall Height: 1"

Base Height: 3/16"

Base Diameter: 1-3/4" x 2" Oval

FS438

Overall Height: 1-3/8"

Base Height: 9/16"

Base Diameter: 1-3/4" x 2" Oval

Finishes *brass*

Ives Number	US3	US4	US5	US10	US10B	US15	US26	US26D	B716
BHMA	605	606	609	612	613	619	625	626	

Finishes *aluminum*

Ives Number	US28
BHMA	628





R435 Riser for FS436 Dome Stop

R437 Riser for FS438 Dome Stop

- Extruded aluminum, mill finish.
- R435 for conversion of FS436 Dome Stop to carpet installation.
- R437 For conversion of FS438 Dome Stop to carpet installation.
- Packed with wood screws, lead shield and stud.
- Specify Tampin (TPN) if required.

Dimensions

Available in 1/4", 3/8", 1/2", 5/8", 3/4" and 1" height.

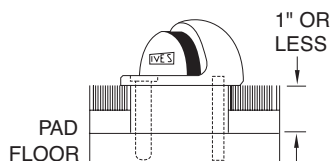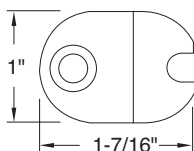

A
Hinges & Pivots

B
Pulls & Plates

C
Flush Bolts & Coordinators

D
Latches, Catches & Bolts

E3
Stops

F
Exterior Hardware

G
Miscellaneous Hardware