

A

Hinges & Pivots

B

Pulls & Plates

C

Flush Bolts & Coordinators

D2

Latches, Catches & Bolts

E

Stops

F

Exterior Hardware

G

Miscellaneous Hardware



Meets ANSI/BHMA A 156.16
UL listed 3 hour fire door, up to 10'0"
Miami Dade County NOA Listed

SB360 Surface Bolt

- Surface Bolt has 1-1/4" throw for maximum security.
- Jimmy-resistant design, bolt locks automatically when thrown, can be released only by pressing knob toward door while retracting.
- Ideal for all types of doors.
- Available in 12" length
- Unit locks in both the up and down position.
- Accepts padlock (not furnished) with maximum 3/8" diameter shackle, minimum 1-3/4" shackle opening height.
- Units packed with one-way screws for added security. Standard screws also supplied.
- Units packed with both a universal top strike (US) and a mortise bottom strike (MS).
- Constructed of heavy duty steel.
- Optional Sex Bolts available.
- Optional Mortise Strike available.

Dimensions

Bar: 3/4" Wide x 3/4" Thick

Overall Width: 2-1/32"


Overall Projection: 2-1/16"

Top Strike: 1-1/2" Wide x 1-1/2" Long x 3/16" Thick

Optional Mortise Strike: 1-5/8" Wide x 3-1/2" Long x 1/8" Thick

Finishes

Ives Number	US2C
BHMA	603

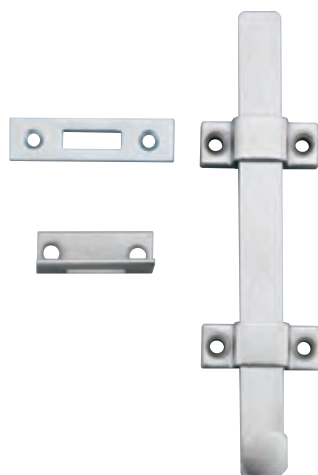

Meets ANSI/BHMA A156.16 L84161
UL listed 3 hour fire door, up to 10'0"

SB453 Surface Bolt

- Surface Bolt has 1-3/16" throw for maximum security.
- Strong tension springs prevent creep.
- Ideal for all types of doors.
- Available 8" & 12" lengths.
- Units packed with standard screws for added security.
- Units packed with both a universal top strike (US) and a mortise bottom strike (MS).
- Constructed of heavy duty steel.
- Optional Sex Bolts available.
- Optional Thru Bolts available.

Dimensions

Bar: 3/4" Wide x 1/4" Thick

Overall Width: 2-1/32"

Overall Projection: 1-5/16"

Top Strike: 1-1/2" Wide x 1-1/2" Long x 3/16" Thick

Bottom Strike: 1-5/8" Wide x 3-1/2" Long x 1/8" Thick

Finishes

Ives Number	US2C	US3	US4*	US10	US10B	US26D
BHMA	603	632	633	639	640	652

* only available in 8" bolt length.