




B500 Series

Commercial deadbolts

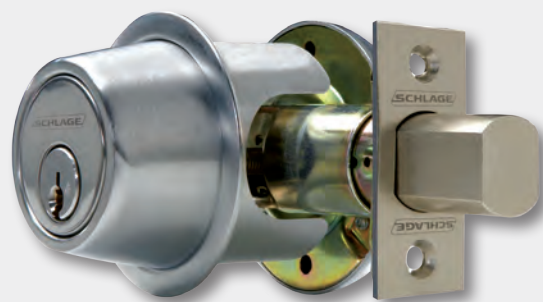

Overview

The B500 Series deadbolt from Schlage is the toughest, most versatile deadbolt in the business. Designed by locksmiths for locksmiths, the B500 Series deadbolt accepts every Schlage cylinder on the market, fits virtually every door you service, enhances lock strength on the jamb side of the door, and will change forever the way you look at deadbolts.

Functions

- B560 - Single cylinder deadbolt lock
- B561 - One-way deadbolt lock
- B562 - Double cylinder deadbolt lock
- B563 - Classroom deadbolt lock
- B571 - Door bolt occupancy indicator
- B580 - Door bolt (no outside trim)
- B581 - Door bolt (with outside blank plate)

Features and benefits

- ANSI A156.5, 2001 Grade 2
- Available UL Listed for three-hour fire door
- Quick, easy installation
- Adjustable backset locks into place
- Anti-pry shield protects latch from attacks
- Metal dust box provides deep anchoring and added strength
- Primary or auxiliary locking for commercial buildings
- High security locking for residential buildings
- Can be suited with virtually all Schlage levers and knobs

Ordering instructions

Order using standard Schlage order form as follows:


B Series deadbolts

Function	Cylinder	Latch suffix	Strike	Finish	Door thickness	Options
B560	P	12-288	10-092	626	1 3/4"	F

Lock specifications

Function	B560, B561, B562, B563, B571, B580, or B581			
Latches	12-288 Square corner (1" x 2 1/4") 2-289 Round corner (1/4" radius) 12-290 Circular deadbolt		12-287 Triple option 12-291 Square corner (1 1/8" x 2 1/4")	
Cylinder	P (Everest 29 standard cylinder) L (Less cylinder) C (Less double cylinder) Leave cylinder code blank if cylinder not applicable		R (Everest 29 S123 FSIC) J (Less FSIC) T (Construction FSIC) G (Everest 29 R family SFIC) B (Less SFIC) BDC (Disposable SFIC) HD (Construction SFIC)	
Finish	605 Bright brass 606 Satin brass 609 Antique brass		612 Satin bronze 613 Oil rubbed bronze 619 Satin nickel 625 Bright chrome 626 Satin chrome 626AM Satin chrome anti-microbial 643e Aged bronze	
Door thickness	1 3/8" - 1 7/8" standard; see pricebook for additional thicknesses			
Options	Specify "F" for UL Listed fire rating. See pricebook for additional options			

B500 Specifications

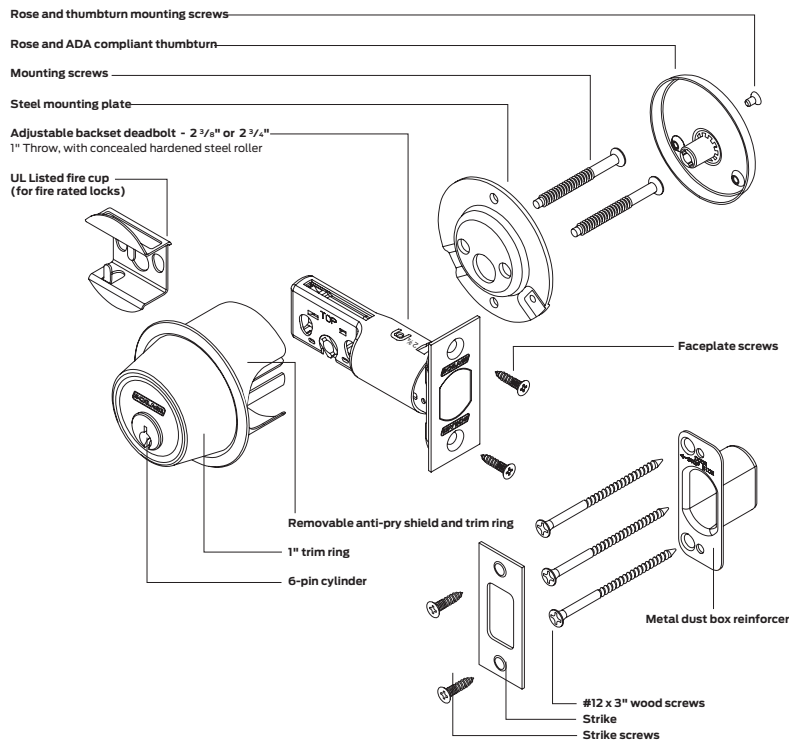


Finishes



605
Bright brass



 
606
Satin brass



609
Antique brass



 612
Satin bronze



613
Oil rubbed
bronze



 
619
Satin nickel



625
Bright chrome



626
Satin chrome



626AM
Satin chrome
anti-microbial



643e
Aged bronze

About Allegion

Allegion (NYSE: ALLE) is a global pioneer in safety and security, with leading brands like CISA®, Interflex®, LCN®, Schlage® and Von Duprin®. Focusing on security around the door and adjacent areas, Allegion produces a range of solutions for homes, businesses, schools and other institutions. Allegion is a \$2 billion company, with products sold in almost 130 countries. For more, visit www.allegion.com.

aptiQ ■ LCN ■ SCHLAGE ■ STEELCRAFT ■ VON DUPRIN



© 2015 Allegion
006477, Rev. 05/15
www.allegion.com/us