


Widescreen LED Security Monitors

18.5" & 21.5" LED Monitors w/HDMI, VGA & BNC Video Inputs, PC Audio In/Output

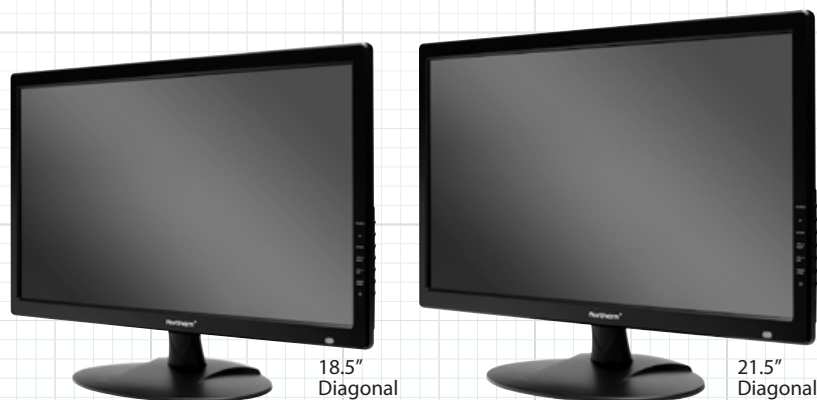

SPECIFICATION	LED18	LED22
Video System	NTSC/PAL (Auto Sensing)	
Max Resolution	1360 x 768	1920 x 1080
Supported Resolutions	720x400; 640x480; 800x600; 1024x768; 1280x1024; 1360x768; 1920x1080 (scaled)	720x400; 640x480; 800x600; 1024x768; 1280x1024; 1360x768; 1440x900; 1600x900; 1680x1050; 1920x1080
3D Comb Filter	Yes	
3D De-Interlace	Yes	
OSD (On Screen Display)	Yes	
Backlight	LED (RGB)	
Active Display Area	18.5" Diagonally	21.5" Diagonally
Impedence	75 OHM Self Terminating	
Video Input Signals	HDMI, VGA, Composite BNC	
Aspect Ratio	Selectable 16:9 or 4:3 in OSD or by One Touch Instant Scaling	
Pixel Pitch	0.28	0.248
Color Depth	Over 16 million colors	
Brightness	250 CD/m ²	
Contrast Ratio	2000:1	
Viewing Angle (H/V)	(170/160)	
Response Time	5ms	
Auto Adjustment	Yes	
Certificates	UL, CUL, CE, FCC, HDMI Forum	
Languages	English, Chinese, German, French, Spanish, Italian	
Input Voltage	100 ~ 240VAC (detachable USA line cord provided)	
Power Consumption	< 20W	< 30W
Video Connections	HDMI, VGA, BNC 1 Input, BNC 2 Input/Output	
Audio Connections	PC Audio (3.5mm Stereo) for VGA & BNC Inputs	
Dimensions (with stand) (H x W x D)	13.42 x 17.8 x 7.28	14.81 x 20.34 x 7.28
Weight	5.51lb	8.75lb
Vesa Mounting	Yes (100 x 100)	
Operating Temperature	32° ~ 104°F	

Note: Specification subject to change without notice


FEATURES

- ◆ 16:9 Aspect Ratio
- ◆ 1360 x 768 Max Resolution (LED18)
- ◆ 1920 x 1080 Max Resolution (LED22)
- ◆ Super Fast 5ms Response Time
- ◆ LED Backlight
- ◆ Built-in Power Supply
- ◆ 3D Comb Filter & 3D De-Interlace
- ◆ Includes 6' HDMI & VGA Cables
- ◆ 3D Digital Noise Reduction
- ◆ HDMI Input
- ◆ VGA & Looping BNC Inputs
- ◆ PC Audio Input/Output
- ◆ Low Power Consumption
- ◆ Full OSD Control of All Monitor Functions
- ◆ Vesa Mounting (100 x 100)
- ◆ UL, CUL, CE Certifications

INCLUDED / ACCESSORIES


1. 6' HDMI Cable
1. 6' VGA Cable
1. 3.5mm Stereo Audio Cable
1. Power Cord
1. User Manual

REAR PANEL CONNECTIONS

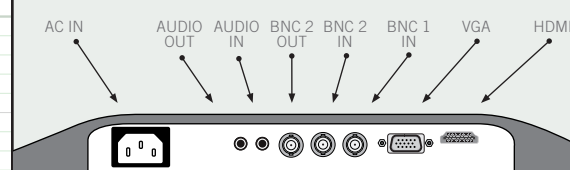


Monitor Dimensions:

LED18

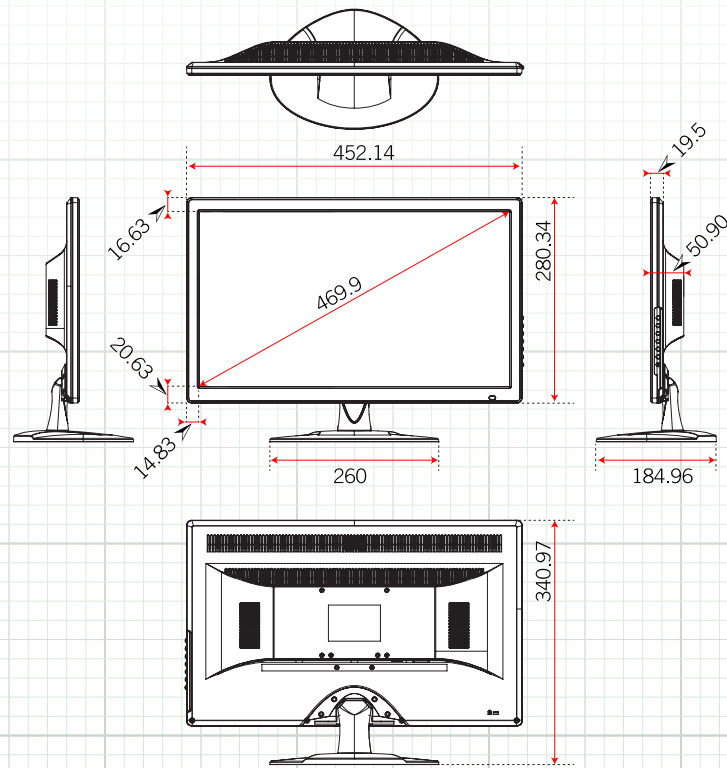

LED22

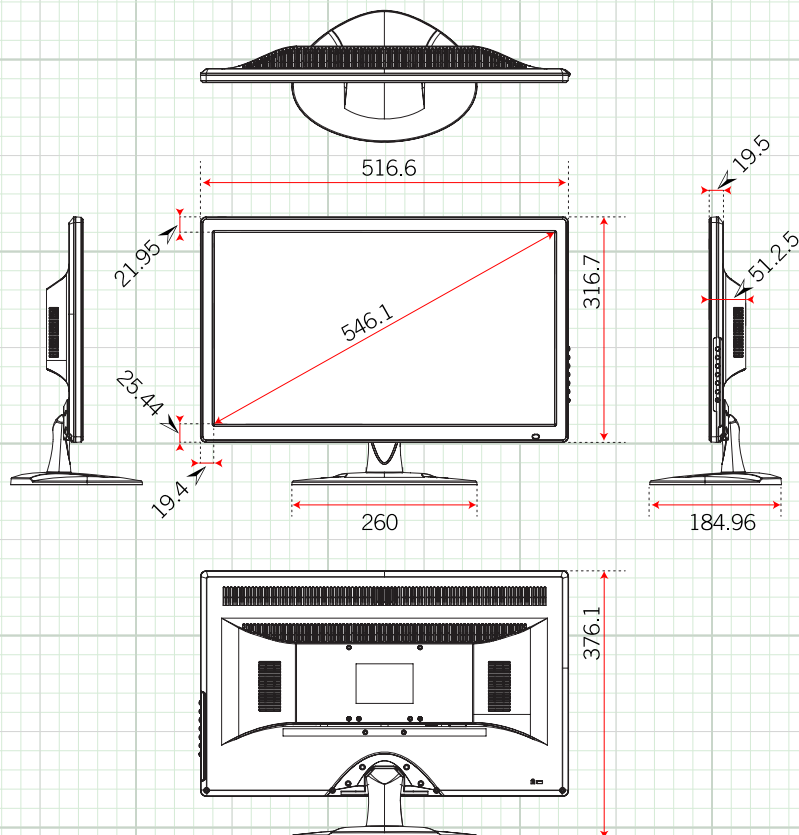

Note: Specification subject to change without notice