

Widescreen LED Security Monitor

27" LED Monitor w/HDMI, VGA & BNC Video Inputs, PC Audio In/Output



27"
Diagonal

SPECIFICATION	LED27
Video System	NTSC/PAL (Auto Sensing)
Max Resolution	1920 x 1080
Supported Resolutions	720x400; 640x480; 800x600; 1024x768; 1280x1024; 1360x768; 1400x900; 1600x900; 1680x1050; 1920x1080
3D Comb Filter	Yes
3D De-Interlace	Yes
OSD (On Screen Display)	Yes
Backlight	LED (RGB)
Active Display Area	27" Diagonal
Impedence	75 OHM Self Terminating
Video Input Signals	HDMI, VGA, Composite BNC
Aspect Ratio	Selectable 16:9 or 4:3 in OSD or by One Touch Instant Scaling
Pixel Pitch	0.3
Color Depth	Over 16 million colors
Brightness	300 CD/m ²
Contrast Ratio	3000:1
Viewing Angle (H/V)	(170/160)
Response Time	5ms
Auto Adjustment	Yes
Certificates	CE, FCC
Languages	English, Chinese, German, French, Spanish, Italian
Input Voltage	12VDC UL/CUL External Power Supply Included
Power Consumption	30W
Video Connections	HDMI, VGA, BNC 1 Input, BNC 2 Input/Output
Audio Connections	PC Audio (3.5mm Stereo) for VGA & BNC Inputs
Dimensions (with stand) (H x W x D)	17.7 x 25.6 x 8.3
Weight	8.39 lb
Vesa Mounting	Yes (100 x 100)
Operating Temperature	32° ~ 104°F

Note: Specification subject to change without notice


FEATURES

- ◆ 16:9 Aspect Ratio
- ◆ 1920 x 1080 Max Resolution
- ◆ Super Fast 5ms Response Time
- ◆ LED Backlight
- ◆ UL/CUL External Power Supply
- ◆ 3D Comb Filter & 3D De-Interlace
- ◆ Includes 6' HDMI & VGA Cables
- ◆ 3D Digital Noise Reduction
- ◆ HDMI Input
- ◆ VGA & Looping BNC Inputs
- ◆ PC Audio Input/Output
- ◆ Low Power Consumption
- ◆ Full OSD Control of All Monitor Functions
- ◆ Vesa Mounting (100 x 100)
- ◆ CE & FCC Certifications

INCLUDED / ACCESSORIES

1. 6' HDMI Cable
1. 6' VGA Cable
1. 3.5mm Stereo Audio Cable
1. Power Cord / Power Supply
1. User Manual

REAR PANEL CONNECTIONS

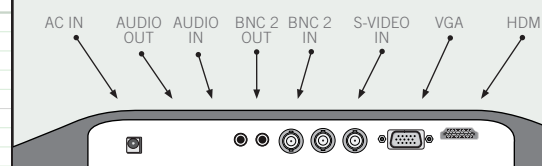

Monitor Dimensions:

LED27

