


1000 Line, Heavy Duty Outdoor Bullet Cameras with IR Sony IMX 238 Chip, True D/N, True WDR, OSD, DNR

**TRUE WIDE DYNAMIC
TRUE DAY/NIGHT**



Dimensions & Photo for both
PRO1000B3 / PRO1000B6

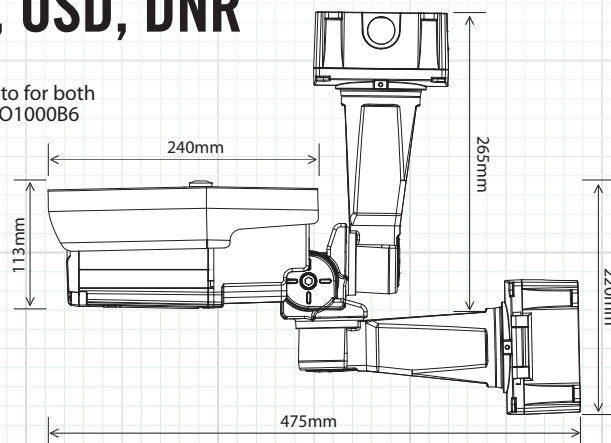

| SPECIFICATION | PRO1000B3 | PRO1000B6 |
|----------------------------|---|------------------|
| Image Sensor | Sony IMX-238 Sensor | |
| Effective Pixels | 1296 (H) x 1041 (V) | |
| Resolution | 1000 TV Lines Color | |
| OSD (On Screen Display) | Yes - Hatch Style | |
| True Wide Dynamic Range | Yes - Double Scan WDR (LOW / MIDDLE / HIGH) | |
| Digital Noise Reduction | Yes - 2D + 3D DNR (OFF / LOW / Middle / HIGH) | |
| Video Output | 1.0Vp-p / 75 OHM | |
| Lens Type - True Day Night | 3~12mm | 6~50mm |
| IR Cut Filter | Yes - Mechanical | |
| Sense-Up | Yes - OFF, 2x ~60x | |
| Minimum Illumination | 0.002 Lux Color (F1.2/50IRE/DSSx60) 0.0002 Lux B/W (F1.2/50IRE/DSSx60) | |
| IR LED (850nm) / Range | 100pc / 250 Foot | 100pc / 325 Foot |
| S/N Ratio | 50 [db] / AGC Off | |
| Electronic Shutter | AUTO / MANUAL - 1/30 ~ 1/60,000 sec / FLICKER | |
| Iris Mode | ALC (Auto Iris Control) ELC (Electric Iris Level Control) | |
| Gain Control | On, Off, 0~20 Adjustable | |
| White Balance | Auto / Auto-Ext / PRESET / MANUAL | |
| Sync System | Internal | |
| Scanning System | Progressive Scan | |
| Video System | NTSC | |
| Gamma | γ= 0.45 Approx | |
| Back Light Compensation | OFF / WDR / BLC | |
| HLMASK (High Light Mask) | OFF / ALL / DAY / NIGHT | |
| Day / Night | A.CDS, A.AGC, Color, B/W | |
| Digital Zoom | Yes 1x~10x | |
| Mirror Mode | Yes - Horizontal & Vertical | |
| Power Range | 12VDC/24VAC Dual Voltage Power (Separate Leads) | |
| Power Requirement | Camera Only: 200mA Max / LED-Fan-Heater On 1.5Amp | |
| Recommended Power | 2Amp Power Supply Recommended | |
| Dimensions (Camera Only) | 5.5" (W) x 4.5" (H) x 9.5" (D) | |
| Weight | Approx. 10lb | |
| Operating Temp | -40°F ~ 130°F | |
| Weatherproof Rating | IP66 | |

Note: Specification subject to change without notice

FEATURES

- ◆ Sony IMX-238 Sensor
- ◆ 1000 Line Resolution
- ◆ True Wide Dynamic Range
- ◆ True Day/Night Operation w/ ICR Cut Filter
- ◆ Built-in Heater & Fan
- ◆ Heavy Duty Professional Housing
- ◆ 3° Mount Adjustments for Precise Aiming
- ◆ Hinged Back Box with 3/4" knockouts
- ◆ 3-Axis Wall or Ceiling Mountable
- ◆ OSD Controls on Door Hatch
- ◆ Sense-up / Northern Lights Technology
- ◆ Move & Leave Lens Adjustments
- ◆ 3~12mm - 250' IR Range
- ◆ 6~50mm - 325' IR Range
- ◆ IR LED On/Off Feature
- ◆ IR LED Beam Adjustment
- ◆ -40°F ~ 130°F Operating Temp for Harsh Environments
- ◆ Video Test Output & Cable
- ◆ 12VDC/24VAC Dual Voltage Power
- ◆ IP66 Weatherproof Rating

INCLUDED ACCESSORIES

- ◆ Mounting Arm and Junction Box
- ◆ Mounting Gasket, Mounting screws & anchors [x4]
- ◆ Junction Box caps, hinge screw & nut
- ◆ 12VDC Adapter
- ◆ Video Test Cable
- ◆ Allen Wrenches [x2]