

Security Rated Widescreen LED Monitor

21.5" LED MONITOR w/ 2x BNC, VGA, HDMI, Audio & 3DNR



21.5"

| SPECIFICATION | LED21HDMI |
|-------------------------------------|---|
| Video System | NTSC/PAL (Auto Sensing) |
| Resolution | 1920 x 1080 (1080p) |
| 3D Comb Filter | Yes |
| 3D De-Interlace | Yes |
| OSD (On-screen Display) | Yes |
| Backlight | LED |
| Active Display Area | 21.5" Diagonally |
| Impedance | 75 OHM Self Terminating |
| Video Input Signals | Composite Video (2x), VGA, HDMI |
| Aspect Ratio | 16:9 HDMI / 16:9 & 4:3 Selectable VGA & BNC |
| Pixel Pitch | 0.248 x 0.248 (mm) |
| Color Depth | 16.7 Million |
| Brightness | 280 cd/m2 |
| Contrast Ratio | 10,000:1 |
| Viewing Angle (H/V) | 170° / 160° |
| Response Time | 5ms |
| Auto Adjustment | Yes |
| Certificates | FCC, CE, ROHS |
| Languages | English, German, French, Italian, Spanish |
| Input Voltage (Power Supply) | AC 100-240V 50/60HZ |
| Power Supply Output Voltage | 12 Volts DC @ 4.1Amp |
| Power Consumption | 25 Watt Max |
| Video Connections | BNC In/Out (2x), VGA, HDMI |
| Audio Connections | RCA (2x -Stereo) PC Audio |
| Dimensions (with stand) (H x W x D) | 14.8" x 20.6" x 6.9" |
| Weight | 7.9lb |
| VESA Mounting | Yes (100 x 100) |
| Operating Temperature | 32°F ~ 104°F |

Note: Specification subject to change without notice


FEATURES

- ◆ LED Backlight
- ◆ 3D Comb Filter
- ◆ 3D De-Interlace
- ◆ Includes 6' HDMI and VGA Cables
- ◆ Up to 1920 x 1080 Resolution (1080p)
- ◆ 3DNR Digital Noise Reduction
- ◆ HDMI and VGA Video Inputs
- ◆ Dual Looping BNC Video Inputs
- ◆ Stereo RCA Audio Inputs
- ◆ PC Audio Input
- ◆ Low Power Consumption
- ◆ Super Fast 5ms Response Time
- ◆ Full OSD Control of all Monitor Functions
- ◆ 16:9 Aspect Ratio
- ◆ Vesa Mounting (100 x 100)

INCLUDED / ACCESSORIES


1. 6' HDMI Cable
1. 6' VGA Cable
1. 12 Volts DC Power Supply/Power Cord
1. User Manual

REAR PANEL CONNECTIONS

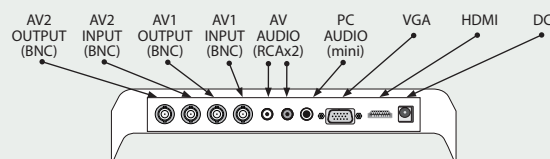

Monitor Dimensions:

LED21HDMI

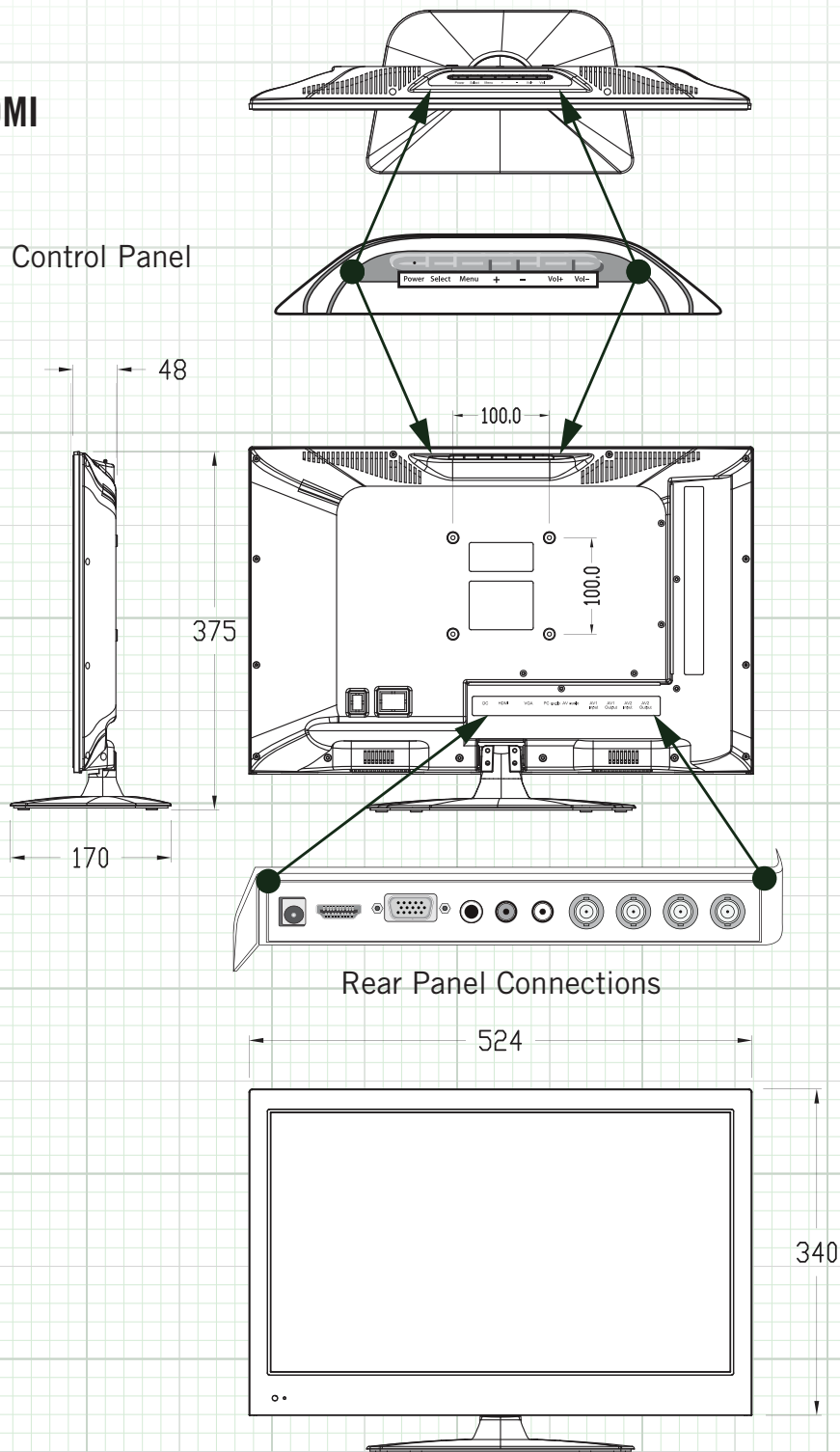

LED21HDMI

Note: Specification subject to change without notice