

## Security Rated Widescreen LED Monitor

### 23.6" LED MONITOR w/ 2x HDMI, VGA, BNC, Audio & 3DNR



23.6"

SPECIFICATION	LED23HDMI
Video System	NTSC/PAL (Auto Sensing)
Resolution	1920 x 1080 (1080p)
3D Comb Filter	Yes
3D De-Interlace	Yes
OSD (On-screen Display)	Yes
Backlight	LED
Active Display Area	23.6" Diagonally
Impedance	75 OHM Self Terminating
Video Input Signals	Composite Video, VGA, HDMI x2
Aspect Ratio	16:9 HDMI / 16:9 & 4:3 Selectable VGA & BNC
Pixel Pitch	0.2715 x 0.2715 (mm)
Color Depth	16.7 Million
Brightness	280 cd/m2
Contrast Ratio	10,000:1
Viewing Angle (H/V)	170° / 160°
Response Time	5ms
Auto Adjustment	Yes
Certificates	FCC, CE, ROHS
Languages	English, German, French, Italian, Spanish
Input Voltage (Power Supply)	AC 100-240V 50/60HZ
Power Supply Output Voltage	12 Volts DC @ 4.1Amp
Power Consumption	25 Watt Max
Video Connections	BNC In/Out, VGA, HDMI x2
Audio Connections	RCA (2x -Stereo) PC Audio
Dimensions (with stand) (H x W x D)	16.9" x 22.9" x 6.9"
Weight	10.1lb
VESA Mounting	Yes (100 x 100)
Operating Temperature	32°F ~ 104°F

Note: Specification subject to change without notice


### FEATURES

- ◆ LED Backlight
- ◆ 3D Comb Filter
- ◆ 3D De-Interlace
- ◆ Includes 6' HDMI and VGA Cables
- ◆ Up to 1920 x 1080 Resolution (1080p)
- ◆ 3DNR Digital Noise Reduction
- ◆ Two HDMI Inputs
- ◆ VGA and Looping BNC Video Inputs
- ◆ Stereo RCA Audio Inputs
- ◆ PC Audio Input
- ◆ Low Power Consumption
- ◆ Super Fast 5ms Response Time
- ◆ Full OSD Control of all Monitor Functions
- ◆ 16:9 Aspect Ratio
- ◆ Vesa Mounting (100 x 100)

### INCLUDED / ACCESSORIES


1. 6' HDMI Cable
1. 6' VGA Cable
1. 12 Volts DC Power Supply/Power Cord
1. User Manual

### REAR PANEL CONNECTIONS

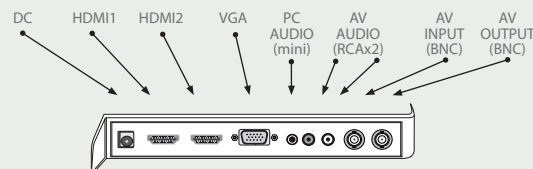

## Monitor Dimensions:

LED23HDMI

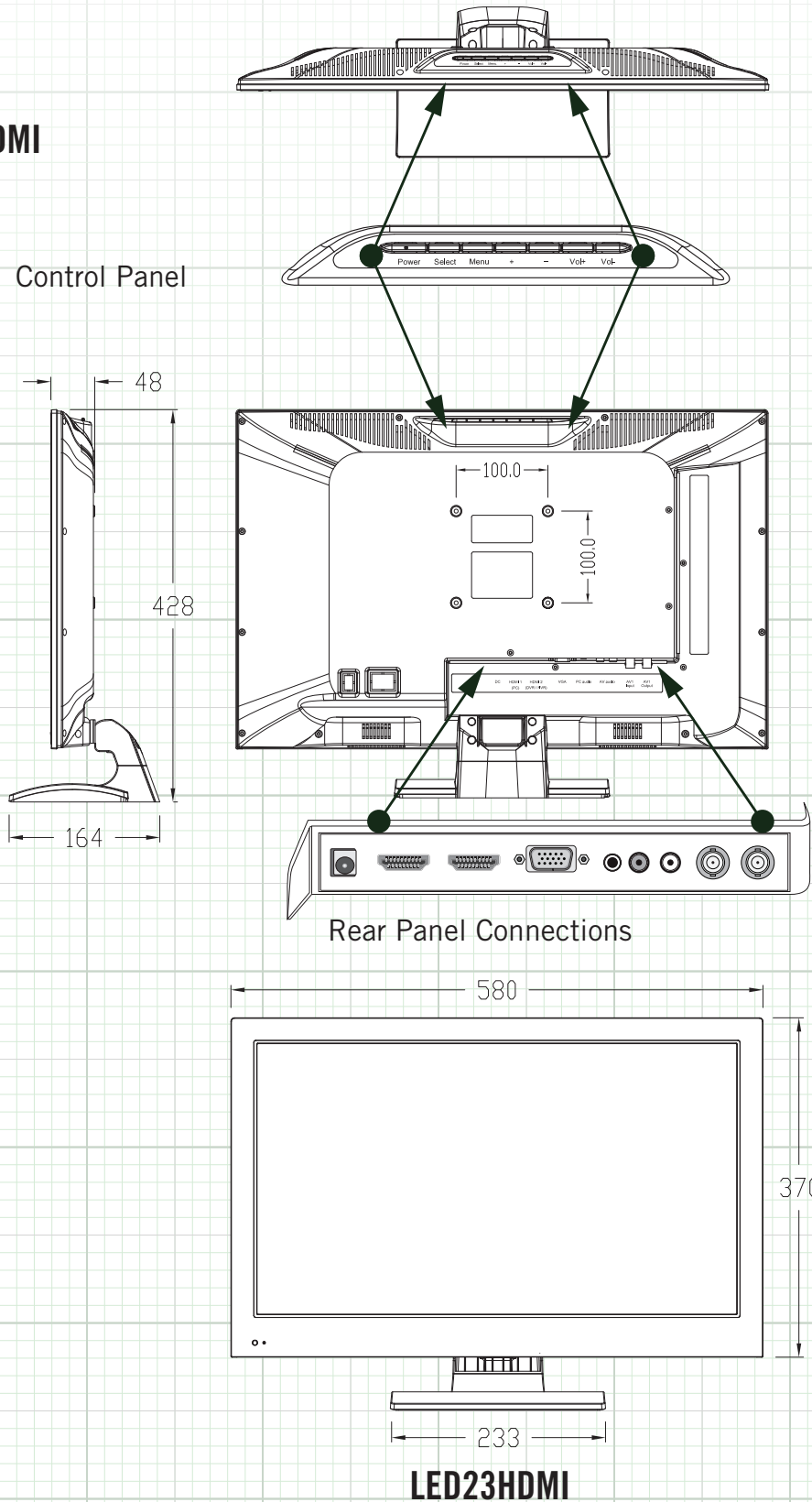

Note: Specification subject to change without notice