



## 960H/700 Line Ultra Miniature Indoor Day/Night Camera

OSD, D-WDR, 3.6mm Lens

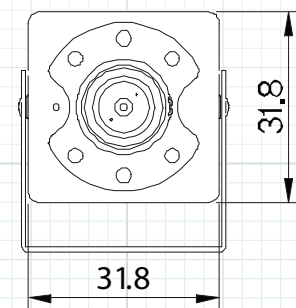

MC700

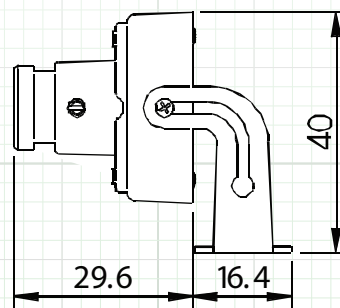

DIMENSIONS (mm)

SPECIFICATION	MC700
Imaging Device	1/3" SONY Super HAD II CCD
Resolution	Color 700 TV Lines – B/W 800 TV Lines
TV System	NTSC
Effective Pixels	976 (H) X 494 (V)
Lens	Fixed Focal 3.6mm
Sync System	Internal
Scanning System	2:1 Interlace
Video Output	1.0Vp-p 75 OHM Composite BNC
Minimum Illumination	0.1 Lux
S/N Ratio	52dB (AGC Off)
Gamma Characteristic	0.45
Electronic Shutter Speed	Auto - Manual (1/60 ~ 1/100,000 sec.)
OSD	Yes Built-in on Back of Camera
BLC (Backlight Compensation)	DWDR / BLC / HLC / OFF
AGC (Auto Gain Control)	x0.25 / x0.50 / x1.0
Day/Night	Electronic Type (Auto, Color, B/W)
D-WDR (ATR)	Yes, Luminance & Contrast Adjustable
Power Requirement	Regulated 12 volts DC +/- 10%
Power Consumption	120mA
Operating Temperature	14° ~ 122°F
Weight	1.8 oz
Housing	Metal Case (Black)
Dimensions (H x W x D)	1.25" x 1.25" x 1.19"

Note: Specification subject to change without notice

### FEATURES

- ◆ SONY 960H Chip / 700 Line Resolution
- ◆ Digital Wide Dynamic Range
- ◆ OSD Control of All Major Functions
- ◆ Auto Electronic Shutter
- ◆ 3.6mm Fixed Focal Lens
- ◆ 12VDC Power Required
- ◆ For Indoor Use

### INCLUDED ACCESSORIES

1. Camera User Manual
1. Mounting Screws (set)
1. Camera Mount