

4 Channel 5 Amp 12VDC Power Supply

FEATURES


- ◆ UL / CUL Listed
- ◆ Built in PTC Fuse for Protection
- ◆ Adjustable Output Voltage up to 13.8V
- ◆ 100V-240V Wide Range Input Voltage
- ◆ Led Indicator Light

INCLUDED / ACCESSORIES

1. Power Cord

Recommended Cable Prep

Ensure Positive [+] Wire Jacket Extends Beyond Bare Lead of Second [-] Wire.

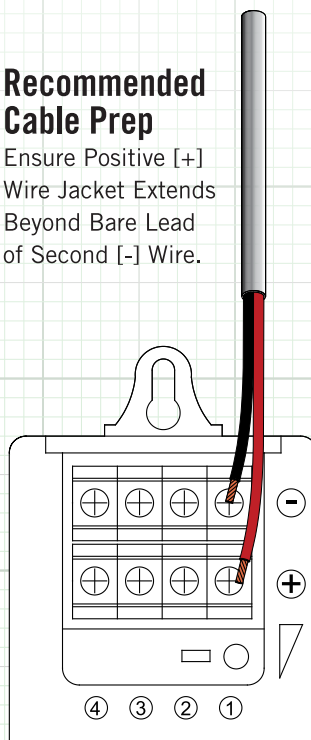

Terminal Strip Cover



Power Output



Power Input



SPECIFICATION	PSMINI4C5AUL
Number of Outputs	4
Input Voltage	AC 100V-240V
Adjustable Output Voltage	12 ~ 13.8 Volts DC
Output Current	5 Amp
Fuse Type	PTC 6-Amp
LED Indicator	Yes
Certificates	UL / CUL
Operating Temperature	-22°F ~ 113°F
Weatherproof Rating	Indoor Only
Dimensions (H x W x D)	6.5" x 2.12" x 1.37"

Note: Specification subject to change without notice