




Universal

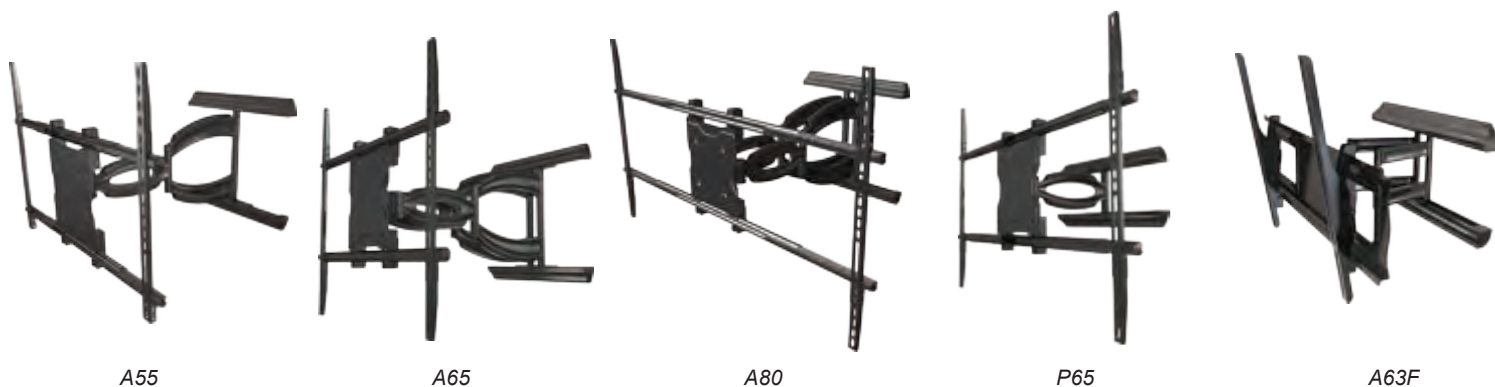

Model	TV Sizes	Max Mounting Pattern (WxH)	Max Extension From Wall	Load Rating
A55	37"-55"	690x544mm	27.0"	150lb
A65	37"-65"	800x672mm	27.0"	200lb
A80	42"-65"+	1080x670mm	27.0"	200lb
P65	37"-65"	800x672mm	14.5"	150lb
A63F	37"-63"	723x501mm	15.5"	130lb



VESA



Model	TV Sizes	Max Mounting Pattern (WxH)	Max Extension From Wall	Load Rating
A55V	32"-55"	400x400mm	27.0"	150lb
P55V	32"-55"	400x400mm	14.4"	150lb

Installation

All models include a wall template and come pre-assembled for quick, easy, and efficient installation.

Installation Surfaces

Double wood stud structures, structural concrete and cinder block surfaces. For metal stud installation, use Crimson HT toggle bolt hardware.

Fully Adjustable

Simplified post-installation vertical adjustment and screen leveling. Side adjustment capability (pre or post installation) for precise placement, corner mounting and centering.

Smooth Lockable Tilt

Unique balanced smooth-tilt feature eliminates typical friction adjustment.

Stylish

Stylish, heavy duty design includes covers and cord management.

VESA Compatible

Series covers all VESA patterns to 1000x600mm.

Construction

Fabricated from high-grade cold rolled steel and aluminum with durable epoxy powder coat finish. Includes a complete array of high-grade fasteners, in a pre-sorted hardware pack for easy selection. UL Listed.