





**Articulating (Dual Link)**

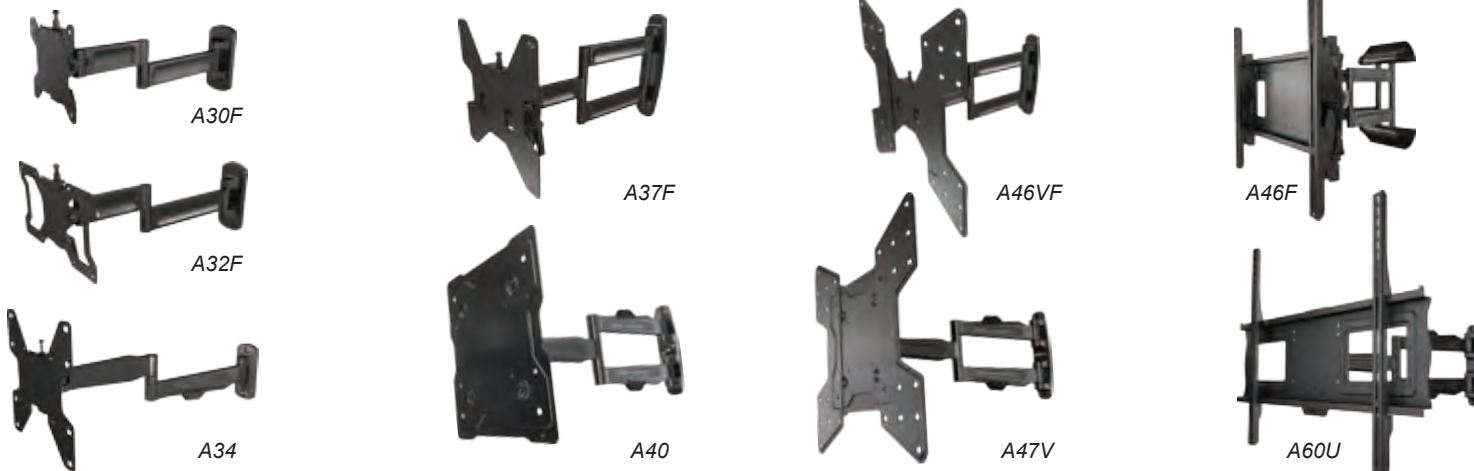

Model	TV Sizes	Max Mounting Pattern (WxH)	Max Extension From Wall	Load Rating
A30F	10"-30"	100x100mm	14.6"	30lb
A32F	13"-32"	200x100mm	14.6"	30lb
A34	13"-34"	200x200mm	20.7"	30lb
A37F	13"-37"	200x200mm	15.4"	80lb
A40	13"-40"	200x200mm	21.0"	80lb
A46VF	13"-46"	400x400mm	15.7"	80lb
A47V	13"-47"	400x400mm	21.0"	80lb
A46F	26"-46"	454x401mm	15.5"	100lb
A60U	37"-60"	756x501mm	22.0"	80lb



**Pivot (Single Link)**

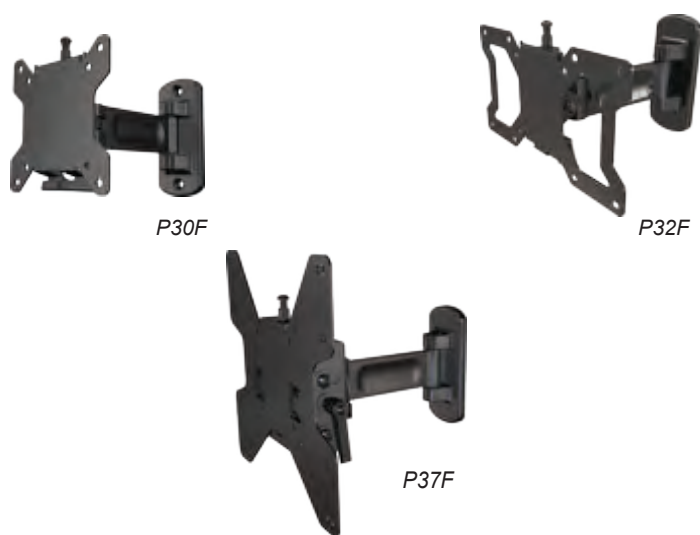

Model	TV Sizes	Max Mounting Pattern (WxH)	Max Extension From Wall	Load Rating
P30F	10"-30"	100x100mm	7.2"	30lb
P32F	13"-32"	200x100mm	7.2"	30lb
P37F	13"-37"	200x200mm	7.8"	80lb

**Installation**

Quick, easy and efficient installation. Product ships pre-assembled.

**Installation Surfaces**

Single stud, structural concrete, cinder block, or other structural surfaces.

**Choice of Extension from Wall**

Functional, durable and competitively priced solutions. Extension length choices include single link minimal extensions, 15" extensions (F-models), and 21" extensions.

**Expandable to 400x400mm VESA**

Easily expandable through 47" TVs with addition of the AD400 VESA pattern extender (A40, A37F, P37F).

**VESA Compatible**

Series covers all VESA patterns to 600x400mm.

**Construction**

Fabricated from high-grade cold rolled steel and aluminum with durable epoxy powder coat finish. Includes a complete array of high-grade fasteners, in a pre-sorted hardware pack for easy selection. UL Listed.