



Carts and Stands




M63



S63

Model	TV Sizes	Max Height Adjustment	Max Mounting Pattern (WxH)	Load Rating
M63	37"-63"	70.75"	723x501mm	150lb
S63	37"-63"	68"	723x501mm	150lb

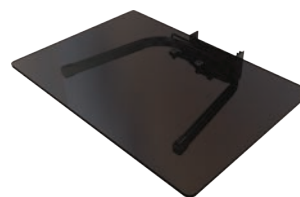


MSG



MSM

Optional tempered glass or metal shelf that easily installs after TV is attached

Collapsible Floor Stand (optional casters)

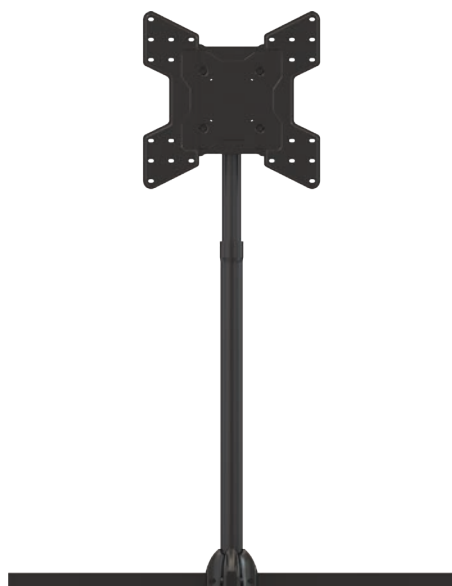

S46P

Model	TV Sizes	Height Adjustment	Max Mounting Pattern (WxH)	Load Rating
S46P	32"-55"	48"-64.5"	400x400mm (expandable to 723x501mm)	100lb

■ Installation

Ships completely pre-assembled (S46P) or as subassemblies that easily and intuitively bolt together. Optional shelves easily attach pre-or post-installation, without removing the display.

■ Heavy Duty Components

Heavy duty joints and casters provide extensive field durability.

■ Fully Adjustable

Height of display may be continuously adjusted vertically, post-installation. S46P completely collapses to a 6"x34" footprint.

■ Variety of Solutions

Portable and semi-portable solutions for a variety of applications.

■ Expandable Functionality

Compatible with narrow, extended landscape displays in Digital Signage applications. Optional accessories provide expanded screen compatibility and functionality.

■ VESA Compatible

Series covers all VESA patterns to 700x500mm (expandable).

■ Construction

Fabricated from high-grade cold rolled steel and aluminum with durable epoxy powder coat finish. Includes a complete array of high-grade fasteners, in a pre-sorted hardware pack for easy selection.