


Flat




F46A



F55A

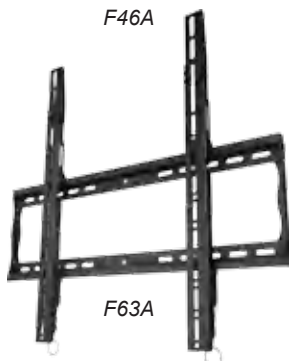

F63A

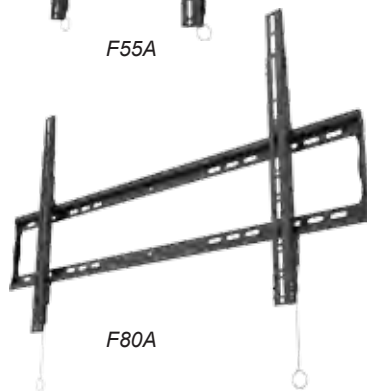

F80A

Model	TV Sizes	Max Mounting Pattern (WxH)	Load Rating
F46A	26"-46"	446x402mm	150lb
F55A	32"-55"+	660x502mm	200lb
F63A	37"-63"+	832x601mm	200lb
F80A	46"-65"+	1096x601mm	300lb




Heavy duty leveling mechanism

Click in place installation
Includes optional locking bolt


Tilt




T46A

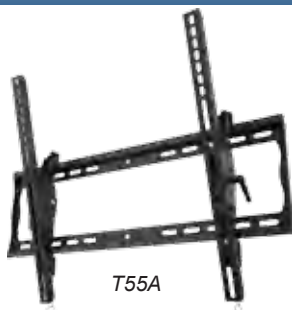

T55A

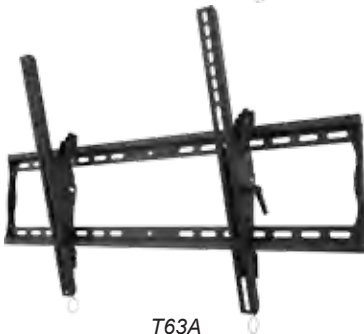

T63A

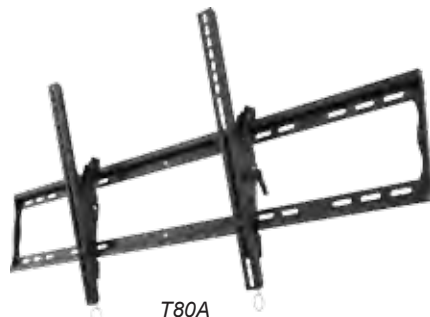

T80A

Model	TV Sizes	Max Mounting Pattern (WxH)	Load Rating
T46A	26"-46"	452x401mm	150lb
T55A	32"-55"+	660x501mm	200lb
T63A	37"-63"+	838x501mm	200lb
T80A	46"-65"+	1105x629mm	300lb

■ Installation

Quick, easy, and efficient installation. Monitor clicks in place when installed. No need to turn screws that are difficult to see and reach, unless you feel the need for additional security, in which case securing screws are there as well. Post-installation leveling feature allows fine-tuning when walls are not perfectly straight.

■ Installation Surfaces

Double or triple wood stud structures, depending on model. Also mounts to structural concrete and cinder block surfaces. For metal stud installation, use Crimson HT toggle bolt hardware.

■ Tilt

Pre-tensioned tilt mechanism with ratcheting handle benefits bottom-heavy displays.

■ VESA Compatible Universal Design

Series covers all VESA patterns to 1000x600mm. Maximum universal mounting pattern 1105x629mm in the tilt series and 1096x601mm in the flat series.

■ Construction

Fabricated from high-grade cold rolled steel with durable epoxy powder coat finish. Includes a complete array of high-grade fasteners, in a pre-sorted hardware pack for easy selection. UL Listed.