

604 Series - CAT6 Protector

4 PAIR - CAT6 - INDOOR BET - NO COVER

Product Specifications


UL497 Primary Protector for Communication Circuits

NAFTA Country of Origin: CANADA - All Models are "Buy America Act" Approved.

These Solid State devices are designed to protect High-Speed 4 Pair CAT6 outside plant cables at speeds of up to 10 gigabit at 250 MHz and clamping speeds of 1-5 nanoseconds. Rated for UL497/UL497B the 75v series is ideal for ISDN, VOIP and PoE/PoE+ applications.

Features & Benefits

- Certified Category 6
- Frequencies up to 250 MHz
- Equipped with an Internal Fuse Link
- Exceeds UL497/UL497B Protection Standards
- 16 AWG Powder Coated Steel
- 110 Connector Accepts 22-26 AWG Solid or Standard Copper Wire

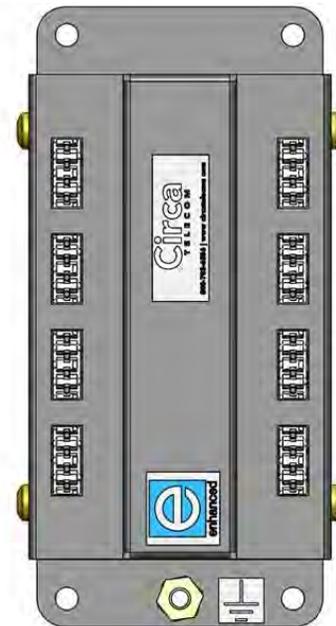

604-30-110

Ordering Information

Model Number	Clamping Voltage	Pair Count	Input	Output	Dimensions (H" x W" x D")	Weight (lbs)
604-30110	30v	4	110	110	5.50 x 2.67 x 1.65	2.0
604-30RJ	30v	4	110	RJ45	5.50 x 2.67 x 1.65	2.0
604-75110	75v	4	110	110	5.50 x 2.67 x 1.65	2.0
604-75RJ	75v	4	110	RJ45	5.50 x 2.67 x 1.65	2.0

Circa Telecom, Inc © 2015 - Version 1.03

604-Series CAT6 Protector


4 PAIR - CAT6 - INDOOR BET - NO COVER



Physical Dimensions

UL497 Primary Protector for Communication Circuits

5.50 x 2.67 x 1.65
(H" x W" x D")

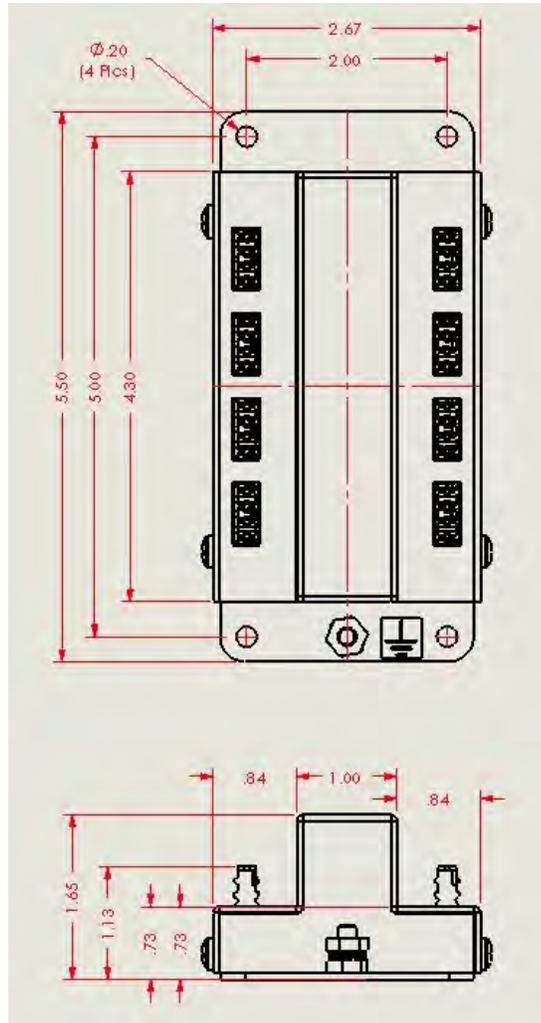

Notes

Installation: Indoor Wall Mount