


High Performance Fanless NVR Appliance

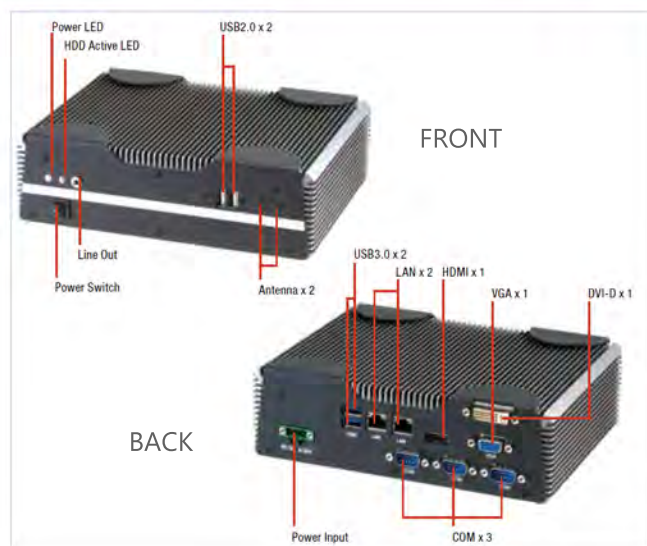

Standard / Integrated Interfaces

Network	2 x 10/100/1000 Base-T Ethernet port(s) RJ45
USB	2 x USB 2.0 (Mouse, Keyboard, Expansion) 2 x USB 3.0
Display Outputs	VGA x 1 (DB15) + DVI-D x 1 + HDMI x 1 VGA: Up to 2048 x 1536 @ 75Hz DVI-D: Up to 1920 x 1200 @ 60 Hz HDMI: Up to 1920 x 1200 @ 60 Hz
Serial Port	1 x RS-232/422/485 (DB9) 2 x RS-232 (DB9)
Audio	1 x Line-Out

System

Operating System	Windows Embedded Standard 7
CPU Options	4th Gen. Intel® Core™ i3 4th Gen. Intel® Core™ i7
Memory	4GB DDR3
HW Watchdog	Auto-boot, OS supervision, temperature monitoring, software monitoring

Storage

Boot	Optional 64GB SSD Boot Drive
Internal	SATA HDD / SSD (2.5 in) 500GB, 1TB & 2TB Models Available
External	Network Storage via LAN (iSCSI) External storage via USB 3.0

Available Options

- WIFI 802.11b/g/n Network Module w/ Antenna

Built-In VMS Software Packages

- Arteco
- Avigilon
- Axis Camera Station / Camera Companion
- ExacqVision
- Genetec Security Center
- Milestone XProtect
- And more...

Protocols

Networking	IPv4/v6, UDP, TCP, IGMP, ARP, DHCP, DNS, HTTP, HTTPS, BONJOUR, NTP
Security	Basic / Digest Authentication, SSL

Software

Auto-Discovery	Bonjour protocol support
Web Interface	Web GUI for remote config. / maintenance
Pre-Loaded Software	Quick Setup Wizard for easy deployment Contact us for list of supported software

Mechanical / Environmental

Dimensions	23.8cm (W) x 7.8cm (H) x 15.6cm (D)
Weight	n/a
Enclosure	Aluminum / Black, Gray
Input Voltage	DC 9 ~ 30V with 3-pin terminal block
Power Consumption	n/a
Operating Temp.	-10C to 50C
Certifications	CE, FCC Class A
Compliance	Vibration: 1g rms / 5~ 500Hz Shock: 20 G peak acceleration (11 msec.)
MTBF	78,000 hours
Warranty	2 Years Standard Extended warranty available (1, 2 or 3 years)