






Septor® Headlamp

FL 1 STANDARD	7 LEDs	3 LEDs	1 LED
	120 LUMENS	45 LUMENS	13 LUMENS
	3.5h	10h	55h
	60m	35m	20m
	900cd	375cd	100cd



A wide flood pattern illuminates your work area

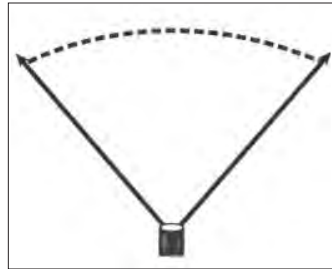

Case Material: Tough ABS thermoplastic construction with elastomer over mold; polycarbonate lens

Dimensions/Weight: Face Cap Diameter: 1.75 in. (4.45 cm) Maximum Width: 2.70 in. (6.85 cm)
Maximum Depth: (Includes head strap mounting plate) 2.40 in. (6.09 cm)
5.50 oz (156.0 grams) with batteries

Light Source: Seven 100,000 hour life 5 mm LEDs
Three lighting modes:
- 7 LEDs for a soft flood light for tasks at arm's length
- 3 LEDs for light without the glare and longer run time
- 1 LED for extended run times and when a less intense beam is ideal

On/Off: Push-button Sequences through one LED, three LEDs, seven LEDs and Off. Easy to use with gloves; recessed to prevent inadvertent activation

Battery: Three "AAA" alkaline batteries (included)

Features:

- LED battery indicator - Red LED flashes when battery voltage is low and batteries are near the end of their useable life; LED is located in the reflector in between the "Low Batt" marking and functions while the light is energized
- Rubber hard hat strap and elastic strap
- 90 degree tilting head with a durable ratcheting system
- IPX4 water-resistant
- 2 meter impact resistance tested

Approvals: C-ETL-US Classified Class I, Div 2, Groups A,B,C,D; Class II, Div 2, Groups F,G; Class III, T5
Most models meet applicable European Community Directives

Warranty: Streamlight warrants this product to be free of defects for a lifetime of use except for batteries and bulbs, abuse and normal wear. We will repair, replace or refund the purchase price of this product should we determine it to be defective. This limited lifetime warranty also excludes rechargeable batteries, chargers, switches and electronics which have a 2 year warranty with proof of purchase. THIS IS THE ONLY WARRANTY, EXPRESSED OR IMPLIED, INCLUDING ANY WARRANTY OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE. INCIDENTAL, CONSEQUENTIAL OR SPECIAL DAMAGES ARE EXPRESSLY DISCLAIMED EXCEPT WHERE SUCH LIMITATION IS PROHIBITED BY LAW. You may have other specific legal rights which vary by jurisdiction.



Description	UPC	Part #
Septor	080926-61052-1	61052

Made in China



STREAMLIGHT



30 Eagleville Road • Eagleville, PA 19403 • 610-631-0600/800-523-7488 Phone • 610-631-0712/800-220-7007 Fax
www.streamlight.com ©Streamlight, Inc Septor 8/13