

## ARGO® LED HEADLAMP ALKALINE AAA BATTERY-POWERED HEADLAMP

**MARKET**
**APPLICATIONS:** Outdoor, Sporting Goods, Automotive, Hardware/Do-It-Yourself, Industrial, Emergency Medical Services, Safety, Gift, Consumer, Pest Control, Boating

**DESCRIPTION:**

The Argo® headlamp with adjustable elastic head strap features a single C4® power LED for long distance lighting with three output modes and a low battery warning indicator.

**CASE MATERIAL:**

Tough ABS thermoplastic construction with elastomer over mold. Available in Yellow

**DIMENSIONS:**

 Face Cap Diameter: 1.75 in. (4.45cm)                      Maximum Width: 2.70 in (6.85 cm)  
 Maximum Depth (including head strap mounting plate): 2.40 in. (6.09 cm)

**WEIGHT:**

5.40 oz (153.0 grams) with batteries (included with purchase).

**LENS:**

Unbreakable polycarbonate lens.

**LIGHT SOURCE:**

One (1) White C4® LED technology, impervious to shock with a 50,000 hour lifetime.

**LIGHT OUTPUT:**

 High - 150 Lumens, 9250 candela peak beam intensity, and 190 meter beam distance.  
 Medium - 100 lumens, 6375 candela peak beam intensity, and 160 meter beam distance.  
 Low - 45 lumens, 2750 candela peak beam intensity, and 103 meter beam distance.

**ON/OFF:**

Push-button sequence through modes, High, Medium, Low and Off

**RUN TIME:**

See chart. All claims to 10% of initial lumen output.


**BATTERY:**


Three (3) "AAA" size, Alkaline batteries.

**FEATURES:**

 C4® LED technology for extreme brightness.  
 Low Battery Indicator - Red LED flashes when battery voltage is low and batteries are near the end of their usable life. LED is located in the reflector in between the "Low Batt" marking and functions while the light is energized.  
 IPX4 rated for water resistant operation.  
 2 meter impact resistance tested.  
 90 degree tilting head.  
 Rubber Hard Hat Strap (included in purchase).

**WARRANTY:**

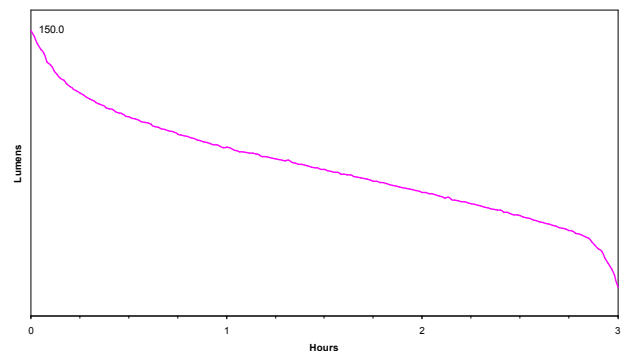
Streamlight's Limited Lifetime Warranty


 


**APPROVALS:**
 Class 1, Division 2, Groups A,B,C,D; Class II, Division 2, Groups F,G; Class III, Temp Code: T5

 Meets applicable European Community directives.

**OPTIONAL ACCESSORIES:**

N/A

**PERFORMANCE CURVE**

**OUTPUT**
**RUNTIME**
**DISTANCE**
**INTENSITY**

FL1 STANDARD	HIGH	MEDIUM	LOW
	150 LUMENS	100 LUMENS	45 LUMENS
	3h	4h 30m	30h
	190m	160m	103m
	9250cd	6375cd	2750cd