



PRODUCT FACT SHEET

JR. REACH® LED ALKALINE BATTERY-POWERED FLASHLIGHT

MARKET APPLICATIONS: Premium Professional Light - Law Enforcement, Fire & Rescue, Automotive, Industrial, Outdoor, Consumer

DESCRIPTION: Ultra-compact, lightweight flashlight featuring a flexible cable protected by a durable silicone coating and the latest in power LED technology. The small compact head helps you get light into hard to reach places. Packaged with a magnetic clip holder for mounting and positioning the light.

CASE MATERIAL: Machined aircraft aluminum with anodized finish. Available in black.

DIMENSIONS: Length (O/A): 20.0 in. (50.80 cm) Diameter: Major Diameter: 0.80 in. (2.03 cm)
Body Diameter: 0.73 in. (1.85 cm)
Reach Length: 14.0 in. (35.6 cm) Folded Length: 9.0 in. (22.8 cm)

WEIGHT: 6.10 ounces (173 grams) with batteries (included with purchase).

LENS: Unbreakable polycarbonate lens.

LIGHT SOURCE: C4® LED technology, impervious to shock with a 50,000 hour lifetime.

LIGHT OUTPUT: Up to 1,600 candela peak central intensity and 85 lumens measured system output. Textured parabolic reflector produces an even, wide beam hotspot.

ON/OFF: Push button tail switch - momentary or constant on operation.

RUN TIME: 3.25 hours of runtime to the 10% output level.


FEATURES: C4® LED technology for extreme brightness.
Internal Reflection Optics
IPX4 rated for water resistant operation.
One meter impact resistance tested.
Maximum brightness throughout battery life.

BATTERY: Two (2) "AA" alkaline batteries; included in packaging

APPROVALS: CE Most models meet applicable European Community Directives.

WARRANTY: Streamlight's Limited Lifetime Warranty.

OPTIONAL ACCESSORIES: Magnetic Clip Holder, Pocket Clip

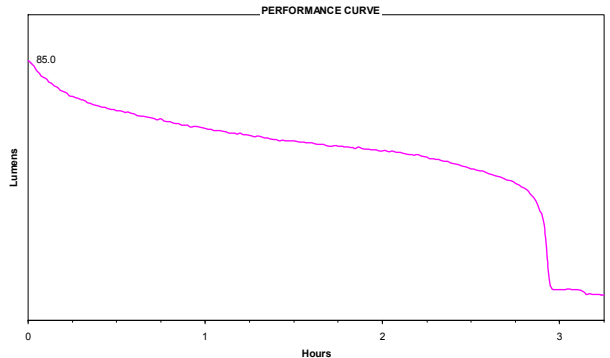

Made In China.