

**CONTINUOUS HINGE WITH 3-POINT LATCH, TYPE 4**

**INDUSTRY STANDARDS**

 UL 508A Listed; Type 4, 12, 13; File No. E61997  
 cUL Listed per CSA C22.2 No. 94; Type 4, 12, 13; File No. E61997

 NEMA/EEMAC Type 3, 4, 12, and 13  
 CSA, File No. 42186: Type 4 and 12  
 IEC 60529, IP66

**APPLICATION**

These time-tested, single-door enclosures feature Hoffman's exclusive padlocking POWERGLIDE Handle with 3-point latching for quick and convenient access. Ideal for indoor and outdoor applications, these rigid-bodied enclosures provide superior ease-of-access without sacrificing a secure seal.

**SPECIFICATIONS**

- 16 or 14 gauge steel
- Internal 3-point latch and padlocking POWERGLIDE Handle for quick, secure access
- Seamless foam-in-place gasket ensures a continuous seal
- 90-degree body flange opening channels away liquids
- External, welded-on mounting feet for easy installation
- Continuous hinge provides strength and ruggedness
- Removable heavy gauge stainless steel continuous hinge pin
- Seams continuously welded and ground smooth

**FINISH**

ANSI 61 gray

**ACCESSORIES**

See also *Accessories*.  
 LED Light Kits  
 Thermoelectric Cooler  
 Touch-Up Paint  
 Hole Seals

**MODIFICATION AND CUSTOMIZATION**


Hoffman excels at modifying and customizing products to your specifications. Contact your local Hoffman sales office or distributor for complete information.

**BULLETIN: A4W3**

Catalog Number	AxBxC in./mm	Body Gauge	Panel	Conductive Panel	Panel Size D x E in./mm	Data Pocket
A16H16ALP3PT	16.00 x 16.00 x 6.00 406 x 406 x 152	16	A16P16	A16P16G	13.00 x 13.00 330 x 330	Small
A20H16ALP3PT	20.00 x 16.00 x 6.00 508 x 406 x 152	16	A20P16	A20P16G	17.00 x 13.00 432 x 330	Small
A24H24ALP3PT	24.00 x 24.00 x 6.00 610 x 610 x 152	16	A24P24	A24P24G	21.00 x 21.00 533 x 533	Small
A20H16BLP3PT	20.00 x 16.00 x 8.00 508 x 406 x 203	16	A20P16	A20P16G	17.00 x 13.00 432 x 330	Small
A20H20BLP3PT	20.00 x 20.00 x 8.00 508 x 508 x 203	16	A20P20	A20P20G	17.00 x 17.00 432 x 432	Small
A24H20BLP3PT	24.00 x 20.00 x 8.00 610 x 508 x 203	16	A24P20	A24P20G	21.00 x 17.00 533 x 432	Small
A24H24BLP3PT	24.00 x 24.00 x 8.00 610 x 610 x 203	16	A24P24	A24P24G	21.00 x 21.00 533 x 533	Small
A30H24BLP3PT	30.00 x 24.00 x 8.00 762 x 610 x 203	14	A30P24	A30P24G	27.00 x 21.00 686 x 533	Small
A30H30BLP3PT	30.00 x 30.00 x 8.00 762 x 762 x 203	14	A30P30	A30P30G	27.00 x 27.00 686 x 686	Small
A36H30BLP3PT	36.00 x 30.00 x 8.00 914 x 762 x 203	14	A36P30	A36P30G	33.00 x 27.00 838 x 686	Small
A36H30CLP3PT	36.00 x 30.00 x 10.00 914 x 762 x 254	14	A36P30	A36P30G	33.00 x 27.00 838 x 686	Small
A36H30DLP3PT	36.00 x 30.00 x 12.00 914 x 762 x 305	14	A36P30	A36P30G	33.00 x 27.00 838 x 686	Small
A48H36DLP3PT	48.00 x 36.00 x 12.00 1219 x 914 x 305	14	A48P36	A48P36G	45.00 x 33.00 1143 x 838	Small
A60H36DLP3PT	60.00 x 36.00 x 12.00 1524 x 914 x 305	14	A60P36	A60P36G	57.00 x 33.00 1448 x 838	Large
A72H36DLP3PT	72.00 x 36.00 x 12.00 1829 x 914 x 305	14	A72P36	A72P36G	69.00 x 33.00 1753 x 838	Large
A48H36FLP3PT	48.00 x 36.00 x 16.00 1219 x 914 x 406	14	A48P36	A48P36G	45.00 x 33.00 1143 x 838	Large
A60H36FLP3PT	60.00 x 36.00 x 16.00 1524 x 914 x 406	14	A60P36	A60P36G	57.00 x 33.00 1448 x 838	Large
A72H36FLP3PT	72.00 x 36.00 x 16.00 1829 x 914 x 406	14	A72P36	A72P36G	69.00 x 33.00 1753 x 838	Large
A60H36GLP3PT	60.00 x 36.00 x 18.00 1524 x 914 x 457	14	A60P36	A60P36G	57.00 x 33.00 1448 x 838	Large
A72H36GLP3PT	72.00 x 36.00 x 18.00 1829 x 914 x 457	14	A72P36	A72P36G	69.00 x 33.00 1753 x 838	Large

Catalog Number	AxBxC in./mm	Body Gauge	Panel	Conductive Panel	Panel Size D x E in./mm	Data Pocket
A60H36JLP3PT	60.00 x 36.00 x 24.00 1524 x 914 x 610	14	A60P36	A60P36G	57.00 x 33.00 1448 x 838	Large
A72H36JLP3PT	72.00 x 36.00 x 24.00 1829 x 914 x 610	14	A72P36	A72P36G	69.00 x 33.00 1753 x 838	Large

Purchase panels separately.

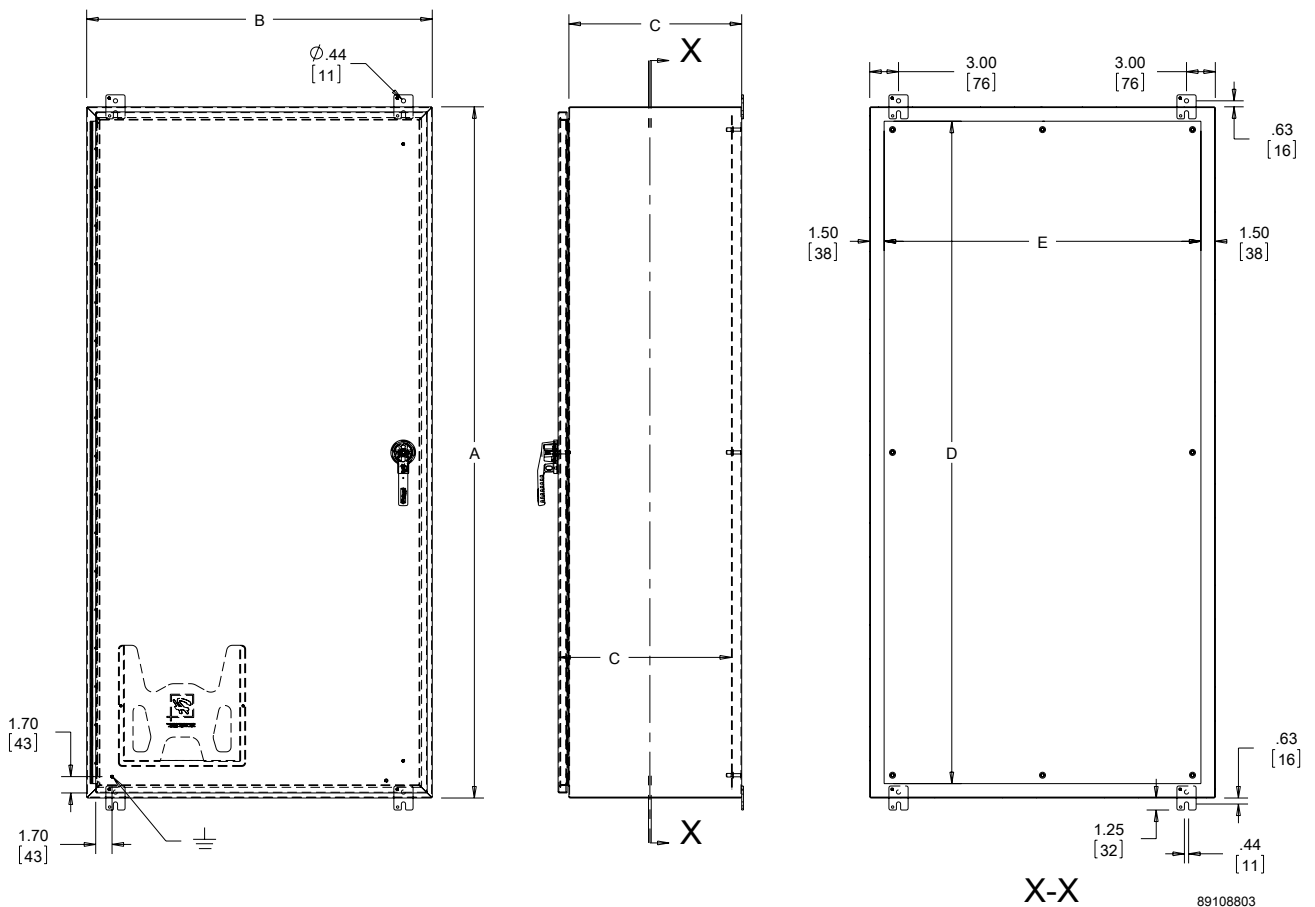

89108803