



PRODUCT FACT SHEET

STINGER® LED or STINGER DS® LED RECHARGEABLE FLASHLIGHT

MARKET

APPLICATIONS: Law Enforcement, Sporting Goods, Security, Fire & Rescue, Hardware/Tool, Automotive, Industrial, Consumer

DESCRIPTION:

Compact & extremely powerful, the Stinger® LED and Stinger DS® LED rechargeable flashlights offer 3 microprocessor controlled intensity modes, strobe mode and the latest in power LED technology. The Stinger DS® LED includes a second independent easy to locate tactical tailcap switch. The combination of rechargeable batteries and the C4® LED results in one of the lowest operating costs of any flashlight made.

CASE MATERIAL:

6000 series machined aircraft aluminum with non-slip rubberized comfort grip with anti-roll rubber ring.

DIMENSIONS:

Stinger® LED Length: 8.41 in. (21.36 cm)

Diameter: Major Diameter: 1.62 in. (4.11 cm)

Stinger DS® LED Length: 8.85 in. (22.48 cm)

Body Diameter: 1.17 in. (2.97 cm)

WEIGHT:

Stinger® LED: 12.4 oz (352 grams)*

Stinger DS® LED: 12.8 oz (364 grams)*

LENS:

Unbreakable polycarbonate with scratch-resistant coating. O-ring sealed.

LIGHT SOURCE:

C4® LED technology, impervious to shock with a 50,000 hour lifetime.

LIGHT OUTPUT:

See Chart. Optimized electronics provides regulated intensity.

Deep-dish parabolic reflector produces a concentrated beam with optimum peripheral illumination.



ON/OFF:

Multi-function, easy access head mounted push-button switch designed for extremely long life; tested at 1 million actuations. Stinger DS® LED provides a second multi-function push-button tactical tailswitch where both switches offer full feature control independent of each other.

RUN TIME:



See Chart. Strobe: 5.50 continuous hours.

BATTERY:

3-cell, 3.6 Volt Ni-Cd sub-C battery, rechargeable up to 1000 times.

3-cell, 3.6 Volt Ni-MH sub-C battery, rechargeable up to 1000 times offered in 230VAC and 12VDC European systems.

CHARGING:

Fits existing Stinger®chargers. Steady charger fully recharges in 10 hours on 100V, 120V, 230V or 240VAC, or 12VDC. 2.5 hour fast charger or PiggyBack® charger models available.

FEATURES:



C4® LED technology for extreme brightness.

IPX4 Rated for water resistant operation.

1 meter impact resistance tested.

Serialized for positive identification.

LED Charge-continuity indicator on charger base.

Compact, snap-in charger mounts in any position.

WARRANTY:


Streamlight's Limited Lifetime Warranty.

APPROVALS:

Meets applicable European Community Directives.

OPTIONAL ACCESSORIES:

Safety wands, ring holder, holster, color filters, 5-unit bank charger, 2.5 hour fast charger, or Piggy-Back® charger that allows for simultaneous charging of light and battery.

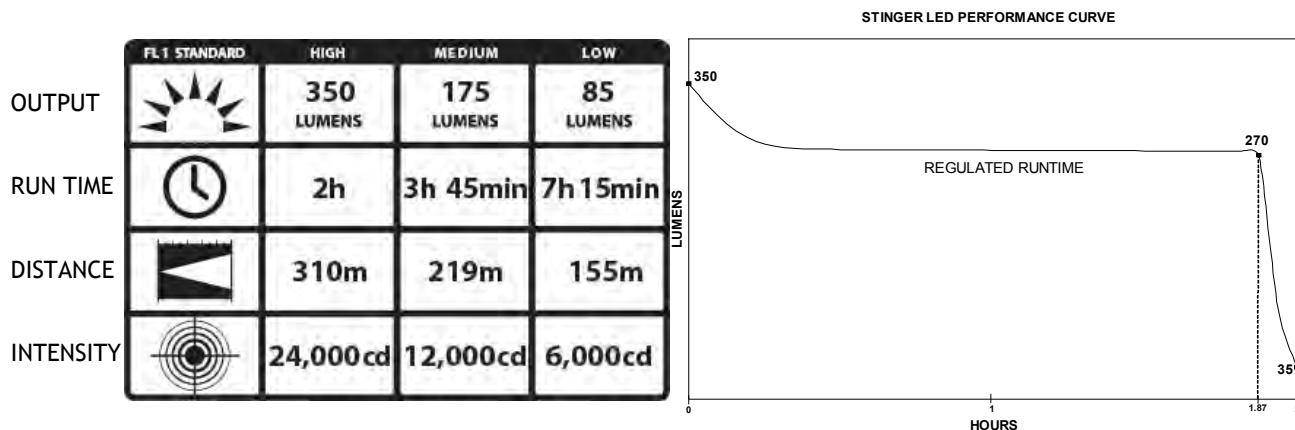

* With battery (included in purchase)

All performance claims to ANSI/NEMA FL1-2009 Standard

Issued: 10/13/06

Revised: 09/11/12 Rev: 8

Assembled In The USA.

Document #201