



PRODUCT FACT SHEET

STINGER® HPL™ OR STINGER DS® HPL™

HIGH LUMEN LONG RANGE RECHARGEABLE FLASHLIGHT

MARKET

APPLICATIONS:

Law Enforcement, Sporting Goods, Security, Fire & Rescue, Hardware/Tool, Automotive, Industrial, Consumer

DESCRIPTION:

Compact & extremely powerful, the Stinger® HPL™ and Stinger DS® HPL™ rechargeable flashlights offer 3 microprocessor controlled variable intensity modes, strobe mode and the latest in high power LED technology. The Stinger DS® HPL™ includes a second independent easy to locate tactical tailcap switch. The combination of rechargeable batteries and the C4®LED results in one of the lowest operating costs of any flashlight made.

CASE MATERIAL:

6000 series machined aircraft aluminum with non-slip rubberized comfort grip.

DIMENSIONS:

Stinger® HPL™ Length: 9.23 in. (23.44 cm)

Diameter: Major Diameter: 2.20 in. (5.59 cm)

Stinger DS® HPL™ Length: 9.65 in. (24.51 cm)

Body Diameter: 1.17 in. (2.97 cm)

WEIGHT:

Stinger® HPL™: 13.6 oz (385 grams)*

Stinger DS® HPL™: 14.0 oz (396 grams)*

LENS:

Unbreakable polycarbonate with scratch-resistant coating. O-ring sealed.

LIGHT SOURCE:

C4®LED technology, impervious to shock with a 50,000 hour lifetime.

LIGHT OUTPUT:



See Chart. Optimized electronics provides regulated intensity.

Deep-dish parabolic reflector produces a long range targeting beam with optimum peripheral illumination.

ON/OFF:

Multi-function, easy access head mounted push-button switch designed for extremely long life; tested at 1 million actuations. Stinger DS® HPL™ provides a second multi-function push-button tactical tailswitch where both switches offer full feature control independent of each other.

RUN TIME:



See Chart. All claims to 10% of initial lumen output. Strobe: 3 continuous hours.

BATTERY:

3-cell, 3.6 Volt Ni-MH sub-C battery, rechargeable up to 1000 times.

CHARGING:

Fits existing Stinger®chargers. Steady charger fully recharges in 10 hours on 100V, 120V, 230V or 240VAC, or 12VDC. 2.5 hour fast charger or PiggyBack® charger models available.

FEATURES:



C4®LED technology for extreme brightness.

IPX4 Rated for water resistant operation.

3 meter impact resistance tested.

Serialized for positive identification.

LED Charge-continuity indicator on charger base.

Compact, snap-in charger mounts in any position.

WARRANTY:

Streamlight's Limited Lifetime Warranty.

APPROVALS:


N/A

OPTIONAL

ACCESSORIES:

Safety wands, Ring holder, 5-unit bank charger, 2.5 hour fast charger, or Piggy-Back® charger that allows for simultaneous charging of light and battery.

	FL1 STANDARD	HIGH	MEDIUM	LOW
OUTPUT		740 LUMENS	380 LUMENS	190 LUMENS
RUN TIME		1h 15min	2h 30min	4h 30min
DISTANCE		438m	310m	219m
INTENSITY		48,000cd	24,000cd	12,000cd

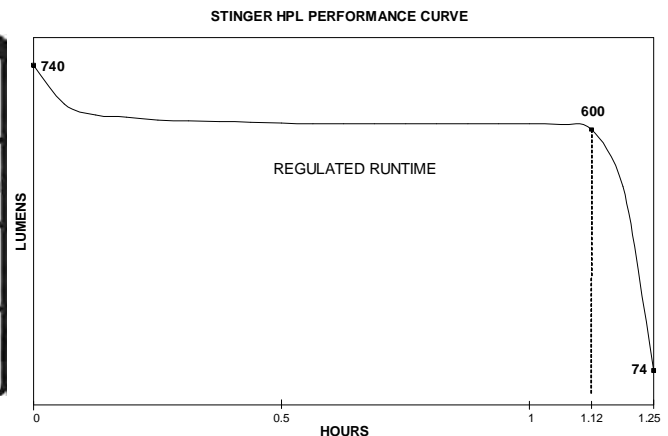

* With battery (included in purchase)

All performance claims to ANSI/NEMA FL1-2009 Standard

Issued: 10/31/2014

Revised:

Rev: 0

Assembled In The USA.

Document #230