

UNIVERSAL

Compression Connector to Cable Cross Reference Chart

Snap-N-Seal

DB Double Bubble™

CP CABLE PRO.™

25-26 AWG CONNECTOR		CABLE			
Center Conductor:	.015 ~ .025	Belden	Liberty	Tappan	West Penn
Dielectric:	.065 ~ .078				
Outer Jacket:	.095 ~ .110				
Snap-N-Seal	Double Bubble	1277P-R, 1278P-R, 1279P-R, 1280P-R 1281R-S3-S4-S5-S6 1282R-S3-S4-S5-S6 1283S3-S5-S6 HC2648R, HC2650R	AVC-6-PLN* AVC-14-PLN* AVC-18-PLN* RGB5C-PLN* RGB5C-25-CMP	H91925 H91946 H91924 H91930	253CRGB 255CRGB 3CRGB 5CRGB WP258255 WP258263 WP258265
FS1BNC, FS1RCA FSBNC1RGB* FSRCA1RGB* FS1BNCST* FS1RCASST* FSBNC1RA*	DB1BNCHD DB1RCA				

* = multi-piece connector for stranded or solid center conductor

Snap-N-Seal

DB Double Bubble™



22-24 AWG CONNECTOR		CABLE					
Center Conductor:	.015 ~ .025	Belden	Coleman	Commscope	General	Liberty	West Penn
Dielectric:	.095 ~ .105						
Outer Jacket:	.145 ~ .160						
Snap-N-Seal	Double Bubble	1164B*, 1167B*	99401	7538	395031	23-YCLLSIAM	2825
FS15, FS15BNC FS15RCA FSBNC15RGB* FSRCA15RGB* FS15BNCST* FS15RCASST* FSBNC15RA*	DB1BNCHD DB1RCA	1371P, 13712R	99403	7538-B		RGB5C-SOL-MINI	25825
		1406B*, 1407B*	99405				45825
		1417B*, 1418B*	99415				825
		1855A, 1855S3	99425				HD25825
		1855S5, 1855S6	99426				HD825
		573945, 673948	993211				WP8253*
		7787A, 7788A, 7789A					WP8255*
		7790A, 7791A, 7792A					
		7794A, 7796A, 8218*					

* = multi-piece connector for stranded or solid center conductor

Snap-N-Seal


DB Double Bubble™



RG11 CONNECTOR		CABLE					
Center Conductor:	.0634 ~ .0647	Belden	Coleman	Commscope	CSC	Tappan	West Penn
Dielectric:	.280 ~ .294						
Outer Jacket:	.390 ~ .417						
Snap-N-Seal		1153A, 1523A, 1525A	821010	2287K	200210	C60003	811
		1617A, 1618A, 3094A	992153		211300	C60006	821
716SNS1P11H, 716SNS1P11HQ		7731A*, 8213, 9011	992155		211198	C60008	Q821
FSNS11HBNC, FSNS11HQBNC		9064, 9764	992161				25Q821
90SNS1P11H			991037				

* = 7731A uses 716SNS1P11HQ or FSNS11HQBNC

Snap-N-Seal

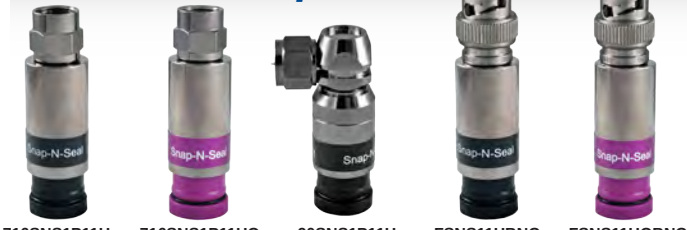

RG59 CONNECTOR			CABLE								
Center Conductor:		.0317 ~ .0339	Belden	Coleman	Commscope	CSC	General	Genesis	Liberty	Tappan	West Penn
Dielectric:		.144 ~ .157									
Outer Jacket:		.232 ~ .273									
Snap-N-Seal		Double Bubble	1186A, 1505A	92074	5565	212053	395025	5001, 5013	RG59CCS-	20RG59FM/CM	2815B
			1505A-S3-S5-S6	92094	F5967BVV	212305	395030	5052, 5301	BLK	20RG59FM+18/2/CM	WP8195
			1505F, 8221, 8263	99501	F5995BVV	211301	C8028				
			9100, 9104, 9104P	993253		862730					
			9110, 9167, 9244, 9259								
			9275, 82108, 543945								
FSNS59U	FS59BNCUS	DB59U									
FSNS59BNCU	FS59RCAUS	DB59BNCU									
FSNS59RCAU	FS59IECUF	DB59RCAU									
FSRCA59URA	FS59IECUM	DB59BNCHD									

Snap-N-Seal

DB Double Bubble™



RG6 CONNECTOR		CABLE								
Center Conductor:	.0399 ~ .0418	Belden	Coleman	Commscope	CSC	General	Genesis	Liberty	Tappan	West Penn
Dielectric:	.180 ~ .193									
Outer Jacket:	.265 ~ .305									
Snap-N-Seal	Double Bubble	152A, 1189A*, 1190A, 1530A, 1532A 1613A, 1614A, 1694A, 1840A, 1843A 1829A, 3092A, 3093A, 3131A 533945, 5339B5, 5339G5, 5339W5 5399B5, 6339Q8, 7710A, 7711A 7712A, 7713A, 7915A, 7916A 7916AP, 9058, 9062, 9066, 9077 9116, 9116R, 9118, 9248, 9290, 82120	92001, 92003 92008, 92041 92042, 92045 92049, 99601 192061, 192115 920036, 920414 992132, 992479 993267	5738 5740* F660BVV F677TSVV F6SSVV*	200201 200206 211010 211011 211015 791224 862729 878945	C5761 C5775 C5776 C5785 C5786 C5789 C8029	5002, 5003, 5007 5008, 5010, 5011 5012, 5021, 5027 5050, 5051, 5055 5060, 5061, 5066 5067, 5302, 5303 5307, 5361	QUADFLEX* 18-CMR-SD-BLK	C40009, C40055 C40065, C40076 C40168, C40181 D40019 H90454 H90767 SU4020 SU4021	806 25Q841*, 2806B 6100, 6300 6310, 6350 AQC806, AQC841 AQC2806, Q841* WP6354, WP6355
FSNS6U FSNS6BNCU FSNS6RCAU FSNS1P6QS	DB6U DB6BNCU DB6RCAU DB6BNCHD									

*= use QS connectors

Snap-N-Seal

DB Double Bubble™



Select Snap-N-Seal® ProSNS® & Double Bubble™ connectors are also available in retail packaging when ordered with [Part Number]-R.

BELDEN
SENDING ALL THE RIGHT SIGNALS™

8285 Tournament Drive
Memphis, TN 38125, USA
Customer Support: 800.685.9452
Fax: 901.748.4308
www.belden.com
ccscustomerservice@belden.com

PLENUM

Compression Connector to Cable Cross Reference Chart

Snap-N-Seal

DB Double Bubble™

CABLE PRO.

RG59 SECURITY/CCTV CONNECTOR		CABLE						
Center Conductor:	.0317 ~ .0339	Belden	Coleman	Commscope	General	Genesis	Tappan	West Penn
Dielectric:	.130 ~ .148							
Outer Jacket:	.232 ~ .248							
Snap-N-Seal	Double Bubble	1426A, 8212, 8221	92004, 92074	2054V, 5550	C1104, C1135	5001, 5009	C30022	804, 814, 815
FSNS59BNC SL	DB59BNC SL	9240, 9265, 9659	991055, 991057	5553, 5554	C1142, C8025	5013, 5103	H90369	819, 2814
	DB59RCASL	543945, 5439W5	993251, 993263		C8027, C8028	5104		AQC815
		549945						AQC819

Snap-N-Seal

DB Double Bubble™



FSNS59BNC SL



DB59BNC SL



DB59RCASL

RG59 PLENUM CONNECTOR		CABLE							
Center Conductor:	.0317 ~ .0339	Belden	Coleman	Commscope	CSC	General	Genesis	Tappan	West Penn
Dielectric:	.130 ~ .157								
Outer Jacket:	.190 ~ .220								
Snap-N-Seal	Double Bubble	1370P, 1370R	99969	2020K-V	221105	C3500	5351	D30009	25815
FSNS59PL	DB59PL2	1506A	99979	2036K-V	221125	C3526	5355	D30124	25819
FSNS59BNC PL	DB59BNC PL2	8279	993236		592002	C8030		H90224	25Q843
FSNS59RCAPL	DB59RCAPL2	82259	993256		861159	495023			
	DB59PL2/4	89108			862732	495028			
	DB59BNC PL2/4	643948				495044			
	DB59RCAPL2/4	649948							
		6439C8							

Snap-N-Seal

DB Double Bubble™



FSNS59BNC PL



FSNS59PL



FSNS59RCAPL



DB59BNC PL2



DB59PL2



DB59RCAPL2

RG59 PLENUM SIZE 3 CONNECTOR		CABLE	
Center Conductor:	.0210 ~ .0240	Belden	Liberty
Dielectric:	.130 ~ .137		
Outer Jacket:	.190 ~ .220		
Snap-N-Seal	Double Bubble	82241	RG59-CCTV-PL-WHT
FSNS59BNC PL3	DB59BNC PL3	88241	
FSNS59RCAPL3	DB59RCAPL3		

Snap-N-Seal

DB Double Bubble™



FSNS59BNC PL3



FSNS59RCAPL3



DB59BNC PL3



DB59RCAPL3

ITS CONNECTOR

CABLE

Center Conductor:
Dielectric:
Outer Jacket:

Belden

General

West Penn

Double Bubble

DB59BNC SL2-M

DB59BNC SL2-F

8281

8281B

C5816

P806

DB Double Bubble™



DB59BNC SL2-M



DB59BNC SL2-F

DBDS3BNC CONNECTOR		CABLE	
Center Conductor:	.014 ~ .020	Belden	Comm-scope
Dielectric:	.070 ~ .085		
Outer Jacket:	.120 ~ .140		
Double Bubble		735A	73501
DBDS3BNC			

DBDS4BNC CONNECTOR		CABLE	
Center Conductor:	.0317 ~ .0399	Belden	Comm-scope
Dielectric:	.145 ~ .155		
Outer Jacket:	.220 ~ .240		
Double Bubble		734D1	734S1
DBDS4BNC		734D1T	

DBDS4BNC PL CONNECTOR		CABLE	
Center Conductor:	.0317 ~ .0399	Belden	Comm-scope
Dielectric:	.145 ~ .155		
Outer Jacket:	.205 ~ .240		
Double Bubble		734A1P	734CIP
DBDS4BNC PL			

DB Double Bubble™



DBDS3BNC



DBDS4BNC



DBDS4BNC PL

RG11 CONNECTOR		CABLE				
Center Conductor:	.0634 ~ .0647	Belden	Coleman	CSC	Tappan	West Penn
Dielectric:	.274 ~ .294					
Outer Jacket:	.339 ~ .355					
Snap-N-Seal		1399P, 1399R	821013	220500	D60001	25811
716SNS1P11HPLA		7732A, 9292		220502	D90011	25821
FSNS11HBNCPLA		89289, 613948				
		6139B8				

Snap-N-Seal



716SNS1P11HPLA



FSNS11HBNCPLA



Select Snap-N-Seal® ProSNS® and Double Bubble™ connectors are also available in retail packaging when ordered with [Part Number]-R.

* = required for RG11 connectors

CABLE PRO®
INSTALLATION TOOLS

Snap-N-Seal

DB Double Bubble™



CPLCCT-SLM



CPSNSCT-596



CPLCCT-LS59/11*



CPLCRBC-BR



PSA59/6



PS59/6/RGB



PS11

RG6 PLENUM CONNECTOR		CABLE							
Center Conductor:	.0339 ~ .0418	Belden	Coleman	Commscope	CSC	General	Genesis	Tappan	West Penn
Dielectric:	.165 ~ .172								
Outer Jacket:	.220 ~ .250								
Snap-N-Seal	Double Bubble	1369P, 1369R	921003	2275K-V	220400	C3521	5352	D40012	25806
FSNS6PL	DB6PL2	1530AP, 1695A	921005	2277K-V	220402	C3523	5353	D40018	25841
FSNS6BNC PL	DB6BNC PL2	9116P	921007	2279K-V	862733	C3524		D40045	256350
FSNS6RCAPL	DB6RCAPL2	82120, 82248	921009	F660BVR	862734	C3525		H90061	25T841
		87120, 89120	921015			C8031		H90794	
		89248, 633938	921017			495025			
		633948, 639948	993265			495035			
		86120/633				495036			

RG6 PLENUM CONNECTOR Quad Shield		CABLE			
Center Conductor:	.0339 ~ .0418	Belden	Coleman	Comm-scope	West Penn
Dielectric:	.165 ~ .172				
Outer Jacket:	.245 ~ .275				
Snap-N-Seal		1152A	921019	2227	25Q841
FSNS6PLQ		1189AP			
FSNS6BNC PLQ		3093A			
FSNS6RCAPLQ		3132A			

Snap-N-Seal

DB Double Bubble™



FSNS6BNC PL



FSNS6PL



FSNS6RCAPL



DB6BNC PL2



DB6PL2



DB6RCAPL2

Actual cable sizes may vary from manufacturer specifications, and testing may be required to verify proper connector fit.

Belden Customer Support 1.800.685.9452

www.belden.com

©Copyright 2013, Belden Inc.

Rev. A082313