


Holemaking Products & Accessories

For Professionals... Since 1857™

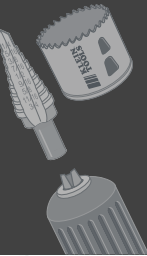

Flexible Drill Bits

Flex Bit Augers

- Used to drill holes through wood within a wall.
- Tapered back for easy bit retrieval.
- Spring steel shaft resists deformation.
- Screw point tip pulls the bit through wood.
- Hole in tip allows for use with wire or cable pulling grip.

Cat. No.	Length	Weight (lbs.)
53716	3/8" x 54" (9.5 mm x 1372 mm)	1.00
53717	3/8" x 72" (9.5 mm x 1829 mm)	1.00
53718	9/16" x 54" (14 mm x 1372 mm)	1.00
53719	3/4" x 54" (19 mm x 1372 mm)	2.00
53751	3/4" x 72" (19 mm x 1829 mm)	2.00
53720	1" x 54" (25 mm x 1829 mm)	2.00



 
53719



53720



53719



53718

53716

Flex Bit Extensions

- Connects to the end of a flex bit and extends the length.



53722

Cat. No.	For Use with Flex Bits	Length	Connection Diameter	Weight (lbs.)
53722	3/4" and larger	54" (1372 mm)	5/8" (14 mm)	1.00
53723	9/16" and smaller	54" (1372 mm)	7/16" (11 mm)	1.00

Flex Bit Placement Tool

- For use with flexible drill bits.
- Positions flexible drill bits horizontally or vertically within a wall.
- Cushion Grip handle for non-slip comfort.
- Folding design stores more compactly than standard tool.



53715-SEN

Cat. No.	Length	Weight (lbs.)
53715-SEN	11" (279 mm)	1.00

Pulling Grips

Pulling Grips

- Used to pull wire or cable through walls.
- Pulling grip attaches to the hole in the tip of the flex bit; wire mesh holds the wire during the pull.
- Swivel end helps reduce twisting.



KPS050-SEN



KPS075-SEN

Cat. No.	Capacity	Maximum Safe Load	Weight (lbs.)
KPS050-SEN	1/2" - 9/16" (12 mm - 14 mm)	100 lb	.07
KPS075-SEN	3/4" - 1" (19 mm - 25 mm)	185 lb	.11

WARNING: Do not exceed maximum safe load as listed on the label attached to the product.

WARNING: Always match proper size and type of grip to application.

WARNING: Always inspect equipment before use.

All dimensions are in inches and (millimeters).



NOTE: Read and follow safety instructions in power tool owner's manual.

www.kleintools.com

See page 296 for additional information on warnings.

Flex Bit Kit

Flex Bit Kit

- 3-piece kit includes folding placement tool, 1/2"-9/16" O.D. pulling grip and 9/16" x 54" flexible drill bit.
- Everything you need to pull up to 9/16" O.D. wire.
- Complete kit used for drilling and pulling wire and cable.
- Use placement tool (Cat. No. 53715-SEN) to guide bit through walls.
- Flexible drill bit (Cat. No. 53718) makes 9/16" holes in wood.
- Pulling grip (Cat. No. KPS050-SEN) attaches to the flexible drill bit after the hole has been made and pulls 1/2" – 9/16" wire and cable.

Cat. No.	Kit Contains	Weight (lbs.)
53721		2.00
Cat. No.	Description	
53715-SEN	flex bit placement tool	
53718	flex drill bit - 9/16" x 54" (14 mm x 1372 mm)	
KPS050-SEN	pulling grip - 1/2"-9/16" (12 mm - 14 mm)	



53721

Hole Saws

NEW!

Bi-Metal Hole Saws

- Optimized for cutting steel including stainless steel.
- Cuts precise holes in stainless steel and mild steel, drywall, ceiling tile, laminates, wood and plastic.
- Longest lasting, fastest cutting blade on the market.
- Heavy-duty steel construction includes 5 mil back plate to withstand abuse.
- The smallest hole saws feature hex-shaped base for easy removal from arbor.



31932

31922

31918

31914 with
31905 arbor

Cat. No.	Saw Diameter	Pipe Tap Size*	Pipe Entrance Size**	For use with Arbor No.	Weight (lbs.)
31914	7/8" (22 mm)	3/4" (19 mm)	1/2" (13 mm)	31905	.06
31918	1-1/8" (29 mm)	1" (25 mm)	3/4" (19 mm)		.08
31922	1-3/8" (35 mm)	–	1" (25 mm)	31905 or 31906	.12
31928	1-3/4" (44 mm)	1-1/2" (38 mm)	1-1/4" (32 mm)	31906	.12
31932	2" (51 mm)	–	1-1/2" (38 mm)		.13
31940	2-1/2" (64 mm)	–	2" (51 mm)		.17
31944	2-3/4" (70 mm)	–	–		.19
31948	3" (76 mm)	–	2-1/2" (64 mm)		.22
31958	3-5/8" (92 mm)	–	3" (76 mm)		.29
31972	4-1/2" (114 mm)	–	4" (102 mm)		.40
31900	6-3/8" (162 mm)	–	6" (152 mm)		2.00

* Pipe Tap Size – The sizes listed provide the necessary information whenever a pipe is to be threaded into tanks, boilers, etc. To secure the best results, the hole should be reamed before tapping with a reamer having a taper of 3/4" per foot.

** Pipe Entrance Size – The sizes listed provide the necessary information for any given pipe size to have sufficient clearance to pass through beams, walls, bulkheads, etc.



Multiple slots provide different leverage points to easily remove material.



NOTE: Read and follow safety instructions in power tool owner's manual.


www.kleintools.com

See page 296 for additional information on warnings.

Hole Saws

Hole-Saw Arbors and Accessories

- Cat. No. 31905 is for use with all Klein hole saws.
- Cat. No. 31906 is for use with Klein hole saws 1-3/8" to 6-6/8" (35 mm- 162 mm).
- Fast and easy to engage and disengage hole saws.
- Steel construction for long life.
- 118° split point pilot bits.
- 31905 includes arbor adaptor for 5/8"-18.
- Hardened mandrels for long thread life.

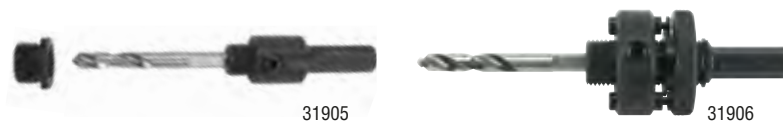

Cat. No.	Shank Style	Pins	Shank Size	Electric Drill Size	Thread Size	Weight (lbs.)
31905	hexagonal	N	3/8" (10 mm)	1/2" and larger	1/2" - 20	.16
31906	hexagonal	Y	7/16" (11 mm)	1/2" and larger	5/8" - 18	.16
Replacement Pilot Drills for Hole-Saw Arbors						
31907	1/4" Replacement Pilot Drill Bit, 1/4" x 3-1/4"					.02

Electrician's Hole Saw Kit

NEW!

- Optimized for cutting steel. Also cuts stainless steel.
- Cuts precise holes in stainless steel and mild steel, drywall, ceiling tile, laminates, wood and plastic.
- Longest lasting, fastest cutting blade on the market.
- Heavy-duty steel construction includes 5 mil back plate to withstand abuse.
- Hex-shaped base for easy removal from arbor.
- Contains the most popular sizes for basic electrical work.
- All components are packed in a rust-proof, molded plastic carrying case.

Cat. No.	Set Contains	Weight (lbs.)																																
31902		2.60																																
<table><tr><th colspan="2">Hole Saws</th><th colspan="2">Arbors</th></tr><tr><th>Cat. No.</th><th>Size</th><th>Cat. No.</th><th>Size</th></tr><tr><td>31914</td><td>7/8" (22 mm)</td><td>31905</td><td>3/8" (10 mm)</td></tr><tr><td>31918</td><td>1-1/8" (29 mm)</td><td>31906</td><td>3/8" (10 mm)</td></tr><tr><td>31922</td><td>1-3/8" (35 mm)</td><td></td><td></td></tr><tr><td>31928</td><td>1-3/4" (44 mm)</td><td></td><td></td></tr><tr><td>31932</td><td>2" (52 mm)</td><td></td><td></td></tr><tr><td>31940</td><td>2-1/2" (64 mm)</td><td></td><td></td></tr></table>		Hole Saws		Arbors		Cat. No.	Size	Cat. No.	Size	31914	7/8" (22 mm)	31905	3/8" (10 mm)	31918	1-1/8" (29 mm)	31906	3/8" (10 mm)	31922	1-3/8" (35 mm)			31928	1-3/4" (44 mm)			31932	2" (52 mm)			31940	2-1/2" (64 mm)			
Hole Saws		Arbors																																
Cat. No.	Size	Cat. No.	Size																															
31914	7/8" (22 mm)	31905	3/8" (10 mm)																															
31918	1-1/8" (29 mm)	31906	3/8" (10 mm)																															
31922	1-3/8" (35 mm)																																	
31928	1-3/4" (44 mm)																																	
31932	2" (52 mm)																																	
31940	2-1/2" (64 mm)																																	



Adjustable Hole Saw

- Quickly and smoothly cuts cleaner holes in drywall and ceiling tiles.
- Blades adjust to cut holes from 2" to 7" in diameter.
- Fits most 3/8" and 1/2" drill chucks.
- No binding while cutting.
- No additional tools needed to adjust the hole saw.
- Dust shield catches ceiling debris (2 included).
- Hex key included.

Cat. No.	Range	Weight (lbs.)
53731	2" - 7" (51 mm - 177 mm)	.31



All dimensions are in inches and (millimeters).



NOTE: Read and follow safety instructions in power tool owner's manual.

www.kleintools.com

See page 296 for additional information on warnings.

Carbide-Tipped Hole Cutters

Carbide Hole Cutters

- Cuts quick, precise holes in stainless steel, mild steel, iron, copper and brass sheet up to 3/16" (5 mm) thick.
- Smooth start pilot drill bit for greater control.
- Split point pilot drill bit prevents bit walking.
- Integrated flange prevents the operator from drilling beyond the sheet metal.
- Ejection spring for easy slug removal.



31860

Cat. No.	Size	Conduit & Pipe Sizes	Weight (lbs.)
31850	3/4" (19 mm)	—	.25
31852	7/8" (22 mm)	1/2"	.30
31856	1-1/8" (29 mm)	3/4"	.40
31860	1-3/8" (35 mm)	1"	.45
31866	1-3/4" (44 mm)	1-1/4"	.70
31868	2" (51 mm)	1-1/2"	.80
31870	2-1/2" (64 mm)	2"	.95
Replacement Parts			
31874	replacement hole cutter pilot bit		.05

4-Piece Carbide Hole Cutter Kit

Conduit and pipe sizes: 1/2"- 1"

Cat. No.	Set Contains	Weight (lbs.)
31872		1.45
	Cat. No.	Size
	31852	7/8" (22 mm)
	31856	1-1/8" (29 mm)
	31860	1-3/8" (35 mm)
	31874	pilot bit



31872

8-Piece Master Electrician's Hole Cutter Kit

Conduit and pipe sizes: 1/2"- 2"

Cat. No.	Set Contains	Weight (lbs.)
31873		4.30
	Cat. No.	Size
	31852	7/8" (22 mm)
	31856	1-1/8" (29 mm)
	31860	1-3/8" (35 mm)
	31866	1-3/4" (44 mm)
	31868	2" (51 mm)
	31870	2-1/2" (64 mm)
	31874	2 pilot bits



31873


All dimensions are in inches and (millimeters).



NOTE: Read and follow safety instructions in power tool owner's manual.

www.kleintools.com

See page 296 for additional information on warnings.

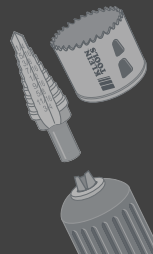

Knockout Punches

Knockout Punch Set

- Optimized design reduces wrench effort.
- Slugs are split inside for easy removal.
- Maximum capacity of 10 gauge mild steel. Also cuts aluminum, fiberglass and plastic.
- Punches holes cleanly and accurately.
- Set includes 1/2" or 3/4" punch and die with draw stud.

Cat. No.	Overall Length	Conduit Size	Weight (lbs.)
53727-SEN	4" (102 mm)	3/4" (19 mm)	.98
53728-SEN	2-5/8" (67 mm)	1/2" (12.5 mm)	.45



53727-SEN



53728-SEN

NOTE: Lubricate threads before each use.

Knockout Punch Set with Wrench

- Set includes: 1" ratcheting wrench, knockout punches, dies and draw studs for 1/2", 3/4", 1", 1-1/4", 1-1/2", and 2" conduit sizes.
- Cutting capacity 10 gauge mild steel; also cuts aluminum, fiberglass and plastic.
- Splits slugs for easy removal.
- Punches holes cleanly and accurately.
- Kit includes six different size knockout punches and dies, two draw studs and one ratcheting box end wrench.



53732-SEN

Cat. No.	Weight (lbs.)
53732-SEN	9.00

Punch Cat. No.	Die Cat. No.	Description	Conduit Size
53819	53820	knockout punch	1/2" (13 mm)
53827	53828	knockout punch	3/4" (19 mm)
53837	53838	knockout punch	1" (25 mm)
53849	53850	knockout punch	1-1/4" (32 mm)
53857	53858	knockout punch	1-1/2" (38 mm)
53867	53868	knockout punch	2" (51 mm)
Cat. No.		Description	Size
53873		ratcheting wrench	1" (25 mm)
53871		draw stud	3/8" x 2-5/8" (9.5 mm x 67 mm)
53872		draw stud	3/4" x 4" (19 mm x 102 mm)

NOTE: Lubricate threads before each use.



All dimensions are in inches and (millimeters).



NOTE: Read and follow safety instructions in power tool owner's manual.

www.kleintools.com

See page 296 for additional information on warnings.

Step Drill Bits

NEW!

Double-Fluted High-Speed Step Drill Bits

- Faster drilling than single flute bits.
- Easy-to-read step rings save time when drilling common holes.
- Fast-starting, non-walking drill tip.
- Thick, extra-long 3/8" hex shank provides a firm, positive grip in the drill and won't spin out.



High-visibility silver step rings!

Cat. No.	Quick Reference	No. of Holes	Increment	Hole Size Range	Weight (lbs.)
KTSB01	#1	13	1/32"	1/8" – 1/2" (3 mm – 13 mm)	.05
KTSB03	#3	9	1/16"	1/4" – 3/4" (6 mm – 19 mm)	.15
KTSB11	#11	2	–	7/8" – 1-1/8" (22 mm – 29 mm)	.30
KTSB14	#14	12	1/16"	3/16" – 7/8" (5 mm – 22 mm)	.15
KTSB15	#15	3	–	7/8", 1-1/8", 1-3/8" (22, 29, 35 mm)	.46



Wood Boring

NEW!

Wood Boring Bits with Screw Point



- Superior to auger bits.
- Low-torque design greatly reduces the wrist fatigue from standard auger bits.
- Easily change direction when drilling holes to customize the shape.
- Unique head shape minimizes chatter while drilling versus ordinary paddle bits.
- The extra durable pilot screws are hardened to last longer.
- Easy-to-sharpen blades.
- Easy-to-replace pilot screw shaft spin out.

Cat. No.	Hole Size	Shaft Dia.	Hex End	Shaft Length	Weight (oz.)
53932	7/8" (22 mm)	3/8" (9.5 mm)	5/16" (8 mm)	6" (152 mm)	4.5
53934	1-1/8" (29 mm)				5.8
53936	1-3/8" (35 mm)				6.2
53938	replacement shaft				3.5

Ship-Auger Bits

Ship-Auger Bits with Screw Point

- Drills through nails, wood, vinyl, plastics and heavy timber.
- Special bit steel with machine-ground flutes and polished edges for smooth, wobble-free boring.
- Full length is heat-treated and tempered.
- Deep, open-throat design clears chips for faster, cleaner cuts.
- 7/16" hex shafts fit 1/2" and larger three-jaw chucks.



Cat. No.	Bit Size	Twist Length	Overall Length	Weight (lbs.)
53402	3/4"	4" (102 mm)	6" (152 mm)	.40
53404	7/8"	4" (102 mm)	6" (152 mm)	.50
53406	1"	4" (102 mm)	6" (152 mm)	.50
53408	1-1/8"	4" (102 mm)	6" (152 mm)	.80

- Head and twist are ground to correct clearance for easy removal from hole.
- For heavy construction and repair work in mines, on docks and bridges, as well as electrical work.

Cat. No.	Bit Size	Twist Length	Overall Length	Weight (lbs.)
53437	3/4"	15" (381 mm)	18" (457 mm)	.95
53439	7/8"	15" (381 mm)	18" (457 mm)	1.20
53441	1"	15" (381 mm)	18" (457 mm)	1.70
53443	1-1/8"	15" (381 mm)	18" (457 mm)	1.80

All dimensions are in inches and (millimeters).




NOTE: Read and follow safety instructions in power tool owner's manual.

www.kleintools.com

See page 296 for additional information on warnings.

Holemaking Products & Accessories

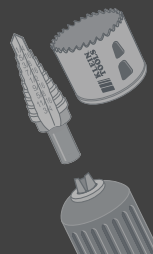

Drill Bit Sets

13-Piece Regular-Point Drill-Bit Set

- Hinged metal box with one stand-up bit holder.

Cat. No.	Set Contains				Weight (lbs.)
53002					.60
Cat. No.	Bit Size	Cat. No.	Bit Size		
53100	1/16"	53107	11/64"		
53101	5/64"	53108	3/16"		
53102	3/32"	53109	13/64"		
53103	7/64"	53110	7/32"		
53104	1/8"	53111	15/64"		
53105	9/64"	53112	1/4"		
53106	5/32"				



53002

15-Piece Regular-Point Drill-Bit Set

- Hinged metal box with two stand-up bit holders.

Cat. No.	Set Contains				Weight (lbs.)
53001					2.00
Cat. No.	Bit Size	Cat. No.	Bit Size		
53100	1/16"	53116	5/16"		
53102	3/32"	53118	11/32"		
53104	1/8"	53120	3/8"		
53106	5/32"	53122	13/32"		
53108	3/16"	53124	7/16"		
53110	7/32"	53126	15/32"		
53112	1/4"	53128	1/2"		
53114	9/32"				



53001

29-Piece Regular-Point Drill-Bit Set

- Hinged metal box with three stand-up bit holders.

Cat. No.	Set Contains				Weight (lbs.)
53000					3.25
Cat. No.	Bit Size	Cat. No.	Bit Size		
53100	1/16"	53115	19/64"		
53101	5/64"	53116	5/16"		
53102	3/32"	53117	21/64"		
53103	7/64"	53118	11/32"		
53104	1/8"	53119	23/64"		
53105	9/64"	53120	3/8"		
53106	5/32"	53121	25/64"		
53107	11/64"	53122	13/32"		
53108	3/16"	53123	27/64"		
53109	13/64"	53124	7/16"		
53110	7/32"	53125	29/64"		
53111	15/64"	53126	15/32"		
53112	1/4"	53127	31/64"		
53113	17/64"	53128	1/2"		
53114	9/32"				



53000

All dimensions are in inches and (millimeters).



NOTE: Read and follow safety instructions in power tool owner's manual.

www.kleintools.com

See page 296 for additional information on warnings.

Drill Bits

Regular-Point 118° High-Speed Drill Bits

- General-purpose, high-speed bits for reliable performance in a wide range of materials.
- Standard jobber length.
- Black-oxide finish reduces chip welding.
- Lightly roughened surface has higher lubricity for easier chip flow.



53128

Cat. No.	Bit Size	Flute Length	Overall Length	Weight (lbs.)
53100	1/16"	7/8" (22 mm)	1-7/8" (48 mm)	.01
53101	5/64"	1" (25 mm)	2" (51 mm)	.01
53102	3/32"	1-1/4" (32 mm)	2-1/4" (57 mm)	.01
53103	7/64"	1-1/2" (38 mm)	2-5/8" (67 mm)	.01
53104	1/8"	1-5/8" (41 mm)	2-3/4" (70 mm)	.01
53105	9/64"	1-3/4" (44 mm)	2-7/8" (73 mm)	.01
53106	5/32"	2" (51 mm)	3-1/8" (79 mm)	.01
53107	11/64"	2-1/8" (54 mm)	3-1/4" (83 mm)	.01
53108	3/16"	2-5/16" (59 mm)	3-1/2" (89 mm)	.02
53109	13/64"	2-7/16" (62 mm)	3-5/8" (92 mm)	.02
53110	7/32"	2-1/2" (64 mm)	3-3/4" (95 mm)	.05
53111	15/64"	2-5/8" (67 mm)	3-7/8" (98 mm)	.05
53112	1/4"	2-3/4" (70 mm)	4" (102 mm)	.05
53113	17/64"	2-7/8" (73 mm)	4-1/8" (105 mm)	.05
53114	9/32"	2-15/16" (75 mm)	4-1/4" (108 mm)	.05

Cat. No.	Bit Size	Flute Length	Overall Length	Weight (lbs.)
53115	19/64"	3-1/16" (78 mm)	4-3/8" (111 mm)	.05
53116	5/16"	3-3/16" (81 mm)	4-1/2" (114 mm)	.05
53117	21/64"	3-5/16" (84 mm)	4-5/8" (117 mm)	.10
53118	11/32"	3-7/16" (87 mm)	4-3/4" (121 mm)	.05
53119	23/64"	3-1/2" (89 mm)	4-7/8" (124 mm)	.10
53120	3/8"	3-5/8" (92 mm)	5" (127 mm)	.10
53121	25/64"	3-3/4" (95 mm)	5-1/8" (130 mm)	.10
53122	13/32"	3-7/8" (98 mm)	5-1/4" (133 mm)	.15
53123	27/64"	3-15/16" (100 mm)	5-3/8" (137 mm)	.15
53124	7/16"	4-1/16" (103 mm)	5-1/2" (140 mm)	.15
53125	29/64"	4-3/16" (106 mm)	5-5/8" (143 mm)	.18
53126	15/32"	4-5/16" (110 mm)	5-3/4" (146 mm)	.15
53127	31/64"	4-3/8" (111 mm)	5-7/8" (149 mm)	.20
53128	1/2"	4-1/2" (114 mm)	6" (152 mm)	.20

Anchors

Conical Anchor Kit – 100 Fasteners

- Kit contains: 100 #2 Phillips, 10 x 1" Screws, and 100 plastic anchors.
- 1/4" Masonry drill bit also included.

Cat. No.	Anchor Size	Screw Size	Bit Size	Weight (lbs.)
53729	10 - 12	10 x 1" (25 mm)	1/4" (6 mm)	1.00



53729

All dimensions are in inches and (millimeters).



NOTE: Read and follow safety instructions in power tool owner's manual.

www.kleintools.com

See page 296 for additional information on warnings.

