


HP ProDisplay P222va 54,6 cm (21.5") Monitor

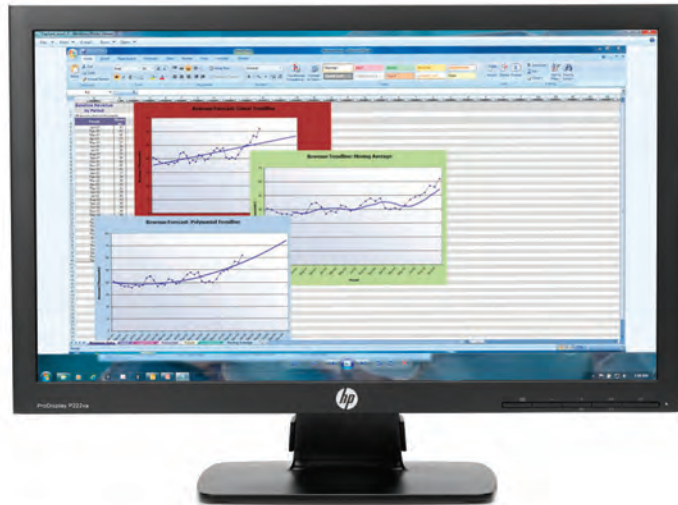

Perfect for your Pro PC.

Put your HP Pro PC content front and center on an ample 54,6 cm (21.5") diagonal display with the HP ProDisplay P222va Monitor. The sleek design delivers essential presentation features and advanced connectivity for your everyday business productivity at a highly affordable price point.



Fabulous front-of-screen.

- Get crisp image clarity for all your content on the 54,6 cm (21.5") diagonal screen with 1920 x 1080 resolution, and 3000:1 contrast ratio.¹ 178-degree viewing angles mean everybody has a great view of the screen.

High-speed connection for FHD imagery.

- Experience stunning FHD picture quality, ultra-fast graphics refresh, and vivid colors from the DisplayPort connection, which also supports multiple monitor connections from a single PC. Get legacy device compatibility from the VGA connector.

Create an efficient, easy-to-use workspace.

- Attach your HP Desktop Mini, HP Chromebox, or select HP Thin Client directly behind the display.² Keep things tidy with an integrated power supply and cable management features.

Additional features

- Reduce power consumption and help lower your costs with an intelligent, energy-efficient, low halogen³ design that is ENERGY STAR® and TCO certified and EPEAT® Gold registered.⁴
- Free up valuable desk space with mounting options⁵ enabled by the 100-mm VESA pattern, including the HP Adjustable Dual Display Stand, which holds two displays in a single-stand footprint. Select the head-only model⁵ if you don't need a stand.
- Customize a total solution with options⁵ designed for your display.
- Design the screen for how you work with HP Display Assistant software.
- Rest assured that your IT investment is supported by a three-year standard limited warranty. Select HP Care Pack Services⁶ to extend your protection beyond the standard limited warranties.

HP ProDisplay P222va 54,6 cm (21.5") Monitor Specifications Table



Product Number	K7X30AA; K7X30AT; K7X30AS;
Product Color	Black
Display size (diagonal)	54,6 cm (21.5")
Display Type	VA w/LED Backlight
Panel Active Area	476 x 267.7 mm;
Viewing Angle	178° horizontal; 178° vertical
Brightness	250 cd/m ²
Contrast Ratio	3000:1 static; 5000000:1 dynamic ¹
Response Ratio	8 ms gray to gray ¹
Aspect Ratio	16:9
Native Resolution	1920 x 1080
Resolutions Supported	1920 X 1080; 1680 X 1050; 1600 X 900; 1440 X 900; 1280 X 1024; 1280 x 800; 1280 X 720; 1024 X 768; 800 X 600; 640 X 480
Display Features	Anti-glare; Language selection; LED Backlights; On-screen controls; Plug and Play; User programmable
Input signal	1 VGA; 1 DisplayPort 1.2 (with HDCP support)
Input power	Input voltage: 100 to 240 VAC
Power consumption	Panel Active Area: 476 x 267.7 mm; Power consumption Description: 28 W (maximum), 24 W (typical), 0.5 W (standby); Screen resolution: 1920 x 1080
Dimensions with Stand (W x D x H)	51.8 x 18.66 x 37.92 cm
Dimensions without Stand (W x D x H)	51.8 x 4.75 x 31.52 cm
Weight	3.61 kg (With stand)
Ergonomic features	Tilt: -5 to +22°
Certification and Compliance	CE; CB; KC/KCC; NOM; PSB; ICE; TUV-S; CCC; CEL; CECp; SEPA; TCO Certified; EPA; ISC; VCCI; FCC; Taiwan BSMI
Environmental	Arsenic-free display glass; Mercury-free display backlights; Low halogen ²
Energy Efficiency Compliance	ENERGY STAR® certified
What's in the box	AC power cord; VGA cable; DisplayPort cable; CD (includes user guide, warranty, drivers)
Warranty	3-years limited warranty including 3 years of parts and labour. Certain restrictions and exclusions apply.

HP ProDisplay P222va 54,6 cm (21.5") Monitor

Accessories and services (not included)

HP Dual Output USB Graphics Adapter



Increase screen real estate and productivity with a dual-monitor setup with the HP Dual Output USB Graphics Adapter, featuring DVI-I and DisplayPort outputs to drive displays at high resolutions through a single USB 3.0 B connection to your PC.

Product number: C5U89AA

HP Integrated Work Center Stand for Ultra Slim Desktop and Thin Client



The HP Integrated Work Center Stand is designed to help maximize the use of limited desk space without compromising performance or productivity by accommodating an HP Compaq 6005 Pro, or 8000 Series HP Ultra-slim Desktop PC or an HP Thin Client and most HP 17 to 24-inch (43.18 to 60.96 cm) diagonal LCD monitors (please refer to compatibility in the Quick Spec) with VESA standard mounting brackets.

Product number: E8H16AA

HP Integrated Work Center for Desktop Mini and Thin Client



Make the most of small work spaces with an HP IWC Desktop Mini/Thin Client that lets you create a compact desktop solution by combining a display with an HP Desktop Mini, HP Thin Client or HP Chromebox and giving you convenient front access to all of its inputs.

Product number: G1V61AA

HP ProDisplay Companion Stand



Maximize small work spaces with an affordable HP ProDisplay Companion Stand, which enables you to create a compact desktop solution by combining an HP ProDisplay Monitor with your choice of platform.

Product number: J7V21AA

HP LCD Speaker Bar



Attach seamlessly to the front bezel of your monitor to add full multimedia support features, including stereo speakers with full sound range and an external jack for headphones.

Product number: NQ576AA

HP 5 year Next business day Onsite Standard Monitor Hardware Support



HP Care Pack Services offer upgraded service levels to enhance your warranty cover for your total peace of mind and help you to stay up and running.

Product number: U7935E

Learn more at
www.hp.eu/hpoptions

HP ProDisplay P222va 54,6 cm (21.5") Monitor

Messaging Footnotes

¹ All performance specifications represent the typical specifications provided by HP's component manufacturers; actual performance may vary either higher or lower.

² Requires HP Quick Release, sold separately. See product QuickSpecs for exact PC and thin client compatibility.

³ External power supplies, power cords, cables and peripherals are not Low Halogen. Service parts obtained after purchase may not be Low Halogen.

⁴ EPEAT® registered where applicable. EPEAT registration varies by country. See www.epeat.net for registration status by country.

⁵ Each accessory sold separately. Mounting hardware sold separately. Head only model sold separately.

⁶ HP Care Pack Services are sold separately. Service levels and response times for HP Care Pack Services may vary depending on your geographic location. Service starts from date of hardware purchase. Restrictions and limitations apply. See www.hp.com/go/cpc for details. HP Services are governed by the applicable HP terms and conditions of service provided or indicated to Customer at the time of purchase. Customer may have additional statutory rights according to applicable local laws, and such rights are not in any way affected by the HP terms and conditions of service or the HP Limited Warranty provided with your HP Product.

Technical specifications disclaimers

¹ All specifications represent the typical specifications provided by HP's component manufacturers, actual performance may vary either higher or lower.

² External power supplies, power cords, cables and peripherals are not Low Halogen. Service parts obtained after purchase may not be Low Halogen.

Learn more at

www.hp.eu/monitors

Engage HP Financial Services

Explore monthly payment options and technology refresh plans that can provide more flexibility to help you meet your IT goals. More information on www.hp.com/go/hpfs.

Sign up for updates

www.hp.com/go/getupdated

The product could differ from the images shown. © 2015 Hewlett-Packard Development Company, L.P. The information contained herein is subject to change without notice. Specific features may vary from model to model. The only warranties for HP products and services are set forth in the express warranty statements accompanying such products and services. Nothing herein should be construed as constituting an additional warranty. HP shall not be liable for technical or editorial errors or omissions contained herein.

ENERGY STAR® and the ENERGY STAR® mark are registered trademarks of the U.S. Environmental Protection Agency.

