

Standard Barrel Copper Lug

T&B Catalog Number:

256-30695-839

UPC Number:

78621064317

Status:

Active

Description:

Copper Two-Hole Lug, Standard Barrel, Peep Hole, Tongue Length 2.06 Inches, Max 35kV, Wire Size 400 Weld, 3/8 Inch Bolt Size, 1 Inch Hole Spacing, Tin Plated, Die Code 80

General

Material	Copper
Finish	Tin Plated
Wire Size	400 Flex
Number of Studs	2
Stud Size	3/8
Bolt Hole Spacing	1
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Code	80

Dimension Information

A (inches)	4.094
B (inches)	2.063
C (inches)	1.609
D (inches)	.219
E (inches)	1.047
F (inches)	.5
G (inches)	1

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Inner Pack	6
Package in Units	60
T&B Sold in UOM	Each
T&B Weight Per UOM	66 lbs. per 100

Application Support


Overview	Available on Website
----------	----------------------

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

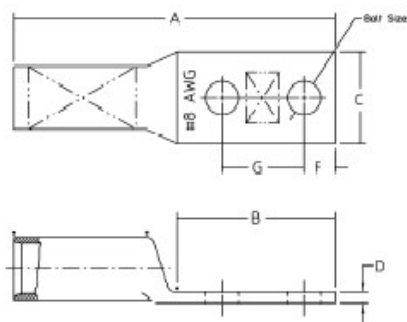

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com