

Standard Barrel Copper Lug

T&B Catalog Number:

54106BS

UPC Number:


78621095455

Status:

Active

Description:

Copper One-Hole Lug, Standard Barrel - Bell Shaped End, Peep Hole, Tongue Length 9/16, Max 35kV, Wire Size Code #4 AWG, 1/4 Inch Bolt Size, Tin Plated, Die Code 29, Die Color Code Gray

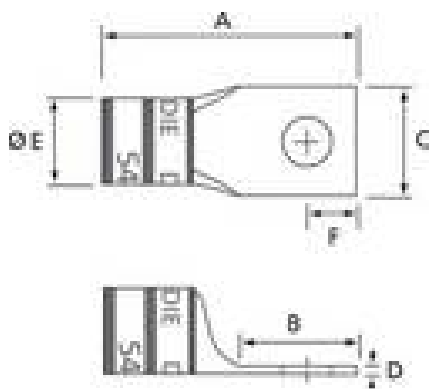

General

Material	Copper
Finish	Tin Plated
Wire Size	#4 AWG
Number of Studs	1
Stud Size	1/4
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Belled End
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Grey
Die Code	29

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Inner Pack	50
Package in Units	500
T&B Sold in UOM	Each
T&B Weight Per UOM	2 lbs. per 100

Application Support

Overview	Available on Website
----------	----------------------

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:

E9809

For further technical assistance, please contact us...

Memphis, TN 38125
www.tnb.com

8155 T&B Blvd.
Memphis, TN 38125

Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com