

Narrow-Tongue Copper Lug T&B Catalog Number:

54118NT

UPC Number:

78620986783

Status:

Active

Description:

Copper One-Hole Lug, Standard Barrel Narrow Tongue, Peep Hole, Max 35kV, Wire Size 500 kcmil, 1/2 Inch Bolt Size, Tin Plated, Die Code 87, Die Color Code Brown

General

Material	Copper
Finish	Tin Plated
Wire Size	500 kcmil
Number of Studs	1
Stud Size	1/2
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Narrow
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Brown
Die Code	87

Dimension Information

A (inches)	3.250
B (inches)	1.250
C (inches)	1.100
D (inches)	0.218
E (inches)	1.100
F (inches)	0.500

Specifications

Voltage Rating	600V
----------------	------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Inner Pack	6
Package in Units	60
T&B Sold in UOM	Each
T&B Weight Per UOM	34.13 lbs. per 100

Application Support

T&B Sales Drawings	wsd-000288
--------------------	------------


Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications



File Nbr:
E9809

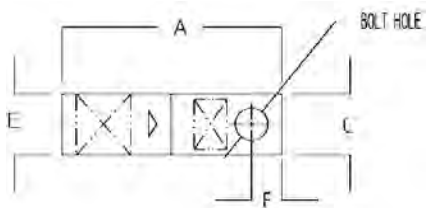

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com