

Long Barrel Copper Lug T&B Catalog Number:

54851BEPHBS

UPC Number:

78621092778

Status:

Active

Description:

Copper Two-Hole Lug - Straight Long Belled End Barrel - max 35KV, #8 AWG Wire, 1/4" Bolt Size, 3/4" Hole Spacing, Tin Plated with Inspection Hole, Red 21

General

Material	Copper
Finish	Tin Plated
Wire Size	#8 AWG
Number of Studs	2
Stud Size	1/4
Bolt Hole Spacing	3/4
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Belled End
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Red
Die Code	21

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Inner Pack	10
Package in Units	50
T&B Sold in UOM	Each
T&B Weight Per UOM	2.5 lbs. per 100

Application Support

Overview	Available on Website
----------	----------------------

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----


Certifications



File Nbr:

E9809

For further technical assistance, please contact us...

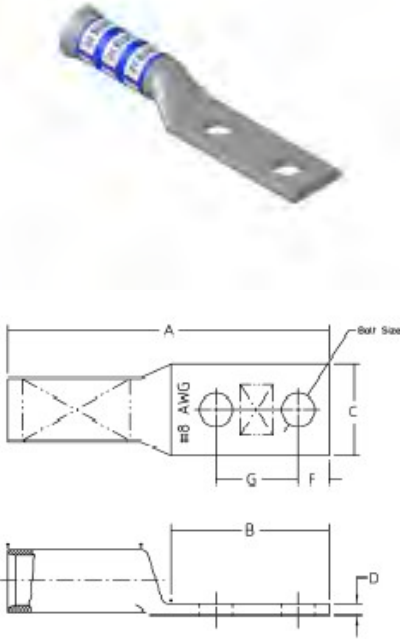

8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com