



Ferrule

T&B Catalog Number:

F4001

UPC Number:

78621033670

Status:

Active

Description:

Polypropylene-Insulated Old DIN Ferrule, Total Length .571 Inches/ 14.5mm, Pin Length .315 Inches/8mm, Pin Diameter .051 Inches/1.3mm, Base Diameter .110 Inches/2.8mm, Wire Range #18 AWG/.75mm², Color White, Copper, Tin Plated


WEB_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Ferrules ensure reliable electrical connections when terminating conductors in screw clamp terminal blocks.

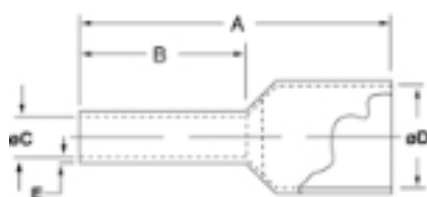

General

Ferrule Type	OLD DIN
Insulation Type	Polypropylene
Material	Copper
Finish	Electro -Tin Plated
Color	White
Wire Range	18
Wire Size (mm ²)	.75

Dimension Information

A (mm)	14.5
B (mm)	8.0
Diameter C (inches)	.051
Diameter C (mm)	1.3
Diameter D (inches)	.110
Diameter D (mm)	2.8
E (mm)	.15
A (inches)	.571
B (inches)	.315
E (inches)	.006

Specifications

Temperature Rating	105°C
Flammability Rating	94HB

Tooling

Tool Charts	Available on Website
Application Tools	T1, T3, ERG4
Recommended Tool	T1, T3, ERG4

Packaging

T&B Order Multiple	500
T&B Inner Pack	500
Package in Units	10000
T&B Sold in UOM	Each
T&B Weight Per UOM	0.63 lbs. per 1000

Application Support

T&B Sales Drawings	wsd-000402
Overview	Available on Website
Wire Guide Tables	Available on Website

Notes

Ferrule dimensions conform to DIN 46228, Part 4.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com