



Ring Terminal T&B Catalog Number:

UPC Number:

K10-38R-T

Status:

78621090387

Description:

Active

Non-Insulated Ring Terminal for Wire Range 12-10 Stud Size 3/8, Metallic, Mylar Tape

Features

Brazed Seam ensures barrel does not separate during crimping. Chamfered barrel entry.

Standards

UL

General

Insulation Type	Non-Insulated
Material	Copper
Finish	Electro -Tin Plated
Color	Metallic
Wire Range	12-10
Stud Size	3/8

Dimension Information

d1 (inches)	.134
D (inches)	.220
E (inches)	.236
F (inches)	.531
L (inches)	1.063
T (inches)	.039
W (inches)	.591

Specifications

Temperature Rating	150°C
Voltage Rating	600V
Flammability Rating	UL 94 V-0

Tooling

Application Tools	WT111M, WT112M, CM2000A
-------------------	-------------------------

Packaging

T&B Order Multiple	2000
Package in Units	2000
T&B Sold in UOM	Each
T&B Weight Per UOM	4.38 lbs. per 1000

Certifications

RoHS Compliance	Yes
-----------------	-----


Certifications



File Nbr:

E9809

For further technical assistance, please contact us...

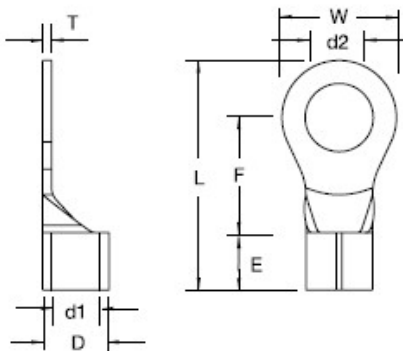

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com