



## Plain Edge Cable Clamps

**T&B Catalog Number:**

N6NY-008C-0-C

**UPC Number:**

72849409704

**Status:**

Active


**Description:**

Plain Edge Cable Clamp, Black Nylon 6.6 for Temperatures up to 85 Degrees Celsius (185 F), Width of 12.7mm (0.50 Inches), Thickness of 1.52mm (0.06 Inches), Hole Diameter of 5.16mm (0.203 Inches), #10 Screw Mounting with Closed Diameter of 12.7mm (0.50 Inches), 100 Pack

### Features

Fully radiused inside edges with size markings in inches and millimeters for easy identification.

Plain edge cable clamps are designed to perform to NAS-1397P.

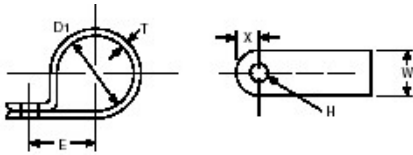

### General

Material	Nylon 6/6
Color	Black
Mounting Method	#10 Screw

### Dimension Information

Width (inches)	0.500
Hole Diameter (inches)	0.203
Closed Diameter (inches)	0.500
Max. Wire Bundle Diameter (inches)	0.500
Thickness (inches)	0.060
E (inches)	0.553
X (inches)	0.218

### Specifications

Temperature Rating	-40°F to 185°F
--------------------	----------------

### Packaging

T&B Order Multiple	100
T&B Inner Pack	100
Package in Units	5000
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	2.5 lbs. per 1000

### Application Support

T&B Sales Drawings	wsd-000525
--------------------	------------

### Certifications

RoHS Compliance	Yes
-----------------	-----

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com